


- Unique **Guide-Rite** Fastener provides for fast and easy installation.
- Fasteners will rotate 360°.
- Simply installed with a hammer and pliers.

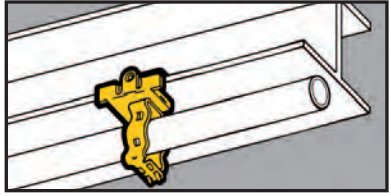

Guide-Rite™ Conduit To Beam Fasteners




UPC/Part Number	Catalog Number	Conduit Size	Flange Thickness	Box Qty.
781011 18450	BG-6-U-2-4*	3/8"	1/8" - 1/4"	100
781011 18455	BG-6-U-5-8*	3/8"	5/16" - 1/2"	100
781011 18460	BG-6-U-9-12*	3/8"	9/16" - 3/4"	100
781011 18525	BG-8-12-U-2-4	1/2", 3/4"	1/8" - 1/4"	100
781011 18530	BG-8-12-U-5-8	1/2", 3/4"	5/16" - 1/2"	100
781011 18535	BG-8-12-U-9-12	1/2", 3/4"	9/16" - 3/4"	100
781011 18625	BG-16-U-2-4	1"	1/8" - 1/4"	100
781011 18630	BG-16-U-5-8	1"	5/16" - 1/2"	100
781011 18635	BG-16-U-9-12	1"	9/16" - 3/4"	100
781011 18680	BG-20-U-2-4	1 1/4"	1/8" - 1/4"	100
781011 18685	BG-20-U-5-8	1 1/4"	5/16" - 1/2"	100
781011 18690	BG-20-U-9-12	1 1/4"	9/16" - 3/4"	100
781011 18720	BG-24-U-2-4	1 1/2"	1/8" - 1/4"	50
781011 18725	BG-24-U-5-8	1 1/2"	5/16" - 1/2"	50
781011 18730	BG-24-U-9-12	1 1/2"	9/16" - 3/4"	50
781011 18760	BG-32-U-2-4	2"	1/8" - 1/4"	50
781011 18765	BG-32-U-5-8	2"	5/16" - 1/2"	50
781011 18770	BG-32-U-9-12	2"	9/16" - 3/4"	50

Patent #4958792

- * BG-6 will accept the following range $\varnothing.420$ - $\varnothing.675$:
1 1/2 thru 10/4 MC/AC cable
and 5/16 or 3/8 flexible conduit

**Static Load
Capacity**

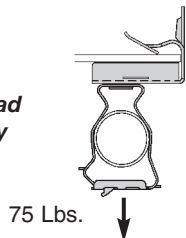

Read safety/installation instruction sheets in packages before use.