

## Panels & Panel Accessories JIC & Small Enclosure Perforated Panels Illustration Sheet and Catalog Number

Discount Schedule: C2; A2  
Subclass: DSO


| Catalog Number | A     |     | B     |     | Gauge | Fits Enclosure Height x Width |         |
|----------------|-------|-----|-------|-----|-------|-------------------------------|---------|
|                | in.   | mm  | in.   | mm  |       | in.                           | mm      |
| AW64PP         | 4.87  | 124 | 2.87  | 73  | 16    | 6.00x4.00                     | 152x102 |
| AW66PP         | 4.87  | 124 | 4.87  | 124 | 16    | 6.00x6.00                     | 152x152 |
| AW86PP         | 6.87  | 174 | 4.87  | 124 | 16    | 8.00x6.00                     | 203x152 |
| AW88PP         | 6.87  | 174 | 6.87  | 174 | 16    | 8.00x8.00                     | 203x203 |
| AW108PP        | 8.87  | 225 | 6.87  | 174 | 16    | 10.00x8.00                    | 254x203 |
| AW1010PP       | 8.87  | 225 | 8.87  | 225 | 16    | 10.00x10.00                   | 254x254 |
| AW126PP        | 10.87 | 276 | 4.87  | 124 | 16    | 12.00x6.00                    | 305x152 |
| AW1210PP       | 10.87 | 276 | 8.87  | 225 | 16    | 12.00x10.00                   | 305x254 |
| AW1212PP       | 10.87 | 276 | 10.87 | 276 | 16    | 12.00x12.00                   | 305x305 |
| AW148PP        | 12.87 | 327 | 6.87  | 174 | 16    | 14.00x8.00                    | 356x203 |
| AW1412PP       | 12.87 | 327 | 10.87 | 276 | 16    | 14.00x12.00                   | 356x305 |
| AW1610PP       | 14.87 | 378 | 8.87  | 225 | 16    | 16.00x10.00                   | 406x254 |
| AW1614PP       | 14.87 | 378 | 12.87 | 327 | 16    | 16.00x14.00                   | 406x356 |

Panels are available in steel and have a white powder paint finish.


| Catalog Number | A     |     | B     |     | Gauge | Fits Enclosure Height x Width |         |
|----------------|-------|-----|-------|-----|-------|-------------------------------|---------|
|                | in.   | mm  | in.   | mm  |       | in.                           | mm      |
| N66PP          | 4.25  | 108 | 4.25  | 108 | 16    | 6.00x6.00                     | 152x152 |
| N86PP          | 6.25  | 159 | 4.25  | 108 | 16    | 8.00x6.00                     | 203x152 |
| N88PP          | 6.25  | 159 | 6.25  | 159 | 16    | 8.00x8.00                     | 203x203 |
| N108PP         | 8.25  | 210 | 6.25  | 159 | 16    | 10.00x8.00                    | 254x203 |
| N1010PP        | 8.25  | 210 | 8.25  | 210 | 16    | 10.00x10.00                   | 254x254 |
| N1210PP        | 10.25 | 260 | 8.25  | 210 | 16    | 12.00x10.00                   | 305x254 |
| N1212PP        | 10.25 | 260 | 10.25 | 260 | 16    | 12.00x12.00                   | 305x305 |
| N1412PP        | 12.25 | 360 | 10.25 | 260 | 16    | 14.00x12.00                   | 356x305 |
| N2012PP        | 18.25 | 463 | 10.25 | 260 | 16    | 20.00x12.00                   | 508x305 |

Panels are available in steel and have a white powder paint finish.


| Hardware Packages |  |                                |          |
|-------------------|--|--------------------------------|----------|
| Catalog Number    | Description                            | Typical Use                    | Quantity |
| 10168             | #8-32 x .375 inch self tap steel screw | NEMA 1 & JIC perforated panels | 20       |

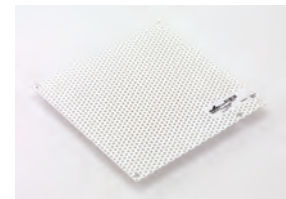


### JIC Enclosure Perforated Panels

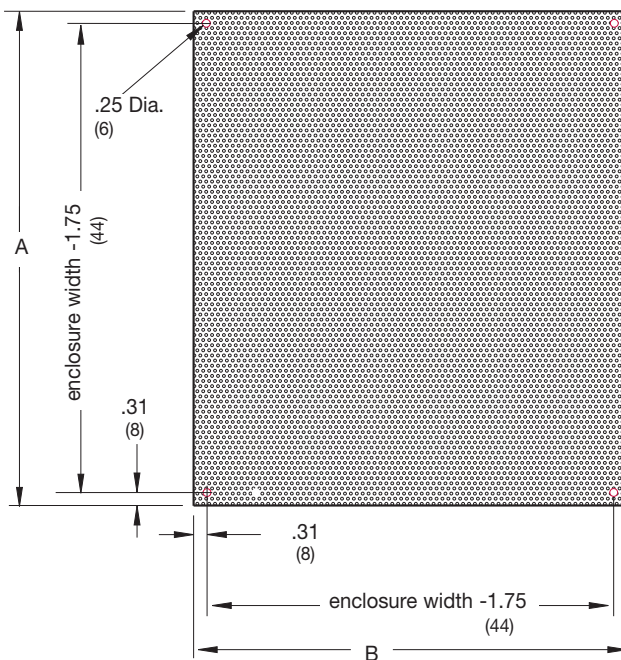

JIC perforated panels can be installed in all types of JIC Enclosures, and are intended for mounting lightweight components without drilling and tapping.

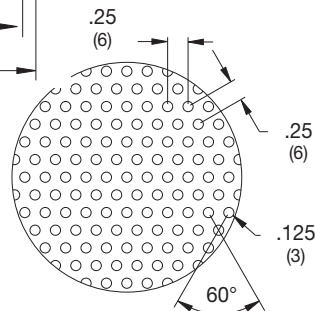

### Small Enclosure Perforated Panels

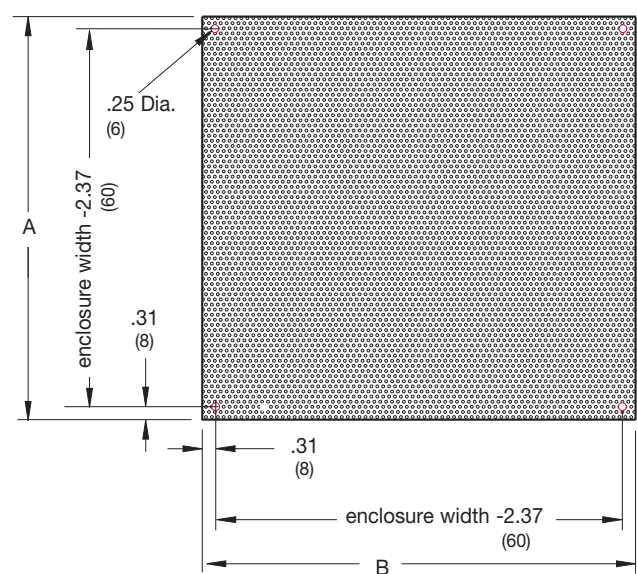

Small enclosure perforated panels can be installed in small Type 3R RHC, and small Type 1 Enclosures, and are intended for mounting lightweight components without drilling and tapping.

**Notes:** Dimensions are in inches. Millimeters shown are for reference only. Data subject to change without notice.