


Beams




- Quickly attaches conduit to beams.
- Fasteners will rotate 360°.
- Simply installed with a hammer.

Push-Type Conduit To Beam Fasteners

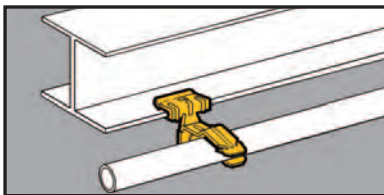

UPC/Part Number	Catalog Number	Conduit Size	Flange Thickness	Box Qty.
781011 19275	BP-8-E-2-4	1/2" EMT	1/8" - 1/4"	100
781011 19280	BP-8-E-5-8	1/2" EMT	5/16" - 1/2"	100
781011 19285	BP-8-E-9-12	1/2" EMT	9/16" - 3/4"	100
781011 19375	BP-12-E-2-4	3/4" EMT 1/2" IMC, Rigid	1/8" - 1/4"	100
781011 19380	BP-12-E-5-8	3/4" EMT 1/2" IMC, Rigid	5/16" - 1/2"	100
781011 19385	BP-12-E-9-12	3/4" EMT 1/2" IMC, Rigid	9/16" - 3/4"	100
781011 19465	BP-16-E-2-4	1" EMT 3/4" IMC, Rigid	1/8" - 1/4"	100
781011 19470	BP-16-E-5-8	1" EMT 3/4" IMC, Rigid	5/16" - 1/2"	100
781011 19475	BP-16-E-9-12	1" EMT 3/4" IMC, Rigid	9/16" - 3/4"	100


**Ultimate
Static Load
Capacity**

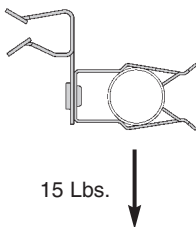

15 Lbs.

Read safety/installation instruction sheets in packages before use.

- Unique **Guide-Rite** Fastener provides for fast and easy installation.
- Fasteners will rotate 360°.
- Simply installed with a hammer and pliers.

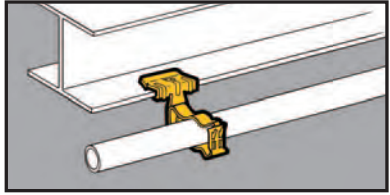


Guide-Rite™ Conduit To Beam Fasteners



UPC/Part Number	Catalog Number	Conduit Size	Flange Thickness	Box Qty.
781011 18430	BG-6-E-2-4*	3/8"	1/8" - 1/4"	100
781011 18435	BG-6-E-5-8*	3/8"	5/16" - 1/2"	100
781011 18440	BG-6-E-9-12*	3/8"	9/16" - 3/4"	100
781011 18505	BG-8-12-E-2-4	1/2", 3/4"	1/8" - 1/4"	100
781011 18510	BG-8-12-E-5-8	1/2", 3/4"	5/16" - 1/2"	100
781011 18515	BG-8-12-E-9-12	1/2", 3/4"	9/16" - 3/4"	100
781011 18575	BG-16-E-2-4	1"	1/8" - 1/4"	100
781011 18580	BG-16-E-5-8	1"	5/16" - 1/2"	100
781011 18585	BG-16-E-9-12	1"	9/16" - 3/4"	100
781011 18660	BG-20-E-2-4	1 1/4"	1/8" - 1/4"	100
781011 18665	BG-20-E-5-8	1 1/4"	5/16" - 1/2"	100
781011 18670	BG-20-E-9-12	1 1/4"	9/16" - 3/4"	100
781011 18705	BG-24-E-2-4	1 1/2"	1/8" - 1/4"	50
781011 18710	BG-24-E-5-8	1 1/2"	5/16" - 1/2"	50
781011 18715	BG-24-E-9-12	1 1/2"	9/16" - 3/4"	50
781011 18745	BG-32-E-2-4	2"	1/8" - 1/4"	50
781011 18750	BG-32-E-5-8	2"	5/16" - 1/2"	50
781011 18755	BG-32-E-9-12	2"	9/16" - 3/4"	50

Patent #4958792

- * BG-6 will accept the following range $\varnothing.420$ - $\varnothing.675$:
14/2 thru 10/4 MC/AC cable
and 5/16 or 3/8 flexible conduit

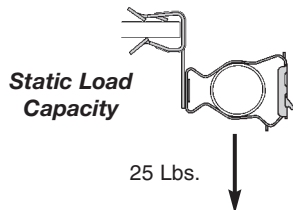

Read safety/installation instruction sheets in packages before use.