

In-line Fuse Holders

HR and HM Series

Specifications

Description: In-line fuse holders for SFE and 1/4" dia. x various length fuses.

Dimensions: See Dimensions illustration.

Ratings:

Volts: — 32V

Amps: — 20A

Features and Benefits

- HR and HM Universal in-line fuse holder for SFE and various length 1/4" diameter fuses with #14 lead wires.

Typical Applications

- Supplemental, Low Voltage, Low Amperage Control Circuits

Catalog Numbers

Catalog Numbers	Includes Fuse	Wire Length & Size
HRJ*	SFE-20	19" of #14
HRI	SFE-14	
HRH	SFE-9	
HRE	SFE-7½	
HRG	SFE-6	
HRF	SFE-4	
HMJ**	SFE-20	8" of #14
HMI	SFE-14	
HMH	SFE-9	
HME	SFE-7½	
HMG	SFE-6	
HMF	SFE-4	

* Also available as in-line fuse holder only with lead wire contacts, HRJ-LESS-Fuse.

** Also available as in-line fuse holder only with lead wire contacts, HMJ-LESS-Fuse.

HHJ-A For 3/8" x 1 1/4" fuse, no wire or fuse included, accepts #18 - #22 wire.


HHJ-B For 1/2" x 1 1/4" fuse, no wire or fuse included, accepts #12 - #16 wire.

HHi-B For 3/4" x 1 1/8" fuse, no wire or fuse included, accepts #12 - #16 wire.

Replacement Contacts

Catalog Number	Symbol
9838	HHJ-A
9841	HHJ-B

Dimensions - in (mm)

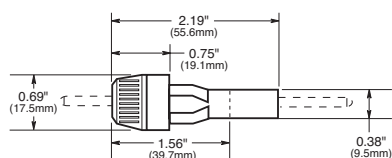

Data Sheet: 2122

HFA Series



Specifications

Description: In-line water-resistant fuse holders for 1/4" x 1 1/4" fuses.

Dimensions: See Dimensions illustration.

Construction: Phenolic body with copper crimp contact leads.

Ratings:

Volts: — 250V

Amps: — 20A

Agency Information: CE, UL Recognized, (Guide IZLT2, File E14853) UL.

Flammability Rating: UL 94HB.

Features and Benefits

- HFA in-line, water-resistant fuse holder for 1/4" x 1 1/4" fuses.

Typical Applications

- Supplemental, Low Voltage, Low Amperage Control Circuits


Refer to data sheet for recommend crimp tools

Catalog Numbers

Catalog Numbers	Terminals
HFA	Crimp #12 - #16
HFA-HH*	1/4" Quick Connect

*No UL Recognition.

Dimensions - in (mm)

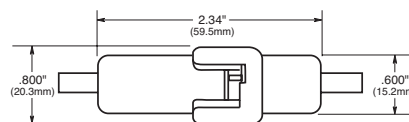

Data Sheet: 2115

HHT Series



Specifications

Description: In-line fuse holders for 5 x 15mm or 5 x 20mm fuses.

Dimensions: See Dimensions illustration.

Construction: Black thermoplastic body with brass contacts, wire: 16 AWG, red.

Ratings:

Volts: — 32V

Amps: — 5A (5 x 15mm)
— 10A (5 x 20mm)

Features and Benefits

- HHT in-line fuse holders for 5 x 15mm and 5 x 20 mm fuses.


Typical Applications

- Supplemental, Low Voltage, Low Amperage Control Circuits

Catalog Numbers

Catalog Number	Fuse Size
HHT	5 x 15mm & 5 x 20mm

Dimensions - in

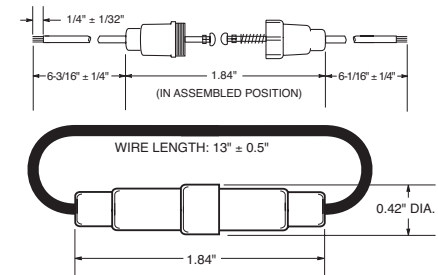

Data Sheet: 2138

Catalog Number Index

Catalog Number	Page	Catalog Number	Page	Catalog Number	Page	Catalog Number	Page	Catalog Number	Page
ENF30	381-383	FH2	*	GG	226	HHD	56	HTC-45M	65
ENF3150	381-383	FHL	*	GH	226	HHF	56	HTC-50M	65
ENF32	381-383	FHN	*	GKB	*	HHG	56	HTC-55M	281
ENF400	381-383	FL-	*	GKJ	*	HHI	278	HTC-60M	65
ENF45	381-383	FL11H_	88	GLD	51	HHJ	278	HTC-65M	65
ENF60	381-383	FL11K_	88	GLH	*	HHL	56	HTC-70M	281
ENF600	381-383	FL11N	*	GLN	*	HHM	56	HVA	87
ENF63	381-383	FL11T_	88	GLP	235	HHT	278	HVB	87
ENF800	381-383	FL12K_	88	GLQ	53	HHX	56	HVJ	87
ENN	*	FL1A5	*	GLR	54	HIF	*	HVL	87
EP	*	FL3H	*	GLX	*	HJL	285	HVR	87
ERK-28	411	FL3K_	88	GMA	61	HJM	*	HVT	87
ERS2	*	FL3T_	88	GMA-V	61	HKA	*	HVU	87
ERS30	*	FLB	*	GMC	61	HKL	285	HVV	87
ESD	225	FLD	*	GMC-V	61	HKP	282	HVX	87
ET	191-192	FLF	*	GMD	61	HKQ	*	HWA	*
ETF	*	FLM	*	GMD-V	61	HKR	285	IXL70F	*
EVF	*	FLN	*	GMF	54	HKT	285	J-__	415
F01A	*	FLS	*	GMQ	53	HKU	285	J101/J	*
F02A	*	FM	191-192, 194	GMT-	399	HXX	285	J201/J	*
F02B	*	FM01A	*	GMT-A	399	HLA	*	J301/J	*
F03A	*	FM08A	*	GMW	*	HLD	285	J60_	266-267
F03B	*	FM09A	*	GOB	*	HLQ	53	J70032	216
F06A	*	FM09B	*	GRF	54	HLR	54	J70100	216
F07A	*	FMM	191-192, 194	GSK-260	410	HLS	399	JA600	268
F09A	*	FMX	*	H07C	224	HLT	399	JB1	*
F09B	*	FNA	51	H25_	260-262	HME	278	JB3	*
F10A	*	FNJ	*	H60_	263-265	HMF	278	JCA	*
F15A	*	FNM	49	HAC-R	*	HMG	278	JCD-	78
F15B	*	FNQ	49	HAS-R	*	HMH	278	JCE-	*
F16A	*	FNQ-R	18	HBC	*	HMI	278	JCG-	80, 82
F16B	*	FNW	*	HBH-I	66	HMJ	278	JCH-	80-81
F19B	*	FP-__	414	HBH-M	66	HMK	*	JCI-	78
F29A	*	FR-1000	*	HBM	*	HMR	*	JCK-	80-81
F38	402	FRN-R	35	HBO	*	HN-1	*	JCK-A-	80-81
F380	*	FRN-R-_ID	35	HBP-	*	HN-3	*	JCK-B-	80-81
F60C	*	FRS-R	36	HBS-	*	HN-5	*	JCL-	80-81
F61C	*	FRS-R-_ID	36	HBV-I	66	HOB	*	JCL-A-	80, 82
F62C	*	FSD	*	HBV-M	66	HOF	*	JCL-B-	80, 82
F63C	*	FT-__	414	HBW-I	66	HPC-D	287	JCM	*
F64C	*	FTI	*	HBW-M	66	HPD	286	JCN	*
F65C	*	FTM	*	HC-	*	HPF	286	JCP	*
F7036-	*	FWA	98-101, 197-198	HC1	*	HPG	286	JCQ-	78
FA02	*	FWC	205-206	HC2	*	HPL	*	JCR-A	80, 82
FA2A	*	FWH	104-105, 201-204	HC3	*	HPM	287	JCR-B-	80, 82
FA4H	*	FWJ	111-112, 213-214	HC7	*	HPS	286	JCT-	78
FBI	66	FWK	211-212	HC8	*	HPS2	287	JCU-	74-75
FBM	66	FWL	215	HCM	*	HRE	278	JCW-	78
FBP	*	FWP	207-210	HEB	279-280	HRF	278	JCX-	74
FC	*	FWS	215	HEC	279	HRG	278	JCY-	74
FCB	*	FWX	102-103, 199-200	HEF	*	HRH	278	JCZ-	74-75
FCC	*	G30060	274	HEG	279	HRI	278	JDN	*
FCU	*	GBA	51	HEH	279	HRJ	278	JDZ-	74-75
FD200	344	GBB	63	HEJ	279	HRK	277	JF1	*
FD400	340-344	GBB-V	63	HET	279	HSK	*	JJN-	38
FD600	340-343, 346	GBC	*	HEX	279	HTB-	283-284	JJS-	39
FD800	340-343, 346	GDA	59	HEY	279	HTC-10M	*	JKS	24
FDM	*	GDA-V	59	HFA	278	HTC-140M	67	JN	*
FE	191-192, 194	GDB	59	HFB	277	HTC-15M	67	JP600	268
FE2475-	*	GDB-V	59	HGA	*	HTC-200M	67	JPA-3	*
FEE	191-192, 194	GDC	60	HGB	*	HTC-210M	67	JSK-36	410
FEH	*	GDC-V	60	HGC	*	HTC-30M	*	JT	255-256
FF	226	GF	226	HHB	277	HTC-35M	281	JTN	255-256
FG	226	GFA	*	HHC	56	HTC-40M	281	JU	*

* Not listed in this catalog. Call Cooper Bussmann Customer Satisfaction for more information. Call 636-527-3877.