


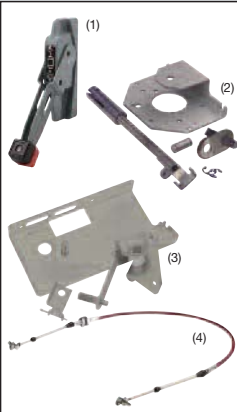


UL 98 Fused Rotary Disconnect Switches—200 & 400A Standard Class J

Select for Standard Applications		or					
		Flange Handle⁽¹⁾ 200A Only - requires shaft operated mechanism <i>or</i> cable operated mechanism + cable					
		NEMA Type	Flange Style	Test Function	Padlockable	Defeatable	Part Number
		1, 3R, 4, 12	Standard	N	Y	Y	FLH1
1, 3R, 4, 4X, 12	Chrome Plated	N	Y	Y	FLH2		
Shaft Operated Flange Mechanism⁽²⁾ 200A Only - includes shaft							
For Enclosure Depth in (mm)					Part Number		
6-24 (152-613)					FLRM		
Cable Operated Flange Mechanism and Cable 200A Only - must select Mechanism ⁽³⁾ <i>and</i> Cable ⁽⁴⁾							
Item					Part Number		
Cable Mechanism					FLCM		
36" (900mm) Cable					FLC36		
60" (1500mm) Cable					FLC60		
120" (3000mm) Cable					FLC120		
Accessories		or					
		NFPA Through the Door Handle Kit - to be used with front pistol handle					
		Use with Switch	Color	Test Function	Padlockable	Defeatable	Part Number
		RDF200J-__	Red	N	Y	N	H79-2
RDF400J-__	Red	N	Y	N	H79-3		
and ...							
Accessories		Auxiliary Contacts					Part Number
		Contact Type	Number of Contacts	Continuous Amp Rating	Voltage Rating	Max Number of Aux Contacts per Switch	Part Number
		NO	1	10A	600Vac	RDF200J-__: 4	BAC05
		NC	1	10A	600Vac	RDF400J-__: 8	BAC06
and ...							
Accessories		Terminal Shrouds - includes terminal shroud for lineside or loadside					Part Number
		Switch Amp Rating	Number of Poles				Part Number
		200	2				TSH8-2TB
		200	3				TSH8-3TB
		200	4				TSH8-4TB
		400	2				TSH9-2TB
		400	3				TSH9-3TB
400	4				TSH9-4TB		

Disconnect Switches

Dimensions – in (mm)

• RDF200J-3

• RDF400J-3

