

Ferrule — FWS/FWL 1000Vdc: 2-30A

FWS 2-15A (20 x 127mm)
FWL 20-30A (20 x 127mm)

Specifications

Description: Ferrule style full range fuses.

Dimensions: See dimensions illustrations.

Ratings:

- Volts: — 1200Vac (FWL 20-30A)
- 1400Vac (FWS 8-15A)
- 2100Vac (FWS 2-6A)
- 1000Vdc (FWL/FWS 2-30)

Amps: — 2-30A

- IR: — 45kA RMS Sym.
- 30kA @ 1000Vdc


Agency Information: CE, IEC 60077

Catalog Numbers


Catalog Numbers	Size	Electrical Characteristics				Watts Loss
		Rated Current RMS-Amps	I ² t (A ² Sec)		Clearing at 1000Vdc	
			Pre-arc			
FWS-2A20F	20 x 127mm (¹³ / ₁₆ " x 5")	2	0.8	2.4	4.4	
FWS-6A20F		6	27	81	6.7	
FWS-8A20F		8	64	192	7.6	
FWS-10A20F		10	118	277	3.0	
FWS-12A20F		12	170	380	3.4	
FWS-15A20F	15	209	500	5.0		
FWL-20A20F	20 x 127mm (¹³ / ₁₆ " x 5")	20	675	1550	5.9	
FWL-25A20F		25	1200	2760	6.5	
FWL-30A20F		30	1850	4300	7.5	

- ADD "I" to catalog number for indicating version.
- Enclosed finger-safe fuse holder — CH127
- See accessories on page 243.
- Watts loss provided at rated current.

Dimensions - mm (in)

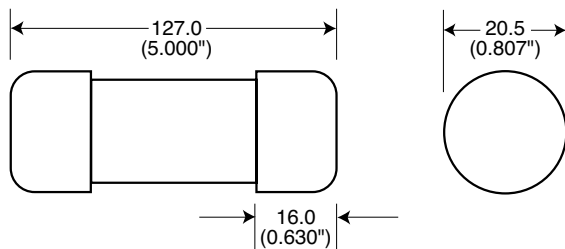

Indicating Version - Dimensions - mm (in)

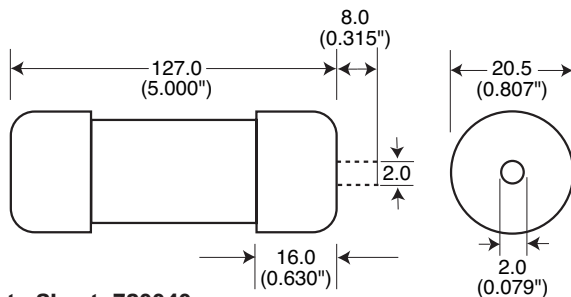

Data Sheet: 720040



Features and Benefits

- Excellent cycling capability and DC performance
- Low arc voltage and low energy let-through (I²t)
- Low watts loss in a compact size
- Used with finger-safe holders/blocks

Typical Applications

- DC Common bus
- DC Drives
- Power converters/rectifiers
- Reduced voltage starters
- Traction aux circuits
- Capacitor protection

FWL/FWS 2-30A: 1000Vdc 2-30A (20 x 127mm)

Time-Current Curve

