

# Steel Masonry Boxes

## MASONRY BOXES

2 1/2" DEEP × 3 3/4" HIGH  
 1/2" AND 3/4" CONCENTRIC KOs  
 UL LISTED




TP682

GP

Cat. #	Gang	Width	KNOCKOUTS			Unit Qty.	Wt. Lbs. Per 100	Capacity Cu. In.
			Each Side	Each End	Bottom			
TP682	1	1 15/16"	2	1	2	20	70	15.5
TP683	2	3 3/4"	2	2	4	10	103	31.0
TP684	3	5 9/16"	2	3	6	5	129	46.5
TP685	4	7 7/8"	2	4	8	5	165	62.0
TP686	5	9 9/16"	2	5	10	5	189	77.5
TP687	6	11"	2	6	12	1	230	93.0

## MASONRY BOXES

3 1/2" DEEP × 3 3/4" HIGH  
 1/2" AND 3/4" CONCENTRIC KOs  
 UL LISTED

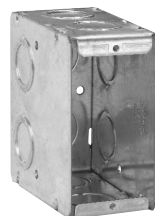

TP690



TP691

Cat. #	Gang	Width	KNOCKOUTS			Unit Qty.	Wt. Lbs. Per 100	Capacity Cu. In.
			Each Side	Each End	Bottom			
TP690	1	1 15/16"	2	2	2	20	84	22.0
TP691	2	3 3/4"	2	4	4	10	120	44.0
TP692	3	5 9/16"	2	6	6	10	155	66.5
TP693	4	7 7/8"	2	8	8	5	207	88.0
TP694	5	9 9/16"	2	10	10	5	235	110.0
TP695	6	11"	2	12	12	1	287	132.0

## MASONRY BOX PARTITIONS

Cat. #	Description	Unit Qty.	Wt. Lbs. Per 100
TP820	Nonmetallic Partition for 2 1/2" Deep Masonry Boxes	25	3
TP821	Nonmetallic Partition for 3 1/2" Deep Masonry Boxes	25	4