


Steel Masonry Boxes

MASONRY BOXES

2 1/2" DEEP × 3 3/4" HIGH
 1/2" AND 3/4" CONCENTRIC KOs
 UL LISTED

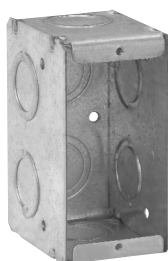


TP682

| Cat. # | Gang | Width | KNOCKOUTS | | | Unit Qty. | Wt. Lbs. Per 100 | Capacity Cu. In. |
|--------|------|----------|-----------|----------|--------|-----------|------------------|------------------|
| | | | Each Side | Each End | Bottom | | | |
| TP682 | 1 | 1 15/16" | 2 | 1 | 2 | 20 | 70 | 15.5 |
| TP683 | 2 | 3 3/4" | 2 | 2 | 4 | 10 | 103 | 31.0 |
| TP684 | 3 | 5 9/16" | 2 | 3 | 6 | 5 | 129 | 46.5 |
| TP685 | 4 | 7 7/8" | 2 | 4 | 8 | 5 | 165 | 62.0 |
| TP686 | 5 | 9 9/16" | 2 | 5 | 10 | 5 | 189 | 77.5 |
| TP687 | 6 | 11" | 2 | 6 | 12 | 1 | 230 | 93.0 |

MASONRY BOXES

3 1/2" DEEP × 3 3/4" HIGH
 1/2" AND 3/4" CONCENTRIC KOs
 UL LISTED

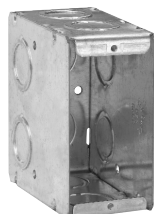

TP690



TP691

| Cat. # | Gang | Width | KNOCKOUTS | | | Unit Qty. | Wt. Lbs. Per 100 | Capacity Cu. In. |
|--------|------|----------|-----------|----------|--------|-----------|------------------|------------------|
| | | | Each Side | Each End | Bottom | | | |
| TP690 | 1 | 1 15/16" | 2 | 2 | 2 | 20 | 84 | 22.0 |
| TP691 | 2 | 3 3/4" | 2 | 4 | 4 | 10 | 120 | 44.0 |
| TP692 | 3 | 5 9/16" | 2 | 6 | 6 | 10 | 155 | 66.5 |
| TP693 | 4 | 7 7/8" | 2 | 8 | 8 | 5 | 207 | 88.0 |
| TP694 | 5 | 9 9/16" | 2 | 10 | 10 | 5 | 235 | 110.0 |
| TP695 | 6 | 11" | 2 | 12 | 12 | 1 | 287 | 132.0 |

MASONRY BOX PARTITIONS

| Cat. # | Description | Unit Qty. | Wt. Lbs. Per 100 |
|--------|---|-----------|------------------|
| TP820 | Nonmetallic Partition for 2 1/2" Deep Masonry Boxes | 25 | 3 |
| TP821 | Nonmetallic Partition for 3 1/2" Deep Masonry Boxes | 25 | 4 |

