

# LOW PROFILE LIQUIDTIGHT FITTINGS

The Low Profile liquidtight fittings are designed specifically for applications that require close side-by-side mounting of multiple liquidtight fittings in tight spaces.

## Standard Materials

- Body – steel (straight fittings), malleable iron (angle fittings)
- Gland nut – steel
- Ferrule – steel
- Gland nut sealing ring – nylon
- Sealing gasket – polypropylene


## Standard Finishes

- Steel – zinc electroplate
- Malleable iron – zinc electroplate
- Nylon – natural
- Polypropylene – natural




## Ordering & Dimensional Information

### Straight Connectors — Steel

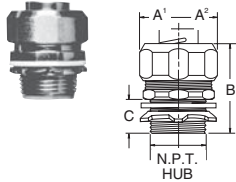


Conduit Size	Non-Insulated Cat. No.	Insulated Cat. No.	Over Round Corner A <sup>1</sup>	Hex A <sup>2</sup>	B	C	N.P.T. Thread Length
3/8"	LTK38	LTBK38	1 3/32"	1 1/32"	1 3/16"		19/32"
1/2"	LTK50	LTBK50	1 3/16"	1 1/8"	1 11/32"		19/32"
3/4"	LTK75	LTBK75	1 7/16"	1 3/8"	1 7/16"		19/32"
1"	LTK100	LTBK100	1 3/4"	1 11/16"	1 5/8"		21/32"
1 1/4"	LTK125	LTBK125	2 5/32"	2 1/16"	1 27/32"		43/64"
1 1/2"	LTK150	LTBK150	2 3/8"	2 9/32"	2"		23/32"
2"	LTK200	LTBK200	2 7/8"	2 25/32"	2 1/8"		23/32"

### 45° Angle Connectors — Malleable Iron

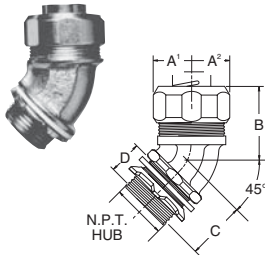

Conduit Size	Non-Insulated Cat. No.	Insulated Cat. No.	Over Round Corner A <sup>1</sup>	Hex A <sup>2</sup>	B	C	N.P.T. Thread Length D
3/8"	LTK3845	LTBK3845	1 3/32"	1 1/32"	1 7/32"	1 1/32"	19/32"
1/2"	LTK5045	LTBK5045	1 3/16"	1 1/32"	1 5/16"	1 1/32"	19/32"
3/4"	LTK7545	LTBK7545	1 7/16"	1 3/8"	1 3/8"	1 1/8"	13/32"
1"	LTK10045	LTBK10045	1 3/4"	1 11/16"	1 21/32"	1 1/4"	21/32"
1 1/4"	LTK12545	LTBK12545	2 5/32"	2 1/16"	1 23/32"	1 11/32"	11/16"
1 1/2"	LTK15045	LTBK15045	2 3/8"	2 9/32"	2"	1 15/32"	23/32"
2"	LTK20045	LTBK20045	2 7/8"	2 25/32"	2 9/32"	1 5/8"	23/32"

### 90° Angle Connectors — Malleable Iron

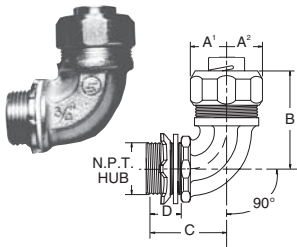

Conduit Size	Non-Insulated Cat. No.	Insulated Cat. No.	Over Round Corner A <sup>1</sup>	Hex A <sup>2</sup>	B	C	N.P.T. Thread Length D
3/8"	LTK3890	LTBK3890	1 3/32"	1 1/32"	1 19/32"	1 1/4"	9/16"
1/2"	LTK5090	LTBK5090	1 3/16"	1 1/8"	1 21/32"	1 1/4"	9/16"
3/4"	LTK7590	LTBK7590	1 7/16"	1 3/8"	1 25/32"	1 17/32"	9/16"
1"	LTK10090	LTBK10090	1 3/4"	1 11/16"	2 3/16"	1 27/32"	21/32"
1 1/4"	LTK12590	LTBK12590	2 5/32"	2 1/16"	2 3/8"	1 15/16"	11/16"
1 1/2"	LTK15090	LTBK15090	2 3/8"	2 9/32"	2 5/8"	2 3/32"	23/32"
2"	LTK20090	LTBK20090	2 7/8"	2 25/32"	3 1/16"	2 13/32"	23/32"

## For more information:

Contact an authorized Cooper Crouse-Hinds Distributor, Sales Office or Customer Service Department:

## Distributed by:

### In the U.S.:

Cooper Crouse-Hinds  
P.O. Box 4999  
Syracuse, NY 13221  
Toll Free: 866-764-5454  
(315) 477-5531  
FAX: (315) 477-5179  
crouse.customerctr@crouse-hinds.com

### In Canada:

Cooper Crouse-Hinds Canada  
Toll Free: 800-265-0502  
(905) 507-4187  
FAX: (905) 568-7048

For office locations outside of North America or for additional product information, visit our website at: [www.crouse-hinds.com](http://www.crouse-hinds.com)

Mexico • Latin America/Caribbean • Germany • Australia • Asia • Dubai • India



Solutions. Worldwide.™

Crouse-Hinds is a registered trademark of Cooper Industries, Inc.  
© 2006 Cooper Industries, Inc.

