

COOPER LIGHTING - SURE-LITES®

DESCRIPTION

The LM Series is an emergency light packaged in an attractive, flame-resistant metal housing. High-impact thermoplastic PAR36 heads permit unrestricted unit placement and easy beam positioning. The unit of choice for installations where the size and cost of emergency lighting must be kept to a minimum without sacrificing dependability or light output.

Catalog #		Type
Project		
Comments		Date
Prepared by		

SPECIFICATION FEATURES

Electronic

- Dual Voltage Input 120/277 VAC, 60 Hz
- Line-latching
- Solid-state Voltage Limited Charger
- Solid-state Switching
- Low-Voltage Disconnect
- Brownout Circuit
- Overload/Short Circuit Protection
- Test Switch/Power Indicator Light

- Universal J-Box
- Mounting Pattern
- Keyhole Mounting Slots
- White Finish

Warranty

- Unit: 1-year
- Battery: 5-year pro-rata

Battery

- Sealed Lead Calcium, Recombination
- Maintenance-free, Long-life
- Full Recharge Time, 24 hrs. (max.)
- Polarized Battery Terminals

Head/Lamp Data


- Two (2) PAR 36 type lamps
- Two Heads Standard
- Side Mounted
- Glare-Free Lens
- Fully Adjustable
- High Impact - Thermoplastic
- Matches Housing Finish

Housing Construction

- 18-Gauge Die-Formed Steel
- Knockout, Conduit or Cord Set

Code Compliance

- UL 924 Listed
- Life Safety NFPA 101
- NEC/OSHA
- Most State and Local Codes

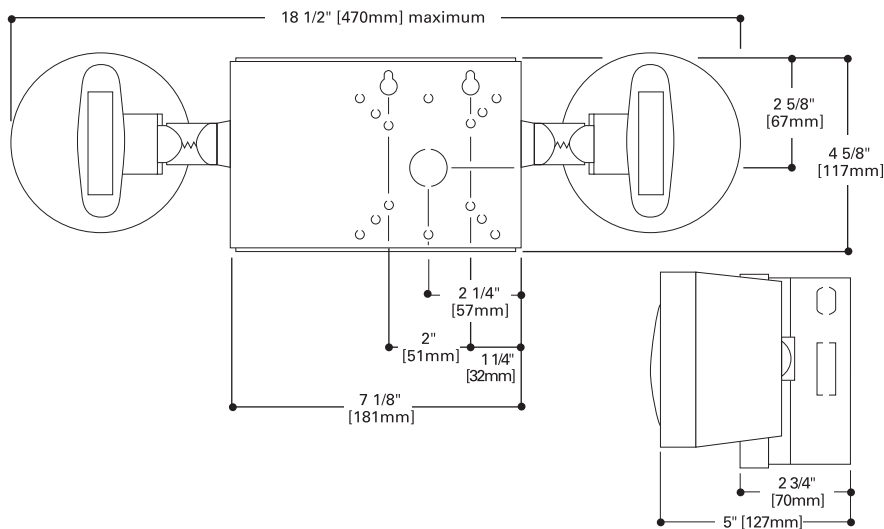

LM1 SERIES

DOUBLE HEAD
METAL BODY
EMERGENCY LIGHTING

TOTALLY PREDICTABLE
RELIABILITY

ELECTRICAL RATINGS

Rated Wattage to 87 1/2% of Rated D.C. Voltage

Model	DC Voltage	1 1/2 Hours	2 Hours
LM1	6	10.8	7.2

Lamp Information

Type	Wattage	Number
Incandescent	5.4	029-121

ORDERING INFORMATION

--	--

Series

LM1

Notes: 1 Order separately.

Accessories ¹

- Mounting Kit**
- 1BRWH**- Mounting Brackets (2) White
- Protective Housing**
- WG2**- Wire Guard
- VS1**- Polycarbonate Vandal Shield
- VS1WP**- Polycarbonate Vandal Shield - Weatherproof
- VK1**- Voltmeter

ENERGY DATA

Input Current (Max.):
120V= .12A
277V= .05A