


SF FALCON

70-150W Pulse Start Metal Halide

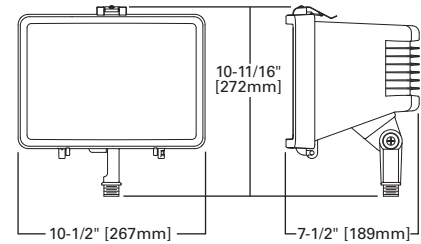


Knuckle

Ordering Information




| Stock Number | UPC | Wattage/ Source | Lamp | Ballast | Lamp Included | Ballast Kit |
|---|--------------|--------------------|--------------------|--------------------|---------------|--------------------------|
| Knuckle Mount Pulse Start Metal Halide | | | | | | |
| MPSF70K | 623961978043 | 70W MP | Medium-base, ED-17 | Hi.Rx/NPF/120/277V | MH70/U/MEDFG | MHKT-70-HIX-NPF-120/277V |
| MPSF10K-MT | 623961978111 | 100W MP | Medium-base, ED-17 | Hi.Rx/HPF/MT/277V | MH100/U/MEDFG | MHKT-100-HIX-HPF-MT |
| MPSF15K-MT | 623961757723 | 150W MP | Medium-base, ED-17 | CWA/MT/277V | MH150UMED | MHKT-150-CWA-MT |

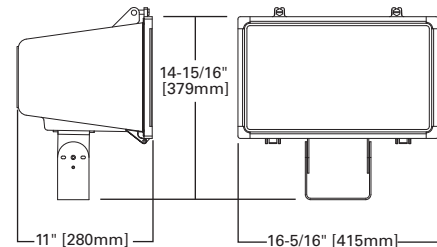

Trunnion

ARROWHEAD™

150-400W Pulse Start Metal Halide

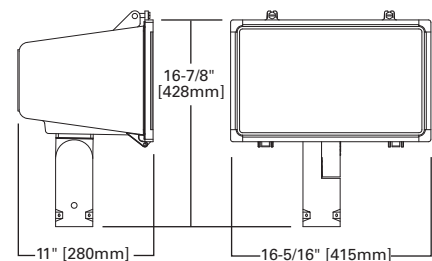

Slipfitter

Ordering Information



| Stock Number | UPC | Wattage/ Source | EISA Compliant | Lamp | Ballast | Lamp Included | Ballast Kit |
|--|--------------|--------------------|-------------------|--------------------|-------------|---------------|-----------------|
| Pulse Start Metal Halide Trunnion | | | | | | | |
| MPAH15T | 080083532025 | 150W MP | | Medium-base, ED-17 | CWA/MT/277V | MH150UMED | MPKT-150-CWA-MT |
| MPAH25T | 080083532032 | 250W MP | (E) | Mogul-base, ED-28 | CWA/MT/277V | MS250/U/PS | MPKT-250-CWA-MT |
| MPAH40T | 080083533152 | 400W MP | (E) | Mogul-base, ED-37 | CWA/MT/277V | M400/PS/U | MPKT-400-CWA-MT |



| | | | | | | | |
|--|--------------|---------|-----|--------------------|-------------|------------|-----------------|
| Pulse Start Metal Halide Slipfitter | | | | | | | |
| MPAH15S | 080083533190 | 150W MP | | Medium-base, ED-17 | CWA/MT/277V | MH150UMED | MPKT-150-CWA-MT |
| MPAH25S | 080083533206 | 250W MP | (E) | Medium-base, ED-28 | CWA/MT/277V | MS250/U/PS | MPKT-250-CWA-MT |
| MPAH40S | 080083533220 | 400W MP | (E) | Medium-base, ED-37 | CWA/MT/277V | M400/PS/U | MPKT-400-CWA-MT |