

STOCKING ORDERING INFORMATION

Sample Stock Number: QDCAST1A

Product	Description	Accessories (Order Separately)
QDCAST1A	LED Parking/Garage/Canopy Luminaire, Concrete Grey with Four Integral Locking Light Panels and Quick-Mount Bracket System, 120V-277V, 50/60 Hz.	QDPBG=Quadcast 6" Pendant Bird Guard QDOCC=Quadcast Photocontrol and Occupancy Sensor (on/off operation) ¹
QDCAST1A-OCC	LED Parking/Garage/Canopy Luminaire, Concrete Grey with Four Integral Locking Light Panels and Quick-Mount Bracket System, 120-277V, 50/60 Hz. Includes Integral On/Off Occupancy Sensor and Photocontrol	
QDCAST1A-347	LED Parking/Garage/Canopy Luminaire, Concrete Grey with Four Integral Locking Light Panels and Quick-Mount Bracket System, 347V, 60Hz.	
QDCAST1A-347V-OCC	LED Parking/Garage/Canopy Luminaire, Concrete Grey with Four Integral Locking Light Panels and Quick-Mount Bracket System, 347V, 60 Hz. Includes Integral On/Off Occupancy Sensor and Photocontrol	

NOTE: 1. QDOCC is supplied standard on QDCASTA-OCC and QDCAST1A-347V-OCC.

POWER CONSUMPTION

Voltage	Current (Amps)	Power (Watts)
120V	0.46A	56
208V	0.26A	56
240V	0.23A	56
277V	0.20A	56
347V	0.17A	58

CRI/CCT TABLE

LED Information	QDCAST1A-XX
Delivered Lumens	4,365
CCT (Kelvin)	4000
Color Rendering Index (CRI)	65


LUMEN MULTIPLIER

Ambient Temperature	Lumen Multiplier
10°C	1.04
15°C	1.03
25°C	1.00
40°C	0.96


LUMEN MAINTENANCE

Ambient Temperature	TM-21 Lumen Maintenance (60,000 Hours)	Theoretical L70 (Hours)
25°C	>94%	>350,000
40°C	>93%	>250,000


Pendant Bird Guard (QDPBG)

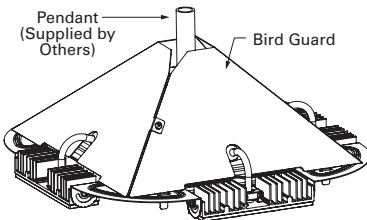

Occupancy Sensor (QDOCC)

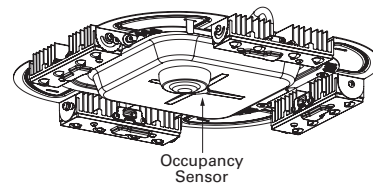

TYPICAL MOUNTING CONFIGURATIONS (PENDANT STEM AND J-BOXES SUPPLIED BY OTHERS)

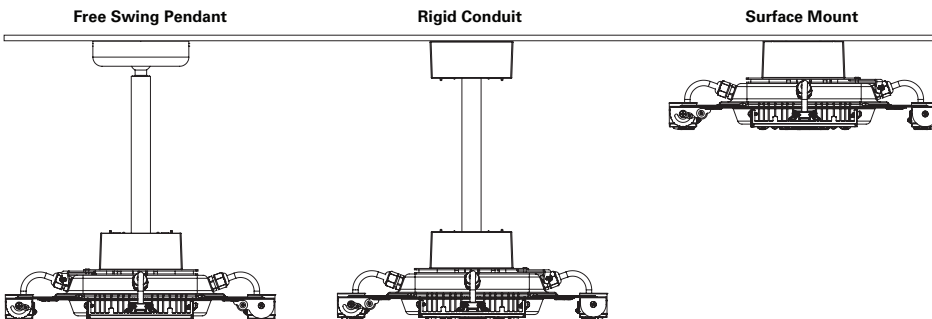

DesignLights™ Consortium Qualified. Refer to www.designlights.org Qualified Products List under Family Models for details.