

DESCRIPTION

Adjustable square baffle designed for use with IC or Non-IC AIR-TITE™ 3" Halo small aperture line and low voltage housings. This die-cast aluminum trim is available in multiple finishes to match interior decor. Trim uses low voltage MR16 or GU10 line voltage lamps ideal for accent and task lighting. Trim offers 15° tilt and integral 350° lamp holder rotation with locking thumbscrew. The trim construction allows use with the Halo H3 series of standard round aperture housings.

Catalog #		Type
Project		
Comments		Date
Prepared by		

DESIGN FEATURES

Adjustable square baffle trim available in Matte White, Black, Satin Nickel, Antique Copper or Tuscan Bronze finishes with Black Baffle. White trim also available with White Baffle. Lampholder can be rotated 350° independently of trim. Lampholder also offers 15° tilt. Three pressure springs ensure positive retention in housing.

Trim includes cover glass lens which may be replaced with a variety of media. (Lamps that have integral glass lens do not require use of the cover glass supplied with this trim.)

3011 is designed for use with the following Halo H3 (standard round) small aperture housings:


- Line Voltage Housing (for 120V GU10 lamps). For nominal 2 x 6 or larger construction.

H36ICAT	50W	IC Air-Tite Housing
H36TAT	50W	Non-IC Air-Tite Housing
H36RTAT	50W	Non-IC Air-Tite Remodel Housing
- Low Voltage Housing (for 12V MR16 lamps). For 2 x 6 construction.

H36LVICAT	50W	IC Air-Tite Housing
H36LVTAT	50W	Non-IC Air-Tite Housing
H36LVRTAT	50W	Non-IC Air-Tite Remodel Housing
H36LVTAT277	50W	Non-IC Air-Tite Housing, 120/277V
H36LVRTAT277	50W	Non-IC Air-Tite Remodel Housing, 120/277V
- Line Voltage Housing (for 120V GU10 lamps). For nominal 2 x 8 or larger construction.

H38ICAT	50W	IC Air-Tite Housing
---------	-----	---------------------
- Low Voltage Housing (for 12V MR16 lamps). For nominal 2 x 8 or larger construction.

H38LVICAT	37W	IC Air-Tite Housing
-----------	-----	---------------------

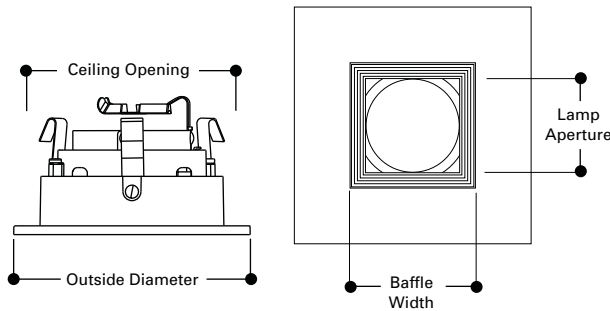

Lamp Aperture: 2" [51mm]
 Baffle Width: 2-1/4" [57mm]
 Ceiling Opening (round): 3-3/4" [95mm]
 Outside Dimension: 4-1/4" Square [108mm]



3011WHBB
White with Black Baffle



3011WHWB
White with White Baffle



3011BKBB
Black with Black Baffle



3011SNBB
Satin Nickel with Black Baffle



3011ACBB
Antique Copper with Black Baffle



3011TBZBB
Tuscan Bronze with Black Baffle

3011

3" Adjustable Baffle Square Trim

3" TRIMS

ORDERING INFORMATION

SAMPLE NUMBER: 3011WHBB

Order housing and trims separately.

Trim

3011

3011= 3" Adjustable Square Baffle Trim

Finish

WHBB=White with Black Baffle
 WHWB=White with White Baffle
 BKBB=Black with Black Baffle
 SNBB=Satin Nickel with Black Baffle
 ACBB=Antique Copper with Black Baffle
 TBZBB=Tuscan Bronze with Black Baffle