

DESCRIPTION

Miniature size, decorator finishes, push-in connectors, economy, all combine to make single-circuit Miniature Trac perfect for residential or commercial use. Polarized connectors and end caps are molded polycarbonate. Halo Miniature Track accepts both Halo and Lazer-by-Halo lampholders.

Catalog #		Type
Project		
Comments		Date
Prepared by		

SPECIFICATION FEATURES

A. Structural

Extruded aluminum .060" [1.5mm] nominal wall thickness

B. Line Conductor:

Solid copper bus bars [cross section equivalent to #12 AWG wire].

C. Insulating Liner

Extruded polyvinyl insulator.

D. Ground Conductor

Exclusive independent grounding bus conductor. Maintains an independent positive ground #12 AWG path between lampholder, Trac channel and building's ground system.

E. Neutral Conductor



Cross section equivalent of #12 AWG wire.

F. Polarity Indicator (Neutral)

Visual polarity groove indicates proper electrical installation of lampholder adapter.

Listings

cULus listed for use with Halo and Lazer-by-Halo lampholders.

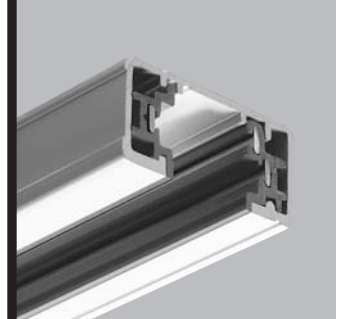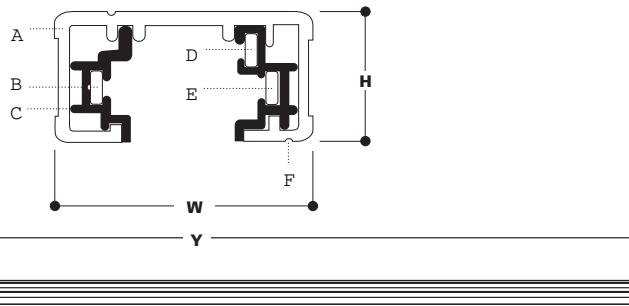

**L650, L651
L652, L653**

**MINIATURE
SINGLE CIRCUIT
TRAC SYSTEM**

Power-Trac

ORDERING INFORMATION

SAMPLE NUMBER: L651MB

Trac		Finishes		Accessories		Connectors	
L650=2' L651=4'	L652=8' L653=12'	P=Satin White MB=Matte Black BZ=Bronze	AB=Antique Brass PB=Polished Brass SL=Silver	(See Below)		L900 Outlet Box Cover L901 Live End connector L902 Flexible Connector L903 Straight Connector L904 L Connector L905 T Connector L906 X Connector L907 Outlet Box for use with T-Bar ceiling L908 Mini Joiner L909 Floating Canopy and Connector L950 Cord and Plug Connector L979 Conduit Continuation Kit L980 Live End Conduit Adapter DE600 Dead End	
L650	L651	L652	L653	Accessories L951 Wire Way Cover for Pendant Assembly Kit L983 T-Bar Attachment Clip L992 Pendant Kit assembly L48 48" Steel Stem L994 Pendant Adapter			
L =2' Nominal Actual length: 20-1/8" [511mm] W=1 3/8" [35mm] H =11/16" [17.5mm]	L =4' Nominal Actual length: 44-1/8" [1121mm] W=1 3/8" [35mm] H =11/16" [17.5mm]	L =8' Nominal Actual length: 98-1/8" [2492mm] W=1 3/8" [35mm] H =11/16" [17.5mm]	L =12' Nominal Actual length: 140-1/8" [3559mm] W=1 3/8" [3559mm] H =11/16" [17.5mm]	Current Limiter - End Feed LC901CB120 =120W (1A @120V) LC901CB300 =300W (2.5A @120V) LC901CB600 =600W (5A @120V) LC901CB960 =960W (8A @120V) LC901CB1200 =1200W (10A @120V) Current Limiter - Center Feed LC903CB120 =120W (1A @120V) LC903CB300 =300W (2.5A @120V) LC903CB600 =600W (5A @120V) LC903CB960 =960W (8A @120V) LC903CB1200 =1200W (10A @120V)			
Finish Codes P = White MB = Black B = Polished Brass SL =Silver	Finish Codes P = White MB = Black BZ = Bronze AB = Antique Brass B = Polished Brass SL =Silver	Finish Codes P = White MB = Black BZ = Bronze AB = Antique Brass B = Polished Brass SL =Silver	Finish Codes P = White MB = Black SL =Silver	Finish Codes P = White MB = Black			


DESCRIPTION

LC901, LC903 Current Limiter - End and Center Feeds

End-feed and Center-feed capable:


Five breaker sizes are available. Consult factory if other sizes are required. Can be utilized on hard or grid ceilings. Can be used with pendant suspended track. Breaker can be used as an on-off switch. Breaker features a "tripped" condition indicator. Approved by the California Energy Commission – meets Title 24 requirements. cULus Listed

Feed Type	Circuit 1 Breaker	Finish
LC901 = Halo Power-Trac 1-Circuit End Feed LC903 = Halo Power-Trac 1-Circuit Center Feed	CB120 = 120W (1A @ 120V) CB300 = 300W (2.5A @ 120V) CB600 = 600W (5A @ 120V) CB960 = 960W (8A @ 120V) CB1200 = 1200W (10A @ 120V)	P = White MB = Black

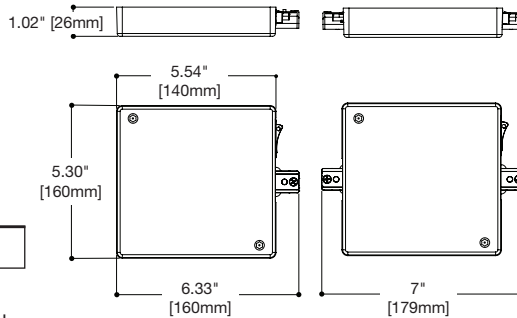

Sample catalog number: LC901CB120P
 (Field assembly of feed and circuit breaker required)

Consult factory for Single Circuit Center-feed requiring two circuit breakers

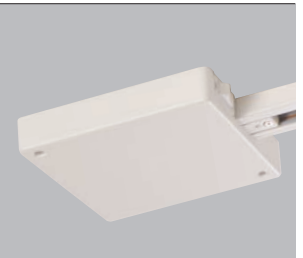

**LC901
LC903**



L900 Outlet Box Cover

Can be used at any electrical feed connection point (Live, Straight, L, T or X). Drill guides on back for virtually all standard outlet boxes. Size: 5" sq. Screws included.

Color codes: P (White), MB (Black)

ORDERING INFORMATION

Connector	Finish
L900	

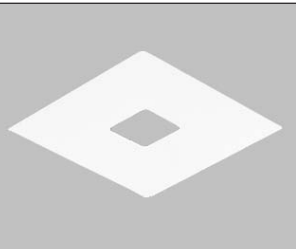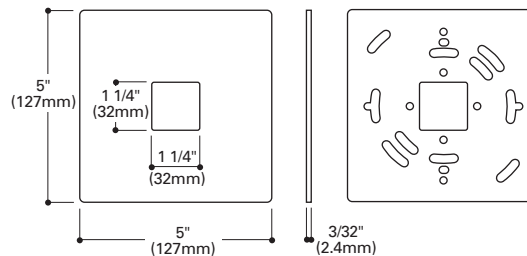

L900



L901 Live End Connector

To start a run.

Color codes: P (White), MB (Black)

ORDERING INFORMATION

Connector	Finish
L901	

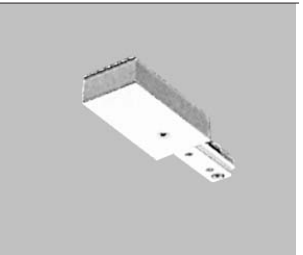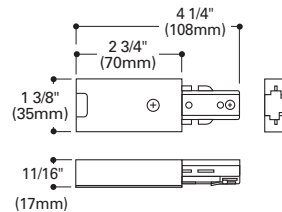

L901



L902 Flexible Connector

To connect two track sections at any angle up to 90° in either plane or wall to ceiling or pitched ceiling applications.

Color codes: P (White), MB (Black)

ORDERING INFORMATION

Connector	Finish
L902	

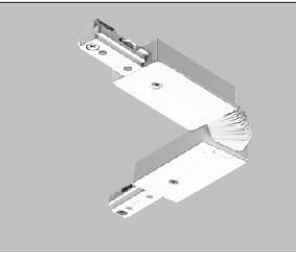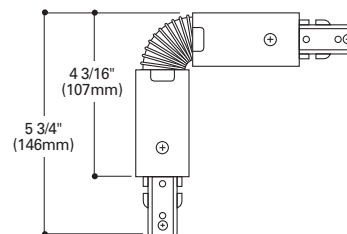


L902

DESCRIPTION

L903 Straight Connector

To connect two track sections end-to-end. L903 differs from mini connector L908 in that it provides a center feed option and is longer. May be used as feed point.

Color codes: P (White), MB (Black)

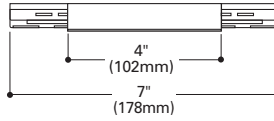

L903


ORDERING INFORMATION

Connector	Finish
L903	

L904 L Connector

To connect two track sections at a right angle. Field adjustable for either right hand or left hand application. May be used as feed point.

Color codes: P (White), MB (Black)

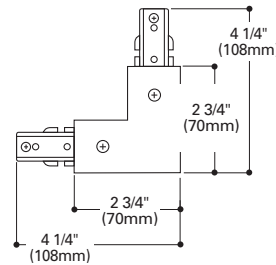

L904



ORDERING INFORMATION

Connector	Finish
L904	

L905 T Connector

To connect three track sections into a T configuration. Field adjustable for either right hand or left hand application. May be used as feed point.

Color codes: P (White), MB (Black)

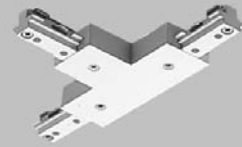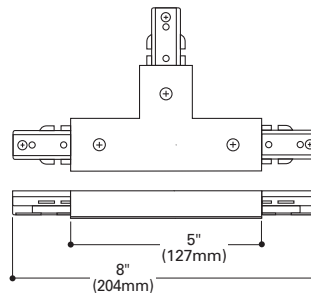

L905


ORDERING INFORMATION

Connector	Finish
L905	

L906 X Connector

To connect four track sections into a cross configuration. May be used as feed point.

Color codes: P (White), MB (Black)

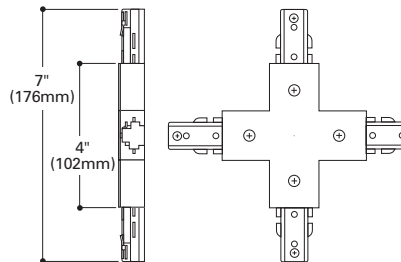

L906


ORDERING INFORMATION

Connector	Finish
L906	

L907 Outlet Box for use with T-Bar ceiling

L901, L903, L904, L905 or L906 connector also required. 4" x 4" x 1 1/8".

Color codes: P (White), MB (Black)

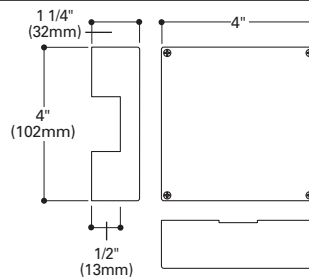

L907



ORDERING INFORMATION

Connector	Finish
L907	

L908 Mini Joiner

A low profile connector to cleanly and crisply join two straight track sections end-to-end. (Note: The L908 is not a feed point).

  Color codes: P (White), MB (Black)



L908

ORDERING INFORMATION

Connector	Finish
L908	

DESCRIPTION



L909 Floating Canopy and Connector

Track can be connected to existing outlet box located anywhere along the track. Comes with canopy cover, connector, dead-end and mounting hardware. 4 1/8" x 4 1/4" x 1 3/8".

Color codes: P (White), MB (Black)

ORDERING INFORMATION

Connector	Finish
L909	

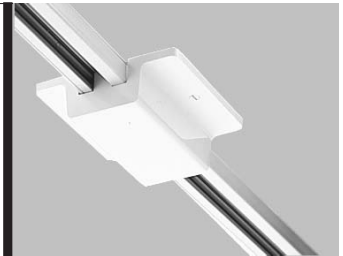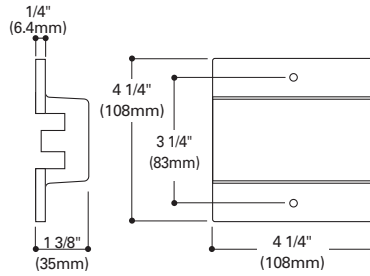

L909


L950 Cord and Plug Connector

12' three-wire cord with grounded plug. Maximum capacity 10 AMP

Color Codes: P (White), MB (Black)

ORDERING INFORMATION

Connector	Finish
L950	

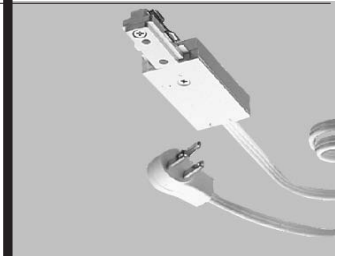

L950



L951 Wire Way Cover for Pendant Assembly Kit

For track to be wired through stem (order one for each feed point used). For use with line connectors (L901, L902, L903, L904, L905 or L906) and pendant stem kit (L992)–order separately

Color Codes: P (White), MB (Black)

ORDERING INFORMATION

Connector	Finish
L951	

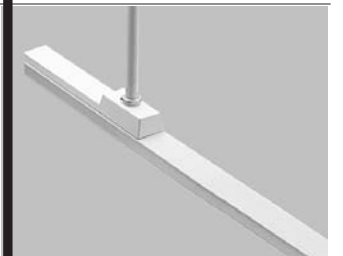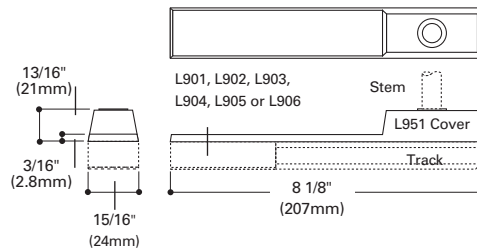

L951



L979 Conduit Continuation Kit

Consisting of one left feed and one right feed. To continue a run around obstructions. Designed to accept 1/2" trade size conduit fitting (not included).

Color Codes: P (White), MB (Black)

ORDERING INFORMATION

Connector	Finish
L979	

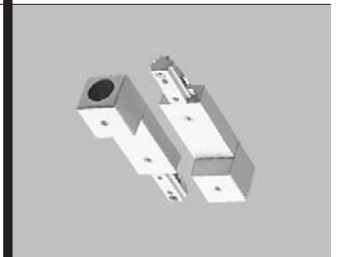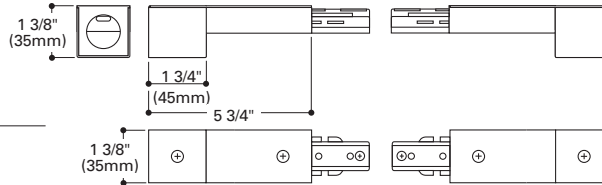

L979



L980 Live End Conduit Adapter

Designed to accept standard 1/2" trade size conduit fitting (not supplied). Use when feeding to track through surface conduit system.

Color Codes: P (White), MB (Black)

ORDERING INFORMATION

Connector	Finish
L980	

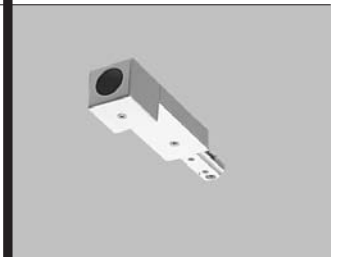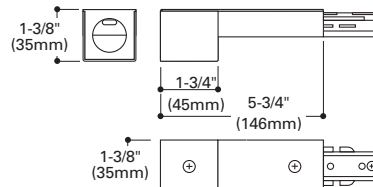


L980

DESCRIPTION

L983 T-Bar Attachment Clip

Allows track to be attached to inverted tee ceiling. Order as follows: 2 kits for 2' Trac; 2 kits for 4' Trac; 3 kits for 8' Trac and 4 kits for 12' Trac.

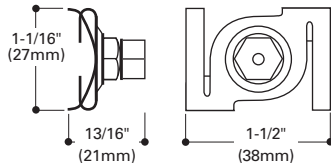

L983

L986 Mini-T Bar Clip

For mounting Trac on suspended ceilings with mini-grid (9/16" wide) system.

ORDERING INFORMATION


Connector	Finish
L98	

L992 Pendant Kit Assembly

Order 2 kits for 2' Trac; 2 kits for 4' Trac; 3 kits for 8' Trac; and 4 kits for 12' Trac. Includes one 18" threaded steel stem, canopy and mounting hardware.

L48 48" Steel Stem

For additional length with L992. Can be field cut.

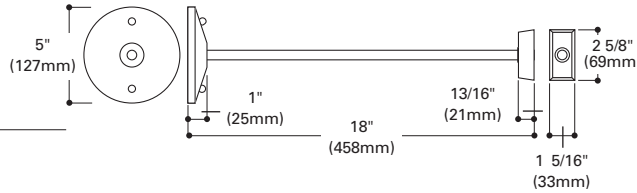

L992

Color Codes: P (White), MB (Black)


ORDERING INFORMATION

Connector	Finish
L992	

L994 Pendant Adapter

For installing pendant mounted Power-Trac on sloped ceiling. For use with L992.

Color Codes: P (White), MB (Black)

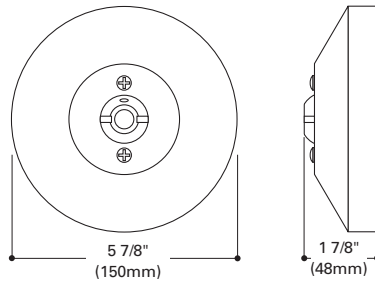

L994

ORDERING INFORMATION

Connector	Finish
L994	

Note: Specifications and Dimensions subject to change without notice.

Visit our web site at www.cooperlighting.com