

**FEATURES**


- Got Nail™ bar hangers
- Pass-N-Thru™ tool-less shortening of bar hangers
- Thermally protected
- Die-formed housing and plaster frame
- Housing may be removed from plaster frame for junction box access
- NM cable pry-outs and conduit knockouts in junction box

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.


**COMPLIANCES:** UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Feed Through, IP Rated



10-INCH SQUARE INCANDESCENT NEW CONSTRUCTION NON - IC

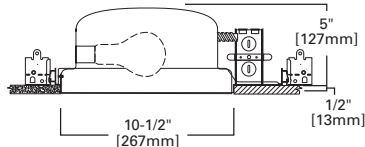

H2T

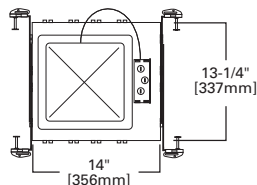

**ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY<sup>Δ</sup>**

**SAMPLE NUMBER:** H2T - 20P

Housing	Trims	Accessories
H2T=10" Square Aperture, New Construction, Non-IC, 120V Line Voltage	<p><b>Lenses and Diffusers</b></p> <p><b>120 Albalite Glass Diffuser Showerlight, 150W A19 or A21, OD: 11-5/8" [295mm] Square</b> 120P=White Splay Trim with Frosted Glass Diffuser</p> <p><b>123 Fresnel Splay Showerlight, 150W A19 or A21, OD: 11-5/8" [295mm] Square</b> 123P=White Splay Trim with Fresnel Glass Lens</p> <p><b>20 Albalite Lens, 150W A19 or A21, OD: 11-5/8" [295mm] Square</b> 20P=White Trim with Albalite Glass Lens</p> <p><b>21GP Drop Diffuser, 150W A19 or A21, OD: 11-5/8" [295mm] Square</b> 21GP=White Trim with Glass Drop Diffuser</p> <p><b>23 Fresnel Lens, 150W A19 or A21, OD: 11-5/8" [295mm] Square</b> 23P=White Trim with Fresnel Glass Lens</p> <p><b>25 All Glass Diffuser, 150W A19 or A21, OD: 11-5/8" [295mm] Square</b> 25=All Glass Frosted Diffuser</p>	<p><b>Transformer</b></p> <p><b>H277=Steps 277V Line Voltage Down to 120V</b> Fixture Operating Voltage, 300VA max., for Use with Non-IC Housings</p>

**NOTES:** Δ UL/cUL Listed for Wet Location with select trims.

10-INCH SQUARE INCANDESCENT NEW CONSTRUCTION ICAT





H2IC

**FEATURES**

- Got Nail!™ bar hangers
- Pass-N-Thru™ tool-less shortening of bar hangers
- AIR-TITE™
- Thermally protected
- Die-formed housing and plaster frame
- Housing may be removed from plaster frame for junction box access
- NM cable pry-outs and conduit knockouts in junction box

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

**COMPLIANCES:** UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Feed Through, IP Rated, AIR-TITE™ Certified ASTM E283

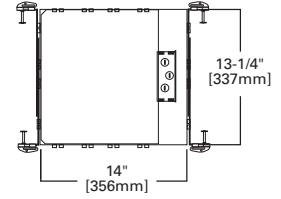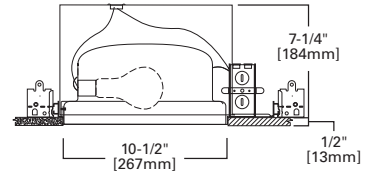

**ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY<sup>Δ</sup>**

SAMPLE NUMBER: H2IC - 20P

Housing	Trims
H2IC=10" Square Aperture, New Construction, IC, AIR-TITE™, 120V Line Voltage	<p><b>Lenses and Diffusers</b></p> <p><b>120 Albalite Glass Diffuser Showerlight, 75W A19, OD: 11-5/8" [295mm] Square</b> 120P=White Splay Trim with Frosted Glass Diffuser</p> <p><b>123 Fresnel Splay Showerlight, 75W A19, OD: 11-5/8" [295mm] Square</b> 123P=White Splay Trim with Fresnel Glass Lens</p> <p><b>20 Albalite Glass Lens, 75W A19, OD: 11-5/8" [295mm] Square</b> 20P=White Trim with Albalite Glass Lens</p> <p><b>21GP Drop Diffuser, 75W A19, OD: 11-5/8" [295mm] Square</b> 21GP=White Trim with Glass Drop Diffuser</p> <p><b>23 Fresnel Glass Lens, 75W A19, OD: 11-5/8" [295mm] Square</b> 23P=White Trim with Fresnel Glass Lens</p> <p><b>25 All Glass Diffuser, 75W A19, OD: 11-5/8" [295mm] Square</b> 25=All Glass Frosted Diffuser</p>

NOTES: Δ Not to be used in direct contact with spray foam insulation. Δ UL/cUL Listed for Wet Location with select trims.

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.



10-INCH SQUARE COMPACT FLUORESCENT NEW CONSTRUCTION NON - IC

**FEATURES**

- Got Nail™ bar hangers
- Pass-N-Thru™ tool-less shortening of bar hangers
- Compact fluorescent with thermally protected electronic ballast
- Die-formed housing and plaster frame
- Housing may be removed from plaster frame for junction box access
- Electronic ballast 120V - 277V, HPF

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

**COMPLIANCES:** UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Feed Through

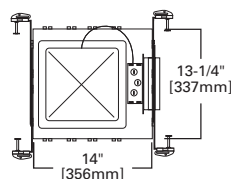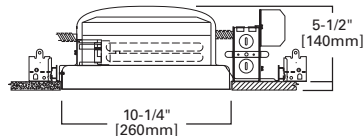

H2EF

**ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY<sup>A</sup>**

**SAMPLE NUMBER:** H2EF - 20P

Housing	Trims
<p><b>H2EF</b>=10" Square Aperture, New Construction, Non-IC, Compact Fluorescent, (2) 26W DTT CFL</p>	<p><b>Lenses and Diffusers</b>  <b>120 Albalite Glass Diffuser Showerlight, (2) 26W DTT, OD: 11-5/8" [295mm] Square</b>                      120P=White Splay Trim with Frosted Glass Diffuser</p> <p><b>123 Fresnel Splay Showerlight, (2) 26W DTT, OD: 11-5/8" [295mm] Square</b>                      123P=White Splay Trim with Fresnel Glass Lens</p> <p><b>20 Albalite Glass Lens, (2) 26W DTT, OD: 11-5/8" [295mm] Square</b>                      20P=White Trim with Albalite Glass Lens</p> <p><b>21GP Drop Diffuser, (2) 26W DTT, OD: 11-5/8" [295mm] Square</b>                      21GP=White Trim with Glass Drop Diffuser</p> <p><b>23 Fresnel Glass Lens, (2) 26W DTT, OD: 11-5/8" [295mm] Square</b>                      23P=White Trim with Fresnel Glass Lens</p> <p><b>25 All Glass Diffuser, (2) 26W DTT, OD: 11-5/8" [295mm] Square</b>                      25=All Glass Frosted Diffuser</p>

**NOTES:** <sup>A</sup> UL/cUL Listed for Wet Location with select trims. <sup>Δ</sup> DTT = Double Twin Tube Compact Fluorescent Lamp.

Housing	Wattage	Voltage	CFL Lamp Type (lamp by others)	Generic Lamp Designation	Socket	Ballast	Lamp
H2EF	(2) 26W	120V-277V	DTT (Double Triple Tube)	CFQ26W/G24q	G24q-3 (4-pin)	Electronic	Not included

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.

**10-INCH SQUARE COMPACT FLUORESCENT NEW CONSTRUCTION ICAT**





**H2EFICAT**

**FEATURES**

- Got Nail!™ bar hangers
- Pass-N-Thru™ tool-less shortening of bar hangers
- AIR-TITE™
- Compact fluorescent with thermally protected electronic ballast
- Die-formed housing and plaster frame
- Housing may be removed from plaster frame for junction box access
- Electronic ballast 120V - 277V, HPF

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

**COMPLIANCES:** UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Feed Through, UL/cUL Listed for Insulation Contact, AIR-TITE™ Certified ASTM E283

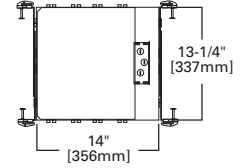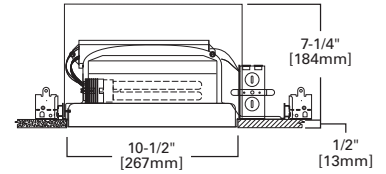

**ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY<sup>Δ</sup>**

**SAMPLE NUMBER:** H2EFICAT - 20P

 
Housing	Trims
<p><b>H2EFICAT</b>=10" Square Aperture, New Construction, IC, AIR-TITE™, Compact Fluorescent, (2) 18W DTT CFL</p>	<p><b>Lenses and Diffusers</b></p> <p><b>120 Albalite Glass Diffuser Showerlight, (2) 18W DTT, OD: 11-5/8" [295mm] Square</b>                      120P=White Splay Trim with Frosted Glass Diffuser</p> <p><b>123 Fresnel Splay Showerlight, (2) 26W DTT, OD: 11-5/8" [295mm] Square</b>                      123P=White Splay Trim with Fresnel Glass Lens</p> <p><b>20 Albalite Glass Lens, (2) 18W DTT, OD: 11-5/8" [295mm] Square</b>                      20P=White Trim with Albalite Glass Lens</p> <p><b>21GP Drop Diffuser, (2) 18W DTT, OD: 11-5/8" [295mm] Square</b>                      21GP=White Trim with Glass Drop Diffuser</p> <p><b>23 Fresnel Glass Lens, (2) 18W DTT, OD: 11-5/8" [295mm] Square</b>                      23P=White Trim with Fresnel Glass Lens</p> <p><b>25 All Glass Diffuser, (2) 18W DTT, OD: 11-5/8" [295mm] Square</b>                      25=All Glass Frosted Diffuser</p>

**NOTES:** Δ Not to be used in direct contact with spray foam insulation. Δ UL/cUL Listed for Wet Location with select trims.

Housing	Wattage	Voltage	CFL Lamp Type (lamp by others)	Generic Lamp Designation	Socket	Ballast	Lamp
H2EFICAT	(2) 18W	120V-277V	DTT (Double Triple Tube)	CFQ18W/G24q	G24q-2 (4-pin)	Electronic	Not included

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.

**120 Albalite Glass Diffuser Showerlight**




120P White Splay Trim with Frosted Glass Diffuser

**HOUSING / LAMP:**  
 H2EF: (2) 26W DTT  
 H2EFICAT: (2) 18W DTT  
 H2IC: 75W A19  
 H2T: 150W A19 or A21

**DIMENSIONS:** OD: 11-5/8" [295mm] Square

**123 Fresnel Splay Showerlight**

 


123P White Splay Trim with Fresnel Glass Lens

**HOUSING / LAMP:**  
 H2EF: (2) 26W DTT  
 H2EFICAT: (2) 18W DTT  
 H2IC: 75W A19  
 H2T: 150W A19 or A21

**DIMENSIONS:** OD: 11-5/8" [295mm] Square

**20 Albalite Glass Lens**

 


20P White Trim with Albalite Glass Lens

**HOUSING / LAMP:**  
 H2EF: (2) 26W DTT  
 H2EFICAT: (2) 18W DTT  
 H2IC: 75W A19  
 H2T: 150W A19 or A21

**DIMENSIONS:** OD: 11-5/8" [295mm] Square

**21GP Drop Diffuser**

 


21GP White Trim with Glass Drop Diffuser

**HOUSING / LAMP:**  
 H2EF: (2) 26W DTT  
 H2EFICAT: (2) 18W DTT  
 H2IC: 75W A19  
 H2T: 150W A19 or A21

**DIMENSIONS:** OD: 11-5/8" [295mm] Square

**23 Fresnel Glass Lens**

 


23P White Trim with Fresnel Glass Lens

**HOUSING / LAMP:**  
 H2EF: (2) 26W DTT  
 H2EFICAT: (2) 18W DTT  
 H2IC: 75W A19  
 H2T: 150W A19 or A21

**DIMENSIONS:** OD: 11-5/8" [295mm] Square

**25 All Glass Diffuser**

 

25 All Glass Frosted Diffuser

**HOUSING / LAMP:**  
 H2EF: (2) 26W DTT  
 H2EFICAT: (2) 18W DTT  
 H2IC: 75W A19  
 H2T: 150W A19 or A21

**DIMENSIONS:** OD: 11-5/8" [295mm] Square

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.

**10-INCH SQUARE HID NEW CONSTRUCTION NON - IC**




M200T

**FEATURES**

- Square aperture downlight for use with Metal Halide HID
- Available for use with 50W, 70W or 100W Metal Halide lamps
- Metal Halide magnetic ballast options: dual tap 120V/277V or 120V/347V
- Housing may be removed from plaster frame for junction box access
- Medium base porcelain socket with nickel plated screw shell
- Junction box positioned for straight conduit runs
- Two-piece Bar hangers included
- Insulation detector opens circuit if insulation is present
- Compatible 10" square aperture trims

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

**COMPLIANCES:** UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Feed Through

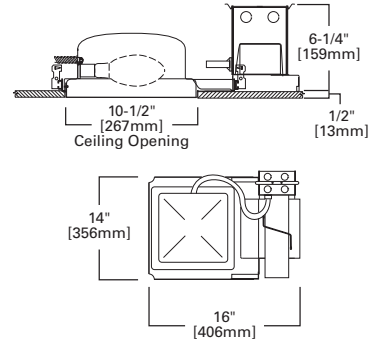

**ORDERING INFORMATION: ORDER HOUSING, BALLAST AND TRIMS SEPARATELY<sup>A</sup>**

SAMPLE NUMBER: M200T - 720 - 20P

Housing	Ballast	Trims
M200T=10" Square Aperture, New Construction, Non-IC, Magnetic Ballast, Metal Halide, HID	720=50W Metal Halide (120/277V) 728=50W Metal Halide (120V/347V) 730=70W Metal Halide (120/277V) 738=70W Metal Halide (120V/347V) 740=100W Metal Halide (120/277V) 748=100W Metal Halide (120V/347V)	<p><b>Lens</b></p> <p><b>Albalite Glass Diffuser Showerlight, 50W/75W/100W Metal Halide, OD: 11-5/8" [295mm] Square</b>                      120P=White Splay Trim with Frosted Glass Diffuser</p> <p><b>Albalite Glass Lens, 50W/75W/100W Metal Halide, OD: 11-5/8" [295mm] Square</b>                      20P=White Trim with Albalite Glass Lens</p> <p><b>All Glass Diffuser, 50W/75W/100W Metal Halide, OD: 11-5/8" [295mm] Square</b>                      25=All Glass Frosted Diffuser</p> <p><b>Drop Diffuser, 50W/75W/100W Metal Halide, OD: 11-5/8" [295mm] Square</b>                      21GP=White Trim with Glass Drop Diffuser</p> <p><b>Fresnel Glass Lens, 50W/75W/100W Metal Halide, OD: 11-5/8" [295mm] Square</b>                      23P=White Trim with Fresnel Glass Lens</p> <p><b>Fresnel Splay Showerlight, 50W/75W/100W Metal Halide, OD: 9-3/8" [238mm] Square</b>                      123P=White Splay Trim with Fresnel Glass Lens</p>

 
NOTES: <sup>A</sup> UL/cUL Listed for Wet Location with select trims.

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.

**20 Albalite Glass Lens**



20P White Trim with Albalite Glass Lens



**HOUSING / LAMP:**

 
M200T-720: 50W Metal Halide  
 M200T-730: 70W Metal Halide  
 M200T-740: 100W Metal Halide

**DIMENSIONS:** OD: 11-5/8" [295mm] Square

**21GP Drop Diffuser**



21GP White Trim with Glass Drop Diffuser



**HOUSING / LAMP:**

 
M200T-720: 50W Metal Halide  
 M200T-730: 70W Metal Halide  
 M200T-740: 100W Metal Halide

**DIMENSIONS:** OD: 11-5/8" [295mm] Square

**23 Fresnel Glass Lens**



23P White Trim with Fresnel Glass Lens



**HOUSING / LAMP:**

 
M200T-720: 50W Metal Halide  
 M200T-730: 70W Metal Halide  
 M200T-740: 100W Metal Halide

**DIMENSIONS:** OD: 11-5/8" [295mm] Square

**25 All Glass Diffuser**



25 All Glass Frosted Diffuser



**HOUSING / LAMP:**

 
M200T-720: 50W Metal Halide  
 M200T-730: 70W Metal Halide  
 M200T-740: 100W Metal Halide

**DIMENSIONS:** OD: 11-5/8" [295mm] Square

**120 Albalite Glass Diffuser Showerlight**



120P White Splay Trim with Frosted Glass Diffuser



**HOUSING / LAMP:**

 
M200T-720: 50W Metal Halide  
 M200T-730: 70W Metal Halide  
 M200T-740: 100W Metal Halide

**DIMENSIONS:** OD: 11-5/8" [295mm] Square

**123 Fresnel Splay Showerlight**



123P White Splay Trim with Fresnel Glass Lens



**HOUSING / LAMP:**

M200T-720: 50W Metal Halide  
 M200T-730: 70W Metal Halide  
 M200T-740: 100W Metal Halide

**DIMENSIONS:** OD: 11-5/8" [295mm] Square

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.