

DESCRIPTION

Adjustable reflector designed for use with IC or Non-IC AIR-TITE™ 3" Halo small aperture line and low voltage housings. Trim ring is available in multiple finishes to match interior decor. Reflector trim uses MR16 low voltage or GU10 line voltage lamps ideal for accent and task lighting. Trim offers 35° tilt, and 360° orientation within housing.

Catalog #		Type
Project		
Comments		Date
Prepared by		

SPECIFICATION FEATURES

Cast aluminum trim ring and spun aluminum reflector are available in multiple designer finishes. Three pressure springs ensure positive retention in housing.

Trim includes soft focus cover glass lens for a smooth beam pattern. (Lamps that have integral glass lens do not require use of the cover glass supplied with this trim).

3004 is designed for use with the following Halo H3 small aperture housings:


- Line Voltage Housing (for 120V GU10 lamps).

H36ICAT	50W	IC Air-Tite Housing
H36TAT	50W	Non-IC Air-Tite Housing
H36RTAT	50W	Non-IC Air-Tite Remodel Housing
- Low Voltage Housing (for 12V MR16 lamps).

H36LVICAT	50W	IC Air-Tite Housing
H36LVTAT	50W	Non-IC Air-Tite Housing
H36LVRTAT	50W	Non-IC Air-Tite Remodel Housing
H36LVTAT277	50W	Non-IC Air-Tite Housing, 120/277V
H36LVRTAT277	50W	Non-IC Air-Tite Remodel Housing, 120/277V
- Line Voltage Housing (for 120V GU10 lamps).

H38ICAT	50W	IC Air-Tite Housing
---------	-----	---------------------
- Low Voltage Housing (for 12V MR16 lamps).

H38LVICAT	50W	IC Air-Tite Housing
-----------	-----	---------------------

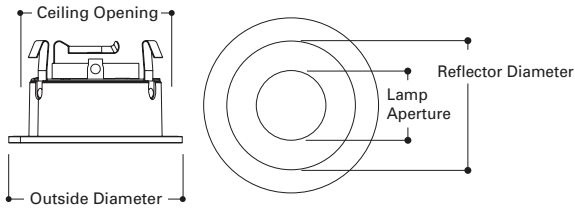

Lamp Aperture: 2" [51mm]
 Reflector Diameter: 3" [75mm]
 Ceiling Opening: 3-3/4" [95mm]
 Outside Diameter: 4-1/4" [108mm]

ORDERING INFORMATION

SAMPLE NUMBER: 3004WHC

Order housing and trims separately.

Trim	Finish
3004= 3" Adjustable Reflector Trim	WHC =White with Specular Clear Reflector SN =Satin Nickel with Satin Nickel Reflector TBZ =Tuscan Bronze with Tuscan Bronze Reflector WHH =White with Haze Reflector WHW =White with White Reflector



3004WHH
White with Haze Reflector



3004WHW
White with White Reflector



3004TBZ
Tuscan Bronze with Tuscan Bronze Reflector



3004SN
Satin Nickel with Satin Nickel Reflector



3004WHC
White with Specular Clear Reflector

3004

3" Adjustable Reflector Trim

3" TRIMS