

## DESCRIPTION

Regressed glass lens adjustable square baffle shower light is designed for use with IC or Non-IC AIR-TITE™ 3" Halo small aperture line and low voltage housings. This die-cast aluminum trim is available in multiple finishes to match interior decor. Trim uses low voltage MR16 or GU10 line voltage lamps ideal for accent and task lighting. Trim offers 15° tilt and integral 360° lamp holder rotation with locking thumbscrew. Wet location listed for use in showers. The trim constructions allows use with the Halo H3 Series of standard round aperture housings.


Catalog #		Type
Project		
Comments		Date
Prepared by		

## SPECIFICATION FEATURES

Regressed lens fixed glass square baffle shower trim available in Matte White, Black, Satin Nickel, or Tuscan Bronze finishes with Black Baffle and regressed clear lens. White trim also available with White Baffle. Lampholder can be rotated 360° independently of trim. Lampholder also offers 15° tilt. Three pressure springs ensure positive retention in housing.

3012 is designed for use with the following Halo H3 (standard round) small aperture housings:

- Line Voltage Housing (for 120V GU10 lamps).
  - H36ICAT 50W IC Air-Tite Housing
  - H36TAT 50W Non-IC Air-Tite Housing
  - H36RTAT 50W Non-IC Air-Tite Remodel Housing
- Low Voltage Housing (for 12V MR16 lamps).
  - H36LVICAT 50W IC Air-Tite Housing
  - H36LVTAT 50W Non-IC Air-Tite Housing
  - H36LVRTAT 50W Non-IC Air-Tite Remodel Housing
  - H36LVTAT277 50W Non-IC Air-Tite Housing, 120/277V
  - H36LVRTAT277 50W Non-IC Air-Tite Remodel Housing, 120/277V
- Line Voltage Housing (for 120V GU10 lamps).
  - H38ICAT 50W IC Air-Tite Housing
- Low Voltage Housing (for 12V MR16 lamps).
  - H38LVICAT 37W IC Air-Tite Housing

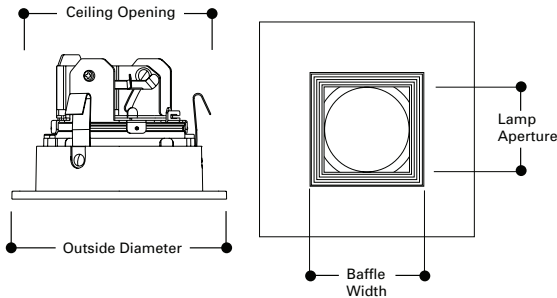

Lamp Aperture: 2" [51mm]  
 Baffle Width: 2 1/4" [57mm]  
 Ceiling Opening (round): 3 3/4" [95mm]  
 Outside Dimension: 4 1/4" Square [108mm]


## ORDERING INFORMATION

**SAMPLE NUMBER: 3012WHBB**  
 Order housing and trims separately.

Trim	Finish
3012= 3" Lensed Showerlight Adjustable Baffle Square Trim	<b>BKBB</b> =Black with Black Baffle <b>SNBB</b> =Satin Nickel with Black Baffle <b>TBZBB</b> =Tuscan Bronze with Black Baffle <b>WHBB</b> =White with Black Baffle <b>WHWB</b> =White with White Baffle



**3012WHWB**  
White with White Baffle

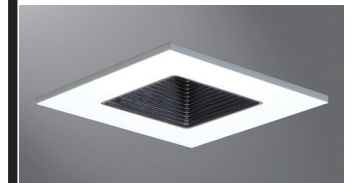

**3012WHBB**  
White with Black Baffle



**3012BKBB**  
Black with Black Baffle



**3012SNBB**  
Satin Nickel with Black Baffle



**3012TBZBB**  
Tuscan Bronze with Black Baffle

## 3012

**3" Lensed Showerlight Adjustable Baffle Square Trim**



3" TRIMS