

6-INCH INCANDESCENT SHALLOW REMODEL HOUSING IC




H27RICT

FEATURES

- Quick Connect wiring connectors included in junction box
- NM cable pry-outs and conduit knockouts in junction box
- Remodel springs accommodate 1/2" and 5/8" ceiling material
- Thermally protected
- Die-formed housing
- Shallow ceiling housing

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

COMPLIANCES: UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaires, UL/cUL Listed for Insulation Contact, IP Rated

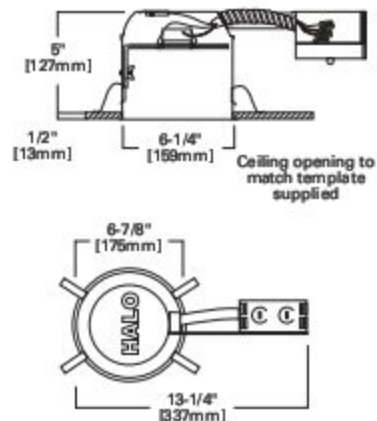

ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY*

SAMPLE NUMBER: H27RICT - 310W

Housing

H27RICT=6" Aperture, Remodel, IC, Shallow Ceiling, 120V Line Voltage

Trims

Adjustables

420 Regressed Eyeball - 30° Tilt, 60W PAR30, 60W PAR30L, 60W BR30, OD: 7-1/4" [184mm]
 420P=White Trim with White Eyeball and Black Baffle
 420PB=Polished Brass Trim with Polished Brass Eyeball and Black Baffle
 420W=White Trim with White Eyeball and White Baffle

74 Eyeball - 30° Tilt, 75W PAR30, OD: 8" [203mm]
 74P=White Trim and Eyeball

77 Adjustable Eyeball - 30° Tilt, 50W PAR20, 75W R20, OD: 8" [203mm]
 77P=White Trim with White Eyeball

78 Eyeball - 30° Tilt, 65W BR30, 75W PAR30L, 75W R30, OD: 8" [203mm]
 78B=Satin Brass Trim with Satin Brass Eyeball
 78P=White Trim with White Eyeball
 78PAT=White Trim with White Eyeball - AIR-TITE™ Trim
 78PB=Polished Brass Trim with Polished Brass Eyeball
 78SN=Satin Nickel Trim with Satin Nickel Eyeball
 78TBZ=Tuscan Bronze Trim with Tuscan Bronze Eyeball

90 Double Bubble Adjustable - 60° Tilt, 150W PAR38, OD: 8" [203mm]
 90P=White Trim and Eyeball

Baffles

310 Collex® Baffle, 50W PAR30, 65W BR30, 75W PAR30L, 310W, P, SN, TBZ - OD: 7-1/4" [184mm], 310WG, PG - OD: 8" [203mm]
 310P=White Trim with Black Collex® Baffle
 310PG=Wide White Trim Ring with Black Collex® Baffle
 310SN=Satin Nickel Trim with Black Collex® Baffle
 310TBZ=Tuscan Bronze Trim with Black Collex® Baffle
 310W=White Trim with White Collex® Baffle
 310WG=Wide White Trim Ring with White Collex® Baffle

312 Collex® Baffle, 50W PAR30, 65W BR30, OD: 7-1/4" [184mm]
 312P=White Trim with Black Baffle
 312W=White Trim with White Baffle

353 Metal Baffle, 50W PAR30, 65W BR30, 75W PAR30L, OD: 7-1/4" [184mm]
 353SN=Satin Nickel Trim with Satin Nickel Baffle
 353TBZ=Tuscan Bronze Trim with Tuscan Bronze Baffle

Accessories

Designer Trim Rings¹

TRM6C=Chrome
 TRM6B=Black Metal
 TRM6P=White Metal
 TRM6SN=Satin Nickel
 TRM6TBZ=Tuscan Bronze
 TRM7MB=Black Plastic

NOTES: Δ Not to be used in direct contact with spray foam insulation. Δ UL/cUL Listed for Wet Location with select trims. 1. Compatible with 310, 312, 420, 426

Lenses and Diffusers

170 Alabite Lens with Reflector, 40W A19, OD: 8" [203mm]
 170P=White Trim with Frosted Alabite Glass Lens
 170PS=White Trim with Frosted Alabite Glass Lens, Wet Location Listed and AIR-TITE™

171 Drop Opal Lens with Reflector, 40W A19, OD: 8" [203mm]
 171P=White Trim with Drop Opal Glass Lens
 171PS=White Trim with Drop Opal Glass Lens, Wet Location Listed and AIR-TITE™

172 Dome Lens with Reflector, 50W PAR30, 60W A19, OD: 7-3/4" [197mm]
 172PS=White Trim with Frosted Glass Dome, Wet Location Listed and AIR-TITE™
 172SNS=Satin Nickel Trim with Frosted Glass Dome, Wet Location Listed and AIR-TITE™
 172TBZS=Tuscan Bronze Trim with Frosted Glass Dome, Wet Location Listed and AIR-TITE™

Open

300 Open Trim with Socket Support, 60W BR30, 75W PAR30, OD: 7-1/4" [184mm]
 300P=White Trim Ring
 300SN=Satin Nickel Trim Ring
 300TBZ=Tuscan Bronze Trim Ring

328 White Splay Trim, 50W PAR30, 65W BR30, 75W PAR30L, OD: 7-3/4" [197mm]
 328P=White Splay Trim

Reflectors

426 Reflector Cone, 50W PAR30, 65W BR30, 75W R30, 75W PAR30L, OD: 7-1/4" [184mm]
 426=White Trim Ring with Clear Specular Reflector Cone
 426CG=White Trim with Champagne Gold Reflector Cone
 426H=White Trim with Haze Reflector Cone
 426MB=White Trim with Specular Black Reflector Cone
 426RG=White Trim with Residential Gold Reflector Cone
 426SN=Satin Nickel Trim with Satin Nickel Reflector Cone
 426TBZ=Tuscan Bronze Trim with Tuscan Bronze Reflector Cone