


Power lock industrial grade locking devices

Product description


4-pole, 5-wire grounding
60A, 600V/AC
Non-NEMA

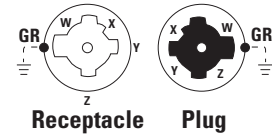

26527



26526

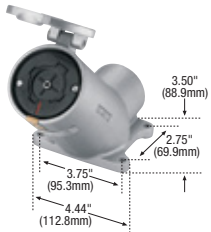

26521



26514A

Industrial grade plugs & connectors



Rating	A	V/AC	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.	
60	600		Armored	0.75-1.25" (19.1-31.8mm)	Y	□ 26515	□ 26514	•
			Armored w/ rubber bushing in cable clamp	0.75-1.25" (19.1-31.8mm)	Y	□ 26526	□ 26527	•
			Armored, accepts ring terminals	N/A	BK	□ 26515AM ^A	—	•

^A RU Listed only

Note: Bushing versions supplied with 3 sizes of rubber bushings

Industrial grade receptacles



Rating	A	V/AC	Description	Color	Single receptacle	
60	600		In cast aluminum cover w/ weather protective life lid	BK	□ 26520	•
			In angled cast aluminum cover w/ weather protective life lid	BK	□ 26521**	•

** Not CSA certified

Industrial grade flanged inlets & outlets



Rating	A	V/AC	Description	Cord diameter	Color	Flanged inlet	Flanged outlet	
60	600		Armored flange	0.75-1.25" (19.1-31.8mm)	Steel	□ 26515A	□ 26514A	•

Dimensional information:
C-82, C-83

Plug & connector specification information:

Power lock: C-94

Receptacle specification information:

Power lock: C-95

Inlet specification information:

Power lock: C-94

Color information:

BK (Black), Y (Yellow)



Compliances, specifications and availability are subject to change without notice.

Indicates NAFTA compliant - Page Q-32