

# C-FL-A-RTF4/RTS4 Series

LED High-Output Floodlight  
Replaces 400W PSMH

**C-LITE**  
LED LIGHTING BY CREE



## UP TO 27,400 LUMENS - OUR BRIGHTEST LED FLOODLIGHT EVER!

High-Output LED Floodlight is two times brighter than previous models (up to 24,700 lumens).

### EFFICIENT

- Uses 33% less energy than 400W PSMH

### RECOMMENDED USE

- Building facades
- Security
- Uplighting for signs & displays

### FLEXIBLE

- Wide (98°) and narrow (36°) beam angles
- Multiple color temperatures to meet any application

### INPUT VOLTAGE

- Universal (120V through 277V Operation)


CERTIFICATIONS:



US: [c-lite.com](http://c-lite.com)

T (800) 236-6800 F (262) 504-5415

# C-FL-A-RTF4/RTS4 Series

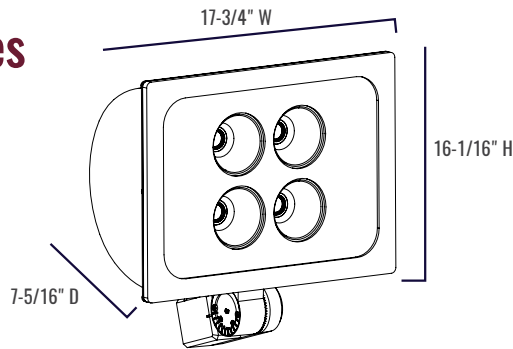

## Series overview

DIMENSIONS	PRODUCT WEIGHT	MOUNTING HEIGHT	SPACING
7-5/16" D x 17-3/4" W x 16-1/16" H	27 lbs.	20 to 30 feet	N/A


## Fixture Specifications

<b>HOUSING</b>	Low-copper, die-cast aluminum housing and lens frame Dark bronze polyester powder-coat finish
<b>LENS ASSEMBLY</b>	Tempered glass lens is thermal, shock and impact resistant Polycarbonate reflector
<b>MOUNTING</b>	Includes 2" adjustable fitter

## Electrical Performance

OPERATING MINIMUM	LIFESPAN <small>L<sub>70</sub> AT 25°C (77°F)</small>	POWER FACTOR	TOTAL HARMONIC DISTORTION	DIMMABLE
-40°C (-40°F)	Estimated >100,000 Hours	< 0.9	< 20%	No
<b>INPUT VOLTAGE</b>	<b>120V</b>	<b>208V</b>	<b>240V</b>	<b>277V</b>
<b>CURRENT DRAW (Amps)</b>	1.95A	1.13A	0.98A	0.85A

## CORRELATED COLOR TEMPERATURE (CCT)

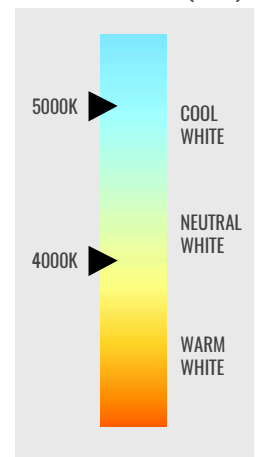

## Warranty and Certifications

Warranty	UL Listed	Energy Star
5-Year Limited*	Wet Locations	N/A

# C-FL-A-RTF4/RTS4 Series

## Output Specifications

SKU	Light Output	Color Temp (see chart)	Power Consumption	Color Accuracy	Distribution	Replaces
C-FL-A-RTF4-26L-50K-DB	26,300 Lumens	Cool White (5000K)	234W	≥ 70 CRI	98° Flood (Wide)	400W PSMH
C-FL-A-RTF4-26L-40K-DB	26,500 Lumens	Neutral White (4000K)	234W	≥ 70 CRI	98° Flood (Wide)	400W PSMH
C-FL-A-RTS4-23L-50K-DB	22,800 Lumens	Cool White (5000K)	234W	≥ 70 CRI	36° Flood (Narrow)	400W PSMH
C-FL-A-RTS4-23L-40K-DB	22,900 Lumens	Neutral White (4000K)	234W	≥ 70 CRI	36° Flood (Narrow)	400W PSMH

## Accessories



**Photocell - Button, 120V/208V/240V/277V**  
**SKU: C-ACC-A-PCCELL-LV (120V)**  
**C-ACC-A-PCCELL-HV (208V/240V/277V)**  
**USE:** Photocell is field installed.