

Bracket Required Trims

Compatible housings and maximum wattages listed



RM30 (Shown)
Black Stepped Baffle
RM30W White Stepped Baffle
RMC30W White Stepped Baffle
(48 PK Only)

Bracket Required
7-3/8" O.D. (187 mm)

Lamp	IC	Non-IC
CR1 / QL6 / CRR1		
PAR30	50W	50W
R/BR30	50W	100W
R150ASIC		
PAR30	75W	
R/BR30	75W	
PR75ASIC		
PAR30	75W	75W
R/BR30	75W	75W
R10		
PAR30		75W
R/BR30		75W
PRR75ICX		
PAR30	75W	75W
R/BR30	75W	75W
R9		
PAR30		75W
R/BR30		75W
RR9		
PAR30L		75W
R/BR30		75W



RM40W (Shown)
White Stepped Baffle
RM40 Black Stepped Baffle

Bracket Required
7-3/8" O.D. (187 mm)


Lamp	IC	Non-IC
CR1 / QL6 / CRR1		
R/BR40		150W
PAR38		150W
R150ASIC		
PAR30	75W	
R/BR30	75W	
R/BR40	100W	
PAR38	90W	
R10		
PAR38		120W
R/BR40		150W



RMS30CLR (Shown)
Clear Reflector
RMS30GLD Gold Reflector
RMS30BLK Black Reflector
RMS30WHT White Reflector

Bracket Required
7-3/8" O.D. (187 mm)

Lamp	IC	Non-IC
CR1 / QL6 / CRR1		
R/BR30	75 W	100W
PAR30	50W	75W
R150ASIC		
PAR30	75W	
R/BR30	75W	
PR75ASIC		
PAR30	50W	50W
R/BR30	75W	75W
R10		
PAR30		75W
R/BR30		75W
PRR75ICX		
PAR30	75W	75W
R/BR30	75W	75W
R9		
PAR30		75W
R/BR30		75W
RR9		
PAR30		75W
R/BR30		75W

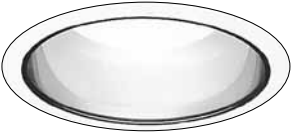

RMS40GLD (Shown)
Gold Reflector
RMS40CLR Clear Reflector
RMS40BLK Black Reflector
RMS40WHT White Reflector

Bracket Required
7-3/8" O.D. (187 mm)

Lamp	IC	Non-IC
CR1 / QL6 / CRR1		
PAR38		150W
R/BR40		150W
R150ASIC		
PAR38	90W	
R/BR40	100W	
R10		
R/BR40		150W
PAR38		150W



RBA100BLK Black Cone
RBA100CLR Clear Cone
RBA100WHT White Cone
RBA100TBZ* Tuscan Bronze Cone
RBA100CBN* Coffee Bean Cone
RBA100SPM* Soft Platinum Cone
RBA100RCP* Rustic Copper Cone
RBA100MCA* Mocha Cone

*Flange matches trim finish
Socket Supporting
7-3/8" O.D. (187 mm)

Lamp	IC	Non-IC
CR1/QL6/CRR1		
A19	75W	75W
A21		150W
R/BR40	90W	150W
PAR38	90W	150W
R/BR30	75W	75W
PAR30L	75W	75W
PAR30	50W	75W
R150ASIC		
BR40	150W	
PAR38	120W	
R/BR30	100W	
R/BR40	100W	
A19	100W	
CR1NB/ QL6NB / CRR1NB		
A19	75W	75W
A21		150W
R/BR40	90W	150W
PAR38	90W	150W
R/BR30	75W	75W
PAR30L	75W	75W
PAR30	50W	75W



RMA100CLR (Shown)
Clear Specular Reflector
RMA100BLK Black Reflector

Bracket Required
7-3/8" O.D. (187 mm)

Lamp	IC	Non-IC
CR1 / QL6 / CRR1		
A19	100W	
R150ASIC		
A19	100W(others)	
	75W (RMA100BLK)	
R10		
A19		100W (RMA100BLK)
A21		150W (others)



RMA101 (Shown)
Clear Black Baffled Reflector
RMA101W Clear White Baffled Reflector

Bracket Required
7-3/8" O.D. (187 mm)

Lamp	IC	Non-IC
CR1 / QL6 / CRR1		
A19		100W
R150ASIC		
A19	40W	
R10		
A19		100W