

# QL5 & QL5QP & QL5NBQP

## 5" Quicklights® Recessed Incandescent Housing

New Construction - IC & Non-IC/AirSeal™

Catalog Number: \_\_\_\_\_

Type: \_\_\_\_\_

Project: \_\_\_\_\_



### Description

For new construction. Thermally protected, labor savings recessed housing for IC, NON-IC and AirSeal™ applications. Thermal insulation may cover fixture in IC applications. Non-IC applications require that thermal insulation be maintained at a minimum distance of three inches from housing. Engineered impact resistant polymer plaster frame includes pre-positioned nails for fast installation. Fixture is UL listed for through branch wiring and damp location.

### Features

- UL Listed for direct contact with thermal insulation for IC applications or Non-IC applications when insulation is a minimum of three inches from housing.
- Labor saving, impact resistant polymer plaster frame includes nails for fast installation.
- 4 sets of BH3 bar hangers are included per standard case of product.
- Housing adjusts vertically in plaster frame to allow for variations in ceiling thickness.
- IC - 75W Maximum, Non-IC - 75W Maximum
- Fixture is provided with stepless adjustable socket mounting plate which can be removed for full reflector socket supporting trims.
- Thermal protection standard.
- Fixture meets Washington State Energy Code (W.S.E.C.) requirements.
- UL Listed for Through-Branch Circuit Wiring and Damp Locations.
- AirSeal rated to ASTM E283.



## CATALOG SYSTEM AND OPTIONS

SAMPLE CATALOG NUMBER: QL5-R136

### Housing

### Trims (choose one)

QL5  
QL5QP  
QL5NBQP

R238 Black Baffle\*  
R238W White Baffle\*  
R240 Black Baffle  
R240W White Baffle  
R130C Specular Clear Reflector  
R130BK Black Reflector  
R130G Gold Reflector  
R130W White Reflector  
R249C Specular Clear Reflector\*  
R249G Gold Reflector\*  
R249BK Black Reflector\*  
R132W White Open Trim\*  
R132PB Polished Brass Open Trim\*  
R120W White Reflector Cone\*  
R120 Black Reflector Cone\*

R136 Drop Round Shower Trim  
R135 Albalite Shower Trim  
R133W PAR30 Eyeball White  
R133PB PAR30 Eyeball Polished Brass  
R133BRN PAR30 Eyeball Brushed Nickel  
R138BK PAR20 Eyeball White w/ Black Baffle  
R138W PAR 20 Eyeball White w/White Baffle  
R138PB PAR 20 Eyeball White w/White Baffle  
R221 White Eyeball  
R221PB Polished Brass Eyeball  
R248 Wall Wash\*  
R134W Recessed Gimbal White Baffle\*  
R134BK Recessed Gimbal Black Baffle\*  
R134WHT Recessed Gimbal White Reflector\*

R134C Recessed Gimbal Clear Reflector\*  
R134PB Recessed Gimbal Polished Brass Reflector\*  
R134BRN Recessed Gimbal\* Brushed Nickel Reflector\*  
R139W Surface Gimbal Clear Reflector\*  
R139PB Surface Gimbal Polished Brass Reflector\*  
R139BRN Surface Gimbal Brushed Nickel\*  
5B30 Black Baffle  
5B30W White Baffle  
5B101 Clear Reflector with Black Baffle  
5B101W Clear Reflector with White Baffle  
5A100C Clear Multiplier  
5A100G Gold Multiplier

\*Bracket required for these trims.

Custom colors are available on select trims. Please see the Decorative Trims link at [www.caprilighting.com](http://www.caprilighting.com) to download brochure and for further details.

## SPECIFICATIONS

1. **Housing** - Constructed of painted white .032 aluminum. Adjusts vertically in plaster frame to accommodate ceilings 1/2" to 1-1/2" thick. Housing can be pulled through plaster frame for access to junction box. Accommodates lamps up to 75 watts, depending on trim used and application to direct contact of ceiling insulation. Ceiling opening of 5-5/16".

2. **Plaster Frame** - High impact, high temperature, lightweight injection-molded single piece plaster frame. Self-leveling frame ensures accurate positioning. Two preinstalled double-headed nails fasten plaster frame to joist. Double-headed 16 penny nails permit easy repositioning if required. May also be used with 27" flat BH3 bar hangers.

3. **Socket** - Medium base screw shell porcelain socket, mounts with snap-in clips to top of trim. Socket clipped to side of housing during shipment to protect from damage.

4. **Junction Box** - Integral non-conductive junction box with four pry-out knockouts for non-metallic sheathed cable (Romex) and two 1/2" conduit pry-outs. Captive door hinges upward and stays open to permit fast electrical connections. Romex connectors not required. Staple Romex to joist within 8 inches of junction box. Meets all safety requirements of UL and the N.E.C.

5. **IC & Non-IC** - Housing is UL Listed for direct contact with thermal insulation. For Non-IC applications higher wattages maybe used. Insulation must be kept three inches away from housing in Non-IC applications.

6. **Thermal Protection** - Standard thermal protection device inside housing automatically takes fixture out of service if temperature becomes excessive from overamping, or wrong lamp/trim combination.

7. **c/UL Listed** for Damp Locations and Through Branch Wiring, 4 in/4 out.

8. **AirSeal** rated to ASTM E283.



### Accessories (Order separately)

Pair 27" Flat Bar Hangers ..... **BH3**

**Options**

Quick Plug..... **QP**

## DIMENSIONS

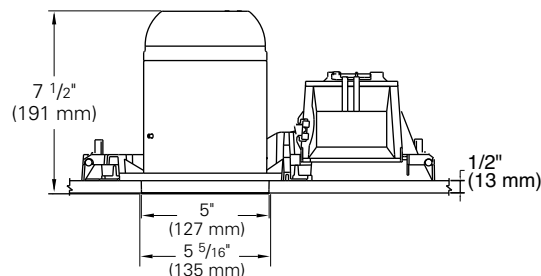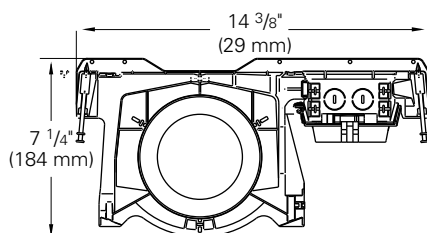

NOTE: Shown with IC Trim

REV. 01/08

# 5" TRIMS



**R238** (Shown)  
Black Baffle Trim

**R238W** White Baffle Trim  
Bracket Required  
5 3/4" O.D. (146 mm)

Housing	Lamp	IC	Non-IC
QL5	PAR20	50W	50W
CR5	PAR30L	75W	75W
CRR5	R30	75W	75W
R5	PAR20	50W	
	PAR30	75W	
	R30	75W	



**R240** (shown)  
Black Baffle Trim

**R240W**  
White Baffle Trim  
Socket Supporting  
6 3/8" O.D. (162 mm)

Housing	Lamp	IC	Non-IC
QL5	PAR30	50W	75W
CR5	R30	75W	
CRR5	BR30	75W	



**R130C** (Shown)  
Specular Clear Reflector

**R130BK** Black Reflector  
**R130G** Gold Reflector  
**R130W** White Reflector  
Socket Supporting  
6 3/8" O.D. (162 mm)


Housing	Lamp	IC	Non-IC
QL5	PAR30	50W	75W
CR5	R30	50W	75W
CRR5	R30	50W	75W



**R249C** (Shown)  
Specular Clear Reflector

**R249G** Gold Reflector  
**R249BK** Black Reflector  
Bracket Required  
5 3/4" O.D. (146 mm)

Housing	Lamp	IC	Non-IC
QL5	PAR20	50W	50W
CR5	R20	50W	50W
CRR5	R20	50W	50W
R5	PAR20	50W	
	R20	50W	

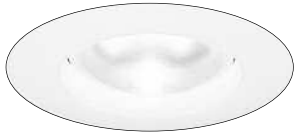

**R132W** (Shown)  
White Open Trim

**R132PB**  
Polished Brass Open Trim  
Bracket Required  
6 3/8" O.D. (162 mm)

Housing	Lamp	IC	Non-IC
QL5	PAR30	75W	75W
CR5	R30	75W	75W
CRR5	R30	75W	75W
R5	PAR30	75W	
	R30	75W	



**R120W** (Shown)  
White Reflector Cone

**R120**  
Black Reflector Cone  
Bracket Required  
6 3/8" O.D. (162 mm)

Housing	Lamp	IC	Non-IC
QL5	PAR20	50W	50W
CR5	R20	50W	50W
CRR5	R20	50W	50W
R5	PAR20	50W	
	R20	50W	



**R136**  
Drop Round Shower Trim

Socket Supporting  
6 3/8" O.D. (162 mm)

Housing	Lamp	IC	Non-IC
QL5	A19	60W	
CR5	PAR30	50W	75W
CRR5	PAR30	50W	75W
R5	A19	60W	
	PAR30	75W	



**R135**  
Albalite Shower Trim

Socket Supporting  
6 3/8" O.D. (162 mm)


Housing	Lamp	Non-IC
QL5	A19	60W
CR5	PAR30	75W
CRR5	PAR30	75W
R5	A19	40W



**R133W** (shown)  
White Par 30 Eyeball

**R133PB**  
Par 30 Eyeball Polished Brass  
**R133BRN**  
Par 30 Eyeball Brushed Nickel  
Socket Supporting  
6 3/8" O.D. (162 mm)

Housing	Lamp	IC	Non-IC
QL5	PAR30	50W	75W
CR5	PAR30	50W	75W
CRR5	PAR30	50W	75W
R5	PAR30	75W	

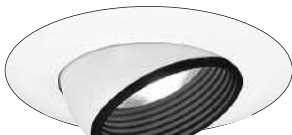

**R138BK**  
Par 20 Eyeball (shown)

**R138W**  
Par 20 Eyeball  
White with White Baffle  
**R138PB**  
Par 20 Eyeball  
Polished Brass with Black Baffle  
Socket Supporting

Housing	Lamp	IC	Non-IC
QL5	PAR20	50W	50W
CR5	PAR20	50W	50W
CRR5	PAR20	50W	50W
R5	PAR20	50W	



**R221**  
White Eyeball

**R221PB**  
Polished Brass Eyeball  
Socket Supporting  
7" O.D. (178 mm)

Housing	Lamp	IC	Non-IC
QL5	PAR20	50W	50W
CR5	R20	50W	50W
CRR5	R20	50W	50W
R5	PAR20	50W	
	R20	50W	



**R248**  
Wall Wash

Bracket Required  
5-3/4" O.D. (146 mm)

Housing	Lamp	IC	Non-IC
QL5	PAR20	50W	50W
CR5	R20	50W	50W
CRR5	R20	50W	50W
R5	R20	50W	



**R139W** (shown)  
Surface Gimbal, Clear Reflector

**R139PB**  
Surface Gimbal,  
Polished Brass Reflector  
Socket Supporting  
6 3/8" O.D. (162 mm)

Housing	Lamp	IC	Non-IC
QL5	PAR30	50W	75W
CR5	PAR30	50W	75W
CRR5	PAR30	50W	75W
R5	PAR30	75W	



**R134W** (shown)  
Recessed Gimbal, White Baffle

**R134BK**  
Recessed Gimbal, Black Baffle  
Socket Supporting  
6 3/8" O.D. (162 mm)

Housing	Lamp	IC	Non-IC
QL5	PAR30	50W	75W
CR5	PAR30	50W	75W
CRR5	PAR30	50W	75W
R5	PAR30	75W	



**R134WHT** (shown)  
Recessed Gimbal, White Reflector

**R134C**  
Recessed Gimbal, Clear Reflector  
**R134PB**  
Recessed Gimbal, Polished Brass Reflector

**R134BRN** Recessed Gimbal Brushed Nickel Reflector  
Socket Supporting  
6 3/8" O.D. (162 mm)

Housing	Lamp	IC	Non-IC
QL5	PAR30	50W	75W
CR5	PAR30	50W	75W
CRR5	PAR30	50W	75W
R5	PAR30	75W	

Custom colors are available on select trims. Please see the Decorative Trims link at [www.caprilighting.com](http://www.caprilighting.com) to download brochure and for further details.

Capri Lighting reserves the right to make changes without notice. ©2008

\* Canadian product offering specifications and wattages may vary from those shown.

This product may be covered by one or more of the following U.S. Patents: #4,408,262, #4,703,406, #4,723,747, #4,910,651, #5,057,979. Other U.S. or Foreign Patents may apply.