

# POWER TOOLS


**GUARANTEED TOUGH.**

## 1/2" VSR DRILLS



SPECIFICATIONS	DWD215G	DWD210G	DW246	DW245	DW235G
Chuck Size	1/2"	1/2"	1/2"	1/2"	1/2"
Amps	10.0 Amps	10.0 Amps	7.8 Amps	7.8 Amps	7.8 Amps
No Load Speed	0-1,200 rpm	0-1,200 rpm	0-600 rpm	0-600 rpm	0-850 rpm
Max Watts Out	980 W	980 W	600 W	600 W	600 W
Keyless Chuck	Yes	No	Yes	No	No
Capacity in Wood (Spade Bit)	1-1/2"	1-1/2"	1-1/2"	1-1/2"	1-1/2"
Capacity in Wood (Auger Bit)	1-1/2"	1-1/2"	1-1/2"	1-1/2"	1-1/8"
Capacity in Steel (Twist Bit)	1/2"	1/2"	1/2"	1/2"	1/2"
Capacity in Steel (Hole Saw)	2"	2"	2-3/4"	2-3/4"	2"
Tool Weight	5.2 lbs	4.9 lbs	4.4 lbs	4.4 lbs	4.2 lbs

## DWD460

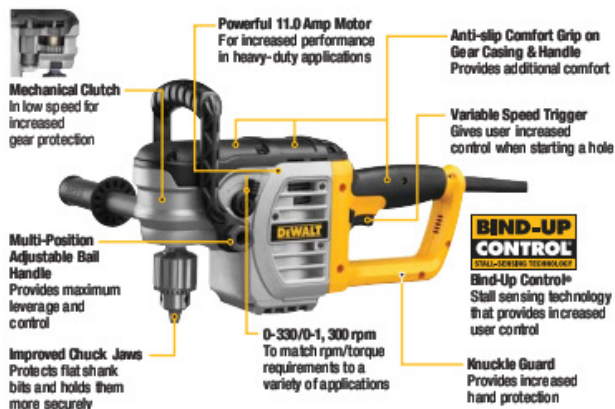

## ELECTRONIC CLUTCH DRILLS



SPECIFICATIONS	DWD220	DW249
Chuck Size	1/2"	1/2"
Amps	10.5 Amps	7.8 Amps
No Load Speed	0-1,200 rpm	0-600 rpm
Max Watts Out	1100 W	600 W
Keyless Chuck	No	No
E-Clutch	Yes	Yes
Capacity in Wood (Spade Bit)	1-1/2"	1-1/2"
Capacity in Wood (Auger Bit)	1-1/2"	1-1/2"
Capacity in Steel (Twist Bit)	1/2"	1/2"
Capacity in Steel (Hole Saw)	2"	2-3/4"
Tool Weight	4.9 lbs	4.5 lbs

## 1/2" SPECIALTY DRILLS



SPECIFICATIONS	DWD460/K	DW124/K	DW120K	DW130V	DW140
Chuck Size	1/2"	1/2"	1/2"	1/2"	1/2"
Amps	11.0 Amps	11.5 Amps	7.0 Amps	9.0 Amps	7.0 Amps
No Load Speed	0-330/0-1,300 rpm	300/1,200 rpm	400/600/900 rpm	0-550 rpm	600 rpm
Max Watts Out	1015 W	850 W	580 W	600 W	580 W
Kit Box	No/Yes	No/Yes	Yes	No	No
Mechanical Clutch	Yes and Bind-Up Control®	Yes	No	No	No
Capacity in Wood (Auger Bit)	1-1/2"	1-1/2"	1-1/2"	1-1/2"	1-1/2"
Capacity in Steel (Twist Bit)	1/2"	1/2"	1/2"	1/2"	1/2"
Capacity in Steel (Hole Saw)	5"	5"	5"	3"	1-1/2"
Tool Weight	11.75 lbs	13.5 lbs	9.75 lbs	7.5 lbs	7.0 lbs

1-800-4 DEWALT

CORDED POWER TOOLS 29