




HEAVY-DUTY POWER TOOLS

GUARANTEED TOUGH.

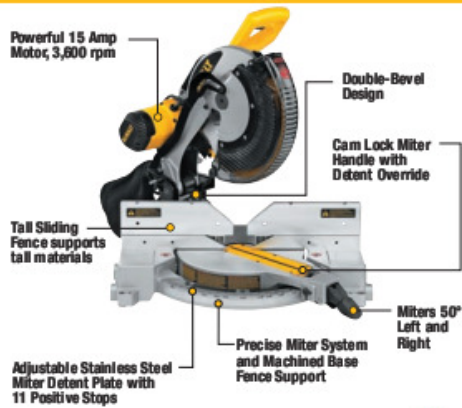

MITER SAWS

SPECIFICATIONS	DW703	DW712
Amps	15.0 Amps	15.0 Amps
No Load Speed	5,000 rpm	5,400 rpm
Blade Diameter	10"	8-1/2"
Arbor Size	5/8"	5/8"
Vertical Capacity: Baseboard Against Fence	3-1/2"	3-1/4"
Vertical Capacity: Crown Molding Vertically Nested	4-1/2"	3-1/2"
Horizontal Capacity: Baseboard Lying Flat	6"	11.8"
Horizontal Capacity: Crown Molding Lying Flat	5-1/4"	11.8"
45° Bevel Cut Capacity (dimensional lumber)	2x6	2x12
90° Cross-Cut Capacity (dimensional lumber)	4x4	2x12



MITER SAWS (continued)



SPECIFICATIONS	DW715	DW716	DW718	DW723
Amps	15.0 Amps	15.0 Amps	15.0 Amps	Quick Change Clamps
No Load Speed	4,000 rpm	3,600 rpm	3,600 rpm	12" Extension
Blade Diameter	12"	12"	12"	Lightweight – 33 lbs
Arbor Size	5/8 or 1"	5/8 or 1"	5/8 or 1"	Support up to 400 lbs
Vertical Capacity: Baseboard Against Fence	6-1/2"	6-1/2"	6-1/2"	
Vertical Capacity: Crown Molding Vertically Nested	5-1/4"	6-5/8"	6-5/8"	
Horizontal Capacity: Baseboard Lying Flat	8"	8" (10" with back fence)	16"	
Horizontal Capacity: Crown Molding Lying Flat	6-1/2"	6-1/2"	11-1/4"	
45° Bevel Cut Capacity (dimensional lumber)	2x8	2x8 (2x10 with back fence)	2x14 (2x16 with back fence)	
90° Cross-Cut Capacity (dimensional lumber)	4x6	2x8 (2x10 with back fence)	2x14 (2x16 with back fence)	

MITER SAW ACCESSORIES

- DW7051 – Length Stop (for all DeWALT Miter Saws)
- DW7053 – Dust Bag (for all DeWALT Miter Saws)
- DW7055 – Replacement Kerf Plate (for DW703, DW715 and DW716)

- DW7080 – Extension Kit (for DW703, DW712, DW715, DW716 and DW718)
- DW7082 – Vertical Clamp (for DW703, DW712, DW715, DW716 and DW718)
- DW7084 – Crown Stops (for DW703, DW712, DW715, DW716 and DW718)

MITER SAW STAND ACCESSORIES

- DW7231 – Workstation Tool Mounting Brackets (for DW723 only)
- DW7232 – Work Piece Support and Length Stop (for DW723 only)

TABLE SAWS



SPECIFICATIONS	DW745	DW744X	SPECIFICATIONS	DW746/DW746X
Amps	15.0 Amps	15.0 Amps	Horsepower	1-3/4 HP
No Load Speed	3,850 rpm	3,650 rpm	No Load Speed	3000 rpm
Blade Diameter	10"	10"	Blade Diameter	10"
Arbor Size	5/8"	5/8"	Arbor Size	5/8"
Dust Port Diameter	2-1/2"	2-1/4"	Dust Port Diameter	2-1/2"
Depth of Cut at 90°	3-1/8"	3-1/8"	Depth Of Cut At 90°	3-1/8"
Depth of Cut at 45°	2-1/4"	2-1/4"	Depth Of Cut At 45°	2-1/8"
Max Rip to Right of Blade	16"	21-1/2"	Max Rip to Right of Blade	with DW7468: 30", with DW7464: 52"
Max Rip to Left of Blade	12"	15-1/2"	Max Rip to Left of Blade	16"
Max Width of Dado	N/A	13/16"	Max Width of Dado	13/16"
Tool Weight	64 lbs	64 lbs	Tool Weight	254 lbs

TABLE SAW ACCESSORIES

- DW7450 – Table Saw Stand (for DW745)
- DW7440 – Portable Table Saw Stand
- DW7441 – Out Feed and Side Support
- DW7444 – Dado Throat Plate

- DW7460 – Mobile Base
- DW7461 – Sliding Table
- DW7462 – Cast Iron Extension Wing
- DW7463 – Out Feed Table
- DW7464 – 52" Precision Fence Rail System
- DW7466 – Dado Throat Plate
- DW7468 – 30" Precision Fence Rail System
- DW7469 – Low Profile Fence Face Attachment