


Ground Clamps With Hubs PC 5560

- UL Listed
- Bronze
- With 1/2", 3/4" or 1" Hubs

Ground clamps with hubs are used to connect grounding conductor in conduit to water pipe for grounding. Cast from high strength, highly conductive copper alloy with steel or bronze screws.

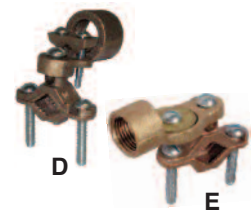

| CAT NO | UPC | PHOTO | WIRE RANGE | HUB SIZE | PIPE SIZE | STD | MSTR | WT/STD | UNIT |
|--------|-------|-------|------------|----------|-------------|-----|------|--------|------|
| 29L | 10051 | E | 10-6 | 1/2" | 1/2 to 1" | 25 | 125 | 9.80# | C |
| 29BRZ | 10054 | E | 10-6 | 1/2" | 1/2 to 1" | 25 | 125 | 10.06# | C |
| 30L | 10053 | D | 10-2/0 | 3/4" | 1/2 to 1" | 25 | 125 | 11.35# | C |
| 31L | 10056 | D | 10-3/0 | 1" | 1/2 to 1" | 25 | 125 | 12.33# | C |
| 270L | 10057 | E | 10-6 | 1/2" | 1-1/4 to 2" | 25 | 25 | 14.87# | C |
| 271L | 10059 | D | 10-2/0 | 3/4" | 1-1/4 to 2" | 25 | 25 | 16.63# | C |
| 272L | 10061 | D | 10-3/0 | 1" | 1-1/4 to 2" | 25 | 25 | 17.44# | C |
| 280L | 10063 | E | 10-6 | 1/2" | 2-1/2 to 4" | 5 | 5 | 6.23# | C |
| 281L | 10064 | D | 10-2/0 | 3/4" | 2-1/2 to 4" | 5 | 5 | 6.63# | C |
| 282L | 10066 | D | 10-3/0 | 1" | 2-1/2 to 4" | 5 | 5 | 6.64# | C |

All clamps provided with steel screws except 29BRZ (bronze screws)

Ground Rod Clamps PC 5570

- UL Listed
- Direct Burial
- Bronze
- With Bronze Hex Head Bolt

Ground rod clamps are used to connect conductor to a driven ground rod. Cast from high strength, highly conductive copper alloy, they are approved for direct burial in ground and concrete and are assembled with a bronze hex head bolt.



| CAT NO | UPC | SIZE | GROUND WIRE | STD | MSTR | WT/STD | UNIT |
|--------|-------|------|-----------------|-----|------|--------|------|
| GR12 | 10500 | 1/2" | 10 Sol to 2 Str | 50 | 250 | 8.83# | C |
| GR58 | 10505 | 5/8" | 10 Sol to 2 Str | 50 | 250 | 4.65# | C |
| GR34 | 10510 | 3/4" | 10 Sol to 2 Str | 25 | 100 | 2.96# | C |

Ground Rod Clamps - Universal PC 5570

- UL Listed
- Direct Burial
- Stainless Steel
- One Size Fits All

Universal Ground Rod Clamp is UL Listed for all sizes of Ground Rods and Rebar. Constructed of Stainless Steel Alloy and a High Performance Stainless Steel Bolt. For direct Burial in Earth or Concrete.




| CAT NO | UPC | ROD SIZES | WIRE RANGE | STD | MSTR | WT/STD | UNIT |
|--------|-------|-----------|------------------|-----|------|--------|------|
| UGRCS | 83180 | 3/8" | 10 Sol - 1/0 Str | 50 | 250 | 4.65# | C |
| | | 1/2" | 10 Sol - 1/0 Str | | | | |
| | | 5/8" | 10 Sol - 1/0 Str | | | | |
| | | 3/4" | 8 Sol - 1/0 Str | | | | |



Hubs PC 5580

- UL Listed
- Bronze

Hubs are used with ground clamps to connect rigid conduit to water pipe for grounding. 360° swing type hub provides flexibility. They are cast from high strength, highly conductive copper alloy with zinc plated screws.

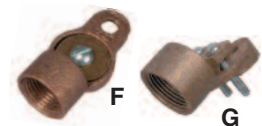

| CAT NO | UPC | SIZE | PHOTO | GROUND WIRE | STD | MSTR | WT/STD | UNIT |
|---------|-------|------|-------|-------------------|-----|------|--------|------|
| HUB50L | 10171 | 1/2" | F | 10 Sol to 6 Str | 25 | 250 | 5.04# | C |
| HUB75L | 10176 | 3/4" | G | 10 Sol to 2/0 Str | 25 | 250 | 7.23# | C |
| HUB100L | 10181 | 1" | G | 10 Sol to 3/0 Str | 10 | 100 | 3.00# | C |