

# Magnetic Hex Tools PC 6700, 6710, 6720


- Hardened Core For Extra Strength
- Heat Treated To Resist Wear
- Specially Designed To Reduce Stripping



\*Magnetic Bit Holder

Socket Adapter Extension

\* MBH: to be used for Insert Bits Only. Not for power bits.

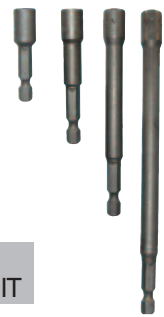


CAT NO	UPC	TYPE	SCREW SIZE	DRIVE LENGTH	STD	MSTR	WT/STD	UNIT
<b>Magnetic Hex Tools</b>								
MT8	17730		#6-8	1/4 x 1-3/4"	1	10	0.070#	Ea
MT8L	17735		#6-8	1/4 x 2-9/16"	1	10	0.080#	Ea
MT84	17737	1/4"	#6-8	1/4 x 4"	1	10	0.110#	Ea
MT86	17739		#6-8	1/4 x 6"	1	10	0.190#	Ea
<hr/>								
MT10	17740		#10-12	5/16 x 1-3/4"	1	10	0.070#	Ea
MT10L	17745		#10-12	5/16 x 2-9/16"	1	10	0.090#	Ea
MT104	17742	5/16"	#10-12	5/16 x 4"	1	10	0.110#	Ea
MT106	17747		#10-12	5/16 x 6"	1	10	0.190#	Ea
<hr/>								
MT38	17760		1/4"	3/8 x 1-3/4"	1	10	0.080#	Ea
MT38L	17752		1/4"	3/8 x 2-9/16"	1	10	0.090#	Ea
MT384	17757	3/8"	1/4"	3/8 x 4"	1	10	0.130#	Ea
MT386	17759		1/4"	3/8 x 6"	1	10	0.190#	Ea
<hr/>								
<b>Magnetic Bit Holder &amp; Drive - PC 6710</b>								
MBH*	16948	Magnetic Bit Holder		1/4 x 3"	1	10	0.110#	Ea
<hr/>								
<b>Socket Adapter Extensions - PC 6720</b>								
SHA14114	23105		1/4" Hex Shank	1/4 x 1-1/4"	1	10	0.032#	Ea
SHA142	23108	1/4"	1/4" Hex Shank	1/4 x 2"	1	10	0.034#	Ea
SHA143	23111		1/4" Hex Shank	1/4 x 3"	1	10	0.050#	Ea
<hr/>								
SHA382	23114		1/4" Hex Shank	3/8 x 2"	1	10	0.044#	Ea
SHA383	23117	3/8"	1/4" Hex Shank	3/8 x 3"	1	10	0.082#	Ea
SHA384	23120		1/4" Hex Shank	3/8 x 4"	1	10	0.109#	Ea

## Tamper Proof Insert Bits PC 6720

CAT NO	UPC	SCREW SIZE	DESCRIPTION	LENGTH	STD	MSTR	WT/STD	UNIT
<b>Hex Pin</b>								
73TR3	22733	#4-5	3/32" Hex Pin	1"	1	5	0.010#	Ea
73TR5	22735	#6	1/8" Hex Pin	1"	1	5	0.010#	Ea
73TR7	22737	#8,10,12,14	5/32" Hex Pin	1"	1	5	0.010#	Ea
73TR8	22738	5/16	3/16" Hex Pin	1"	1	5	0.010#	Ea
73TR9	22739	3/8	7/32" Hex Pin	1"	1	5	0.010#	Ea
<hr/>								
<b>Star Pin</b>								
60TR10	22610	#6R	T10 Star Pin	1"	1	5	0.010#	Ea
60TR15	22615	#6F-8R	T15 Star Pin	1"	1	5	0.010#	Ea
60TR20	22620	#8F	T20 Star Pin	1"	1	5	0.010#	Ea
60TR25	22625	10F-10R	T25 Star Pin	1"	1	5	0.010#	Ea
60TR27	22627	1/4F 1/4R	T27 Star Pin	1"	1	5	0.010#	Ea
60TR30	22630	1/4F	T30 Star Pin	1"	1	5	0.010#	Ea
<hr/>								
<b>Spanner</b>								
1156	31156	#6	#6 Spanner	1"	1	5	0.010#	Ea
1158	31158	#8	#8 Spanner	1"	1	5	0.010#	Ea
11510	31150	#10	#10 Spanner	1"	1	5	0.010#	Ea
11512	31152	#12	#12 Spanner	1"	1	5	0.010#	Ea
11514	31154	#14	#14 Spanner	1"	1	5	0.010#	Ea

### Power and Insert Bit Merchandiser (PBD)

Our attractive counter top Power and Insert Bit Merchandiser has been one of the most popular selling tools in our distributor's showrooms for many years. When fully stocked, our display offers a wide assortment of the most popular power and insert bits to satisfy the needs of every contractor. The clear acrylic lockable lid allows for easy viewing of the product without the concern of shrinkage.

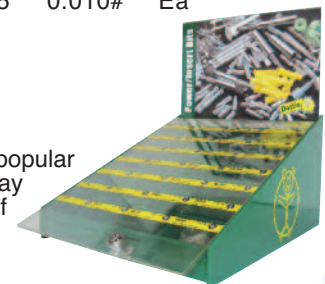

See new products at [Ihdottie.com](http://Ihdottie.com)

Dottie

E25

TOOLS & SPECIALTY ITEMS > MAGNETIC HEX TOOLS > TAMPER PROOF INSERT BITS



# Carded Bits PC 6751

Insert and power bits are available in a variety of configurations. Bits of 1" length are insert bits; bits 2" and longer are power bits. Note: MBH Tool is used with insert bits only. Not to be used with power bits.

- Packed 2 Per Display Card
- Maximum Durability
- Precision Fit Prevents Wear

CAT NO	UPC	TYPE	SCREW SIZE	POINT SIZE / LENGTH	STD	MSTR	WT/STD	UNIT
<b>Phillips Pt. Size 0 &amp; 1</b>								
IB0PC	81836		Insert Bit	#4 #0 x 1"	10	100	0.02#	Ea Card
IB1PC	81837		Insert Bit	#6 #1 x 1"	10	100	0.02#	Ea Card
IB1PLC	81838		Power Bit	#6 #1 x 2"	10	100	0.05#	Ea Card
IB1PXC	81839		Power Bit	#6 #1 x 3"	5	50	0.07#	Ea Card
IB1P4C	81840		Power Bit	#6 #1 x 4"	5	50	0.09#	Ea Card
IB1P6C	81841		Power Bit	#6 #1 x 6"	5	50	0.14#	Ea Card
<b>Phillips Pt. Size 2</b>								
IB2PC	81842		Insert Bit	#8-10 #2 x 1"	10	100	0.02#	Ea Card
IB2PLC	81843		Power Bit	#8-10 #2 x 2"	10	100	0.02#	Ea Card
IB2PXC	81844		Power Bit	#8-10 #2 x 3"	5	50	0.07#	Ea Card
IB2P4C	81845		Power Bit	#8-10 #2 x 4"	5	50	0.09#	Ea Card
IB2P6C	81846		Power Bit	#8-10 #2 x 6"	5	50	0.14#	Ea Card
<b>Phillips Pt. Size 3</b>								
IB3PC	81847		Insert Bit	#12-14 #3 x 1"	10	100	0.02#	Ea Card
IB3PLC	81848		Power Bit	#12-14 #3 x 2"	5	50	0.09#	Ea Card
IB3PXC	81849		Power Bit	#12-14 #3 x 3"	5	50	0.07#	Ea Card
IB3P4C	81850		Power Bit	#12-14 #3 x 4"	5	50	0.09#	Ea Card
IB3P6C	81851		Power Bit	#12-14 #3 x 6"	5	50	0.14#	Ea Card
<b>Slotted Pt. Size 0 &amp; 1</b>								
IB0SC	81852		Insert Bit	#4 #0 x 1"	10	100	0.02#	Ea Card
IB1SC	81853		Insert Bit	#6 #1 x 1"	10	100	0.02#	Ea Card
IB1SLC	81854		Power Bit	#6 #1 x 2"	10	100	0.05#	Ea Card
IB1SXC	81855		Power Bit	#6 #1 x 3"	5	50	0.07#	Ea Card
IB1S4C	81856		Power Bit	#6 #1 x 4"	5	50	0.09#	Ea Card
IB1S6C	81857		Power Bit	#6 #1 x 6"	5	50	0.14#	Ea Card
<b>Slotted Pt. Size 2</b>								
IB2SC	81858		Insert Bit	#8-10 #2 x 1"	10	100	0.02#	Ea Card
IB2SLC	81859		Power Bit	#8-10 #2 x 2"	10	100	0.05#	Ea Card
IB2SXC	81860		Power Bit	#8-10 #2 x 3"	5	100	0.07#	Ea Card
IB2S4C	81861		Power Bit	#8-10 #2 x 4"	5	50	0.09#	Ea Card
IB2S6C	81862		Power Bit	#8-10 #2 x 6"	5	50	0.14#	Ea Card
<b>Slotted Pt. Size 3</b>								
IB3SC	81863		Insert Bit	#12-14 #3 x 1"	10	100	0.02#	Ea Card
IB3SLC	81864		Power Bit	#12-14 #3 x 2"	10	100	0.05#	Ea Card
IB3SXC	81865		Power Bit	#12-14 #3 x 3"	5	50	0.07#	Ea Card
IB3S4C	81866		Power Bit	#12-14 #3 x 4"	5	50	0.09#	Ea Card
IB3S6C	81867		Power Bit	#12-14 #3 x 6"	5	50	0.14#	Ea Card
<b>Square Pt. 0 &amp; 1</b>								
IB0C	81868		Insert Bit	#4 #0 x 1"	10	100	0.02#	Ea Card
IB1C	81869		Insert Bit	#6 #1 x 1"	10	100	0.02#	Ea Card
IB1LC	81870		Power Bit	#6 #1 x 2"	10	100	0.05#	Ea Card
IB1XC	81871		Power Bit	#6 #1 x 3"	5	50	0.07#	Ea Card
IB14C	81872		Power Bit	#6 #1 x 4"	5	50	0.09#	Ea Card
IB16C	81873		Power Bit	#6 #1 x 6"	5	50	0.14#	Ea Card
<b>Square Pt. Size 2</b>								
IB2C	81874		Insert Bit	#8-10 #2 x 1"	10	100	0.02#	Ea Card
IB2LC	81875		Power Bit	#8-10 #2 x 2"	10	100	0.05#	Ea Card
IB2XC	81876		Power Bit	#8-10 #2 x 3"	5	50	0.07#	Ea Card
IB24C	81877		Power Bit	#8-10 #2 x 4"	5	50	0.09#	Ea Card
IB26C	81878		Power Bit	#8-10 #2 x 6"	5	50	0.14#	Ea Card
<b>Square Pt. Size 3</b>								
IB3C	81879		Insert Bit	#12-14 #3 x 1"	10	100	0.02#	Ea Card
IB3LC	81880		Power Bit	#12-14 #3 x 2"	10	100	0.05#	Ea Card
IB3XC	81881		Power Bit	#12-14 #3 x 3"	5	50	0.07#	Ea Card
IB34C	81882		Power Bit	#12-14 #3 x 4"	5	50	0.09#	Ea Card
IB36C	81883		Power Bit	#12-14 #3 x 6"	5	50	0.14#	Ea Card
<b>Combo Pt. Size #2 Square / #2 Phillips</b>								
IB2CLC	81891		Power Bit	#8-10 #2 x 2"	10	100	0.02#	Ea Card

