

# Magnetic Hex Tools PC 6700, 6710, 6720

- Hardened Core For Extra Strength
- Heat Treated To Resist Wear
- Specially Designed To Reduce Stripping



\*Magnetic Bit Holder

Socket Adapter Extension

\* MBH: to be used for Insert Bits Only. Not for power bits.




CAT NO	UPC	TYPE	SCREW SIZE	DRIVE LENGTH	STD	MSTR	WT/STD	UNIT
<b>Magnetic Hex Tools</b>								
MT8	17730		#6-8	1/4 x 1-3/4"	1	10	0.070#	Ea
MT8L	17735		#6-8	1/4 x 2-9/16"	1	10	0.080#	Ea
MT84	17737	1/4"	#6-8	1/4 x 4"	1	10	0.110#	Ea
MT86	17739		#6-8	1/4 x 6"	1	10	0.190#	Ea
<hr/>								
MT10	17740		#10-12	5/16 x 1-3/4"	1	10	0.070#	Ea
MT10L	17745		#10-12	5/16 x 2-9/16"	1	10	0.090#	Ea
MT104	17742	5/16"	#10-12	5/16 x 4"	1	10	0.110#	Ea
MT106	17747		#10-12	5/16 x 6"	1	10	0.190#	Ea
<hr/>								
MT38	17760		1/4"	3/8 x 1-3/4"	1	10	0.080#	Ea
MT38L	17752		1/4"	3/8 x 2-9/16"	1	10	0.090#	Ea
MT384	17757	3/8"	1/4"	3/8 x 4"	1	10	0.130#	Ea
MT386	17759		1/4"	3/8 x 6"	1	10	0.190#	Ea
<hr/>								
<b>Magnetic Bit Holder &amp; Drive - PC 6710</b>								
MBH*	16948	Magnetic Bit Holder		1/4 x 3"	1	10	0.110#	Ea
<hr/>								
<b>Socket Adapter Extensions - PC 6720</b>								
SHA14114	23105		1/4" Hex Shank	1/4 x 1-1/4"	1	10	0.032#	Ea
SHA142	23108	1/4"	1/4" Hex Shank	1/4 x 2"	1	10	0.034#	Ea
SHA143	23111		1/4" Hex Shank	1/4 x 3"	1	10	0.050#	Ea
<hr/>								
SHA382	23114		1/4" Hex Shank	3/8 x 2"	1	10	0.044#	Ea
SHA383	23117	3/8"	1/4" Hex Shank	3/8 x 3"	1	10	0.082#	Ea
SHA384	23120		1/4" Hex Shank	3/8 x 4"	1	10	0.109#	Ea

## Tamper Proof Insert Bits PC 6720

CAT NO	UPC	SCREW SIZE	DESCRIPTION	LENGTH	STD	MSTR	WT/STD	UNIT
<b>Hex Pin</b>								
73TR3	22733	#4-5	3/32" Hex Pin	1"	1	5	0.010#	Ea
73TR5	22735	#6	1/8" Hex Pin	1"	1	5	0.010#	Ea
73TR7	22737	#8,10,12,14	5/32" Hex Pin	1"	1	5	0.010#	Ea
73TR8	22738	5/16	3/16" Hex Pin	1"	1	5	0.010#	Ea
73TR9	22739	3/8	7/32" Hex Pin	1"	1	5	0.010#	Ea
<hr/>								
<b>Star Pin</b>								
60TR10	22610	#6R	T10 Star Pin	1"	1	5	0.010#	Ea
60TR15	22615	#6F-8R	T15 Star Pin	1"	1	5	0.010#	Ea
60TR20	22620	#8F	T20 Star Pin	1"	1	5	0.010#	Ea
60TR25	22625	10F-10R	T25 Star Pin	1"	1	5	0.010#	Ea
60TR27	22627	1/4F 1/4R	T27 Star Pin	1"	1	5	0.010#	Ea
60TR30	22630	1/4F	T30 Star Pin	1"	1	5	0.010#	Ea
<hr/>								
<b>Spanner</b>								
1156	31156	#6	#6 Spanner	1"	1	5	0.010#	Ea
1158	31158	#8	#8 Spanner	1"	1	5	0.010#	Ea
11510	31150	#10	#10 Spanner	1"	1	5	0.010#	Ea
11512	31152	#12	#12 Spanner	1"	1	5	0.010#	Ea
11514	31154	#14	#14 Spanner	1"	1	5	0.010#	Ea

### Power and Insert Bit Merchandiser (PBD)

Our attractive counter top Power and Insert Bit Merchandiser has been one of the most popular selling tools in our distributor's showrooms for many years. When fully stocked, our display offers a wide assortment of the most popular power and insert bits to satisfy the needs of every contractor. The clear acrylic lockable lid allows for easy viewing of the product without the concern of shrinkage.

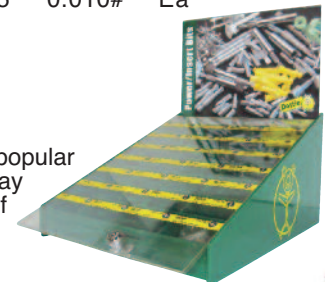

See new products at [Ihdottie.com](http://Ihdottie.com)

Dottie

E25

TOOLS & SPECIALTY ITEMS > MAGNETIC HEX TOOLS > TAMPER PROOF INSERT BITS