


Eye Bolts Zinc Plated Steel - PC 4870

Eye Bolts are manufactured from low carbon cold drawn steel wire and are supplied with NC rolled machine threads and one hex nut.

- Eye Bolts
- Zinc Plated Steel
- Includes Hex Nuts

CAT NO	UPC	SIZE	OVERALL LENGTH (L)	THREAD LENGTH (T)	SHANK LENGTH (S)	THREAD SIZE (W)	INSIDE EYE Dia (C)	WORKING LOAD	WIRE DIA	STD	MSTR	WT/STD	UNIT
EB2	28230	3/16 x 2"	2"	1-1/4"	1-3/8"	3/16" (10-24)	5/16"	38 lbs	0.16	50	500	0.96#	C
EB3	28235	3/16 x 3"	3-11/16"	1-1/2"	3"	3/16" (10-24)	3/8"	38 lbs	0.16	50	500	1.39#	C
EB4	28240	1/4 x 2"	2"	7/8"	1"	1/4"	1/2"	74 lbs	0.16	50	500	2.02#	C
EB5	28245	1/4 x 3"	3"	1-1/4"	2"	1/4"	1/2"	74 lbs	0.214	50	500	2.66#	C
EB6	28250	1/4 x 4"	4"	1-1/2"	3"	1/4"	1/2"	74 lbs	0.214	50	500	3.25#	C
EB7	28255	1/4 x 5"	5"	2-1/2"	4"	1/4"	1/2"	74 lbs	0.214	50	500	3.66#	C
EB8	28260	1/4 x 6"	6"	3"	5"	1/4"	1/2"	74 lbs	0.214	50	500	4.25#	C
EB9	28265	3/8 x 2-1/2"	2-1/2"	7/8"	1"	3/8"	3/4"	144 lbs	0.331	50	200	6.87#	C
EB10	28270	3/8 x 4"	4"	1-1/2"	2-1/2"	3/8"	3/4"	144 lbs	0.331	50	200	7.67#	C
EB11	28275	3/8 x 5"	5"	2"	3-1/2"	3/8"	3/4"	144 lbs	0.331	50	200	9.84#	C
EB12	28280	3/8 x 6"	6-1/2"	3"	5"	3/8"	3/4"	144 lbs	0.331	50	200	11.30#	C

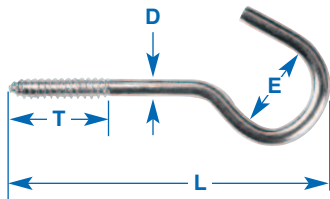


Screw Hooks PC 4870

Screw Hooks can be used for hanging chain when installing light fixtures. Sharp point bites into wood quickly and easily.

- Screw Hooks
- Round Bend Type
- Zinc Plated Steel

CAT NO	UPC	OVERALL LENGTH (L)	THREAD LENGTH (T)	HOOK OPENING (E)	WIRE DIAMETER (D)	STD	MSTR	WT/STD	UNIT
SH20	30905	4-15/16"	1-3/4"	1"	.307	50	200	3.68#	C
SH40	30910	3-7/8"	1-1/2"	13/16"	.275	50	500	1.51#	C
SH60	30915	3-3/8"	7/8"	3/4"	.192	100	1000	3.65#	C
SH80	30920	2-9/16"	7/8"	9/16"	.160	100	1000	2.05#	C
SH100	30925	2-1/16"	11/16"	3/8"	.135	100	1000	1.22#	C
SH120	30930	1-5/16"	1/2"	1/4"	.080	100	1000	1.05#	C

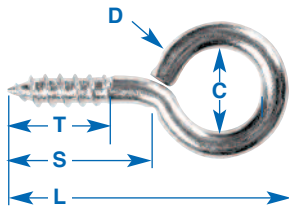

Screw Eyes PC 4870

Screw Eyes are manufactured from low carbon cold drawn steel wire. The lag screw threads are rolled to fit standard anchors and shields. Sharp point bites into wood quickly and easily.

- Screw Eyes
- Zinc Plated Steel
- Gimlet Point for use in wood

CAT NO	UPC	OVERALL LENGTH (L)	SHANK LENGTH (S)	THREAD LENGTH (T)	INSIDE EYE DIA (C)	WIRE DIAMETER (D)	STD	MSTR	WT/STD	UNIT
SE1	30855	2-5/8"	1-1/4"	1-1/8"	3/4"	.264	50	500	3.99#	C
SE2	30860	2-3/16"	1-1/8"	1"	5/8"	.225	50	500	2.47#	C
SE3	30865	1-13/16"	15/16"	3/4"	7/16"	.192	100	1000	2.59#	C
SE4	30870	1-5/8"	3/4"	5/8"	1/2"	.160	100	1000	1.54#	C
SE5	30875	1-3/8"	11/16"	5/8"	7/16"	.135	100	1000	0.90#	C
SE6	30880	1-3/16"	9/16"	1/2"	3/8"	.105	100	1000	0.46#	C

STEEL AND WIRE GAUGE

(A)	000	00	0	1	2	3	4	5	6	7	8	9	10	11	12	13	14	15	16	17	18	19	20							
(B)				9/32	1/4		9/32		3/16		5/32		1/8		3/32				1/16											
(C)	.363	.328	.307	.283	.281	.262	.250	.244	.225	.219	.207	.192	.187	.177	.162	.156	.148	.135	.125	.120	.105	.094	.091	.080	.072	.062	.054	.047	.041	.034

(A) Steel Wire Gauge No. (B) Common Fractions (C) Decimal

