


# Wall Grip / Wall Drive Anchors PC 4435

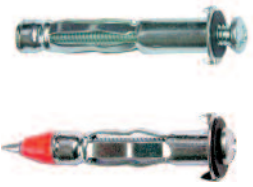

- Wall Grip / Wall Drive
- Drive Style Anchor
- Does Not Require a Pre-drilled Hole
- Steel
- Caution! Always Wear Eye Protection

Wall Grip Anchors: Also known as "Mollies" or Molly Bolts. Made for hollow wall installations. When tightened, the body pulls up to enable the anchor to secure itself to very thin walls such as paneling.

CAT NO	UPC	SIZE	GRIP RANGE	DRILL	STD	MSTR	WT/STD	UNIT
<b>Wall Grip</b>								
WG18S	31400	1/8"	1/8"-1/2"	5/16"	100	1000	1.20#	C
WG18L	31402	1/8"	5/8"-7/8"	5/16"	100	1000	1.70#	C
WG316S	31404	3/16"	1/8"-5/8"	3/8"	50	500	1.70#	C
WG316L	31406	3/16"	5/8"-1-3/16"	3/8"	50	500	2.04#	C
WG14S	31408	1/4"	1/8"-5/8"	1/2"	50	500	2.45#	C
WG14L	31410	1/4"	5/8"-1-3/16"	1/2"	50	500	2.94#	C
<b>Wall Drive Anchors</b>								
18SD	31412	1/8"	1/8"-1/2"		100	1000	1.40#	C
18SLD	31414	1/8"	1/8"-13/16"		100	1000	1.75#	C

## Lag Shields PC 4450



- Lag Shields
- Short & Long Styles
- Zamac Metal
- Caution! Always Wear Eye Protection

Lag shields: Allows for using lag screws in materials such as mortar joints, poured concrete, brick and concrete blocks.

CAT NO	UPC	SIZE	DIA	MIN DEPTH	TENSILE	STD	MSTR	WT/STD	UNIT
<b>HLS (Short) for Hard Masonry</b>									
HLS14	31200	1/4"	1/2"	1"	1450#	100	1000	1.98#	C
HLS516	31205	5/16"	1/2"	1-1/4"	1500#	100	1000	2.68#	C
HLS38	31210	3/8"	5/8"	1-3/4"	1600#	50	500	2.30#	C
HLS12	31215	1/2"	3/4"	2"	2000#	25	250	2.07#	C
<b>SLS (Long) for Soft Masonry</b>									
SLS14	31230	1/4"	1/2"	1-1/2"	1600#	50	500	3.90#	C
SLS516	31235	5/16"	1/2"	1-13/16"	1700#	50	500	5.40#	C
SLS38	31240	3/8"	5/8"	2-1/2"	1800#	50	500	2.30#	C
SLS12	31245	1/2"	3/4"	3"	2750#	25	250	2.07#	C

## Pipe Spike PC 4380




- One Piece Design
- Vibration Resistant
- Approved for Overhead

The Pipe Spike is designed primarily for use when hanging threaded rod. Using a special manufacturing process the anchor is formed with a "S" shaped configuration at the working end of the anchor to create an expansion mechanism. As the anchor is driven into the hole, the expansion mechanism is compressed and flexes to the size of the hole.

CAT NO	UPC	SIZE	CONTENTS	STD	MSTR	WT/STD	UNIT
PS25	81492	1/4"	Pipe Spike for 1/4" Rod Hanging	100	600	4.00#	C
PS38	81493	3/8"	Pipe Spike for 3/8" Rod Hanging	50	300	4.00#	C

## Pre-Tied Ceiling Wire With Clip PC 4385

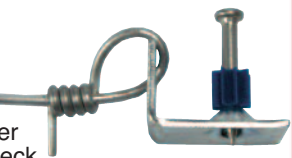

- 12 Gauge Wire
- Includes 1-1/4" Pin & Clip
- Galvanized Finish
- ICC# ESR1530

Pre-Tied Ceiling Wires are installed with low velocity powder actuated tools in poured concrete deck.

CAT NO	UPC	DESCRIPTION	STD	MSTR	WT/STD	UNIT
CWC	81936	6' Pre-Tied ceiling wire with 1-1/4" Pin & Clip	100	100	22.00#	C