





## Wiha Insulated Screwdriver Sets

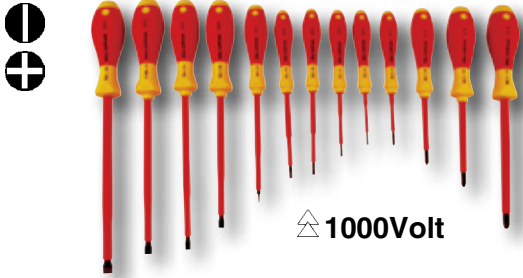

### WH32094 13 Piece Slotted & Phillips Set

Item No.		⚡
WH32094	Slotted: 2.0, 2.5, 3.0, 3.5, 4.5, 5.5, 6.5, 8.0, 10.0mm Phillips: 0, 1, 2, 3	lbs. 2.3

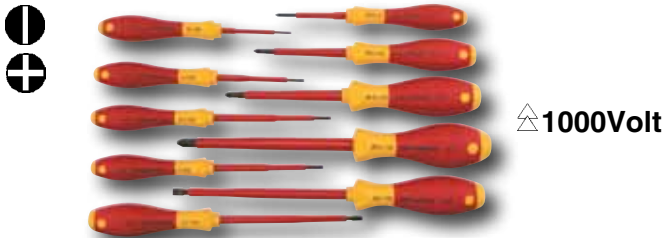

### WH32093 10 Piece Slotted & Phillips Set

Item No.		⚡
WH32093	Slotted: 2.0, 2.5, 3.0, 3.5, 4.5, 6.5 Phillips: 0, 1, 2, 3	lbs. 1.63



### WH32190 15 Piece Slotted, Phillips & Inch Nut Drivers Set

Item No.		⚡	lbs.
WH32190	Slotted: 2.0, 2.5, 3.0, 3.5, 4.5, 6.5, 8.0mm Phillips: 1, 2, 3 Nut Drivers Inch: 1/4, 5/16, 3/8, 7/16, 1/2"		5.9



⚡ 1000Volt

Tool box set in blow molded tray

### WH32095 19 Piece Slotted, Phillips, Square, Xeno Screwdriver Set

Insulated Screwdriver set in a light weight tool box tray.

Item No.		⚡
WH32095	Slotted: 2.5, 3.0, 3.5, 4.0, 4.5, 5.5, 6.0, 6.5, 8.0, 10.0mm Phillips: #0, #1, #2, #3 Square: #1, #2 lbs. Xeno Terminal: #1, #2	
4.92	Single Pole Voltage Detector 110V to 250V	


## Wiha Insulated Hex Metric Screwdrivers

⚡ 1000Volt



**WH323** Hex Metric Screwdriver, With Wiha-SoftFinish® Handle Insulation According to ASTM F-1505-01, New VDE Specification 0682/part 201 and EN/IEC 60900, NFPA70E & CSA, ⚡ up to 1000 Volt. Individually Tested. Blade high alloy CVM steel, hardened, black finish. Insulation molded directly onto blade. Wiha-SoftFinish® handle, multi-component, cushion grip.

Item No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
WH32302	2.5	75	3.0	179	7.0	.06	10
WH32303	3.0	75	3.0	179	7.0	.08	10
WH32304	4.0	75	3.0	186	7.3	.12	10
WH32305	5.0	75	3.0	186	7.3	.15	10
WH32306	6.0	100	3.9	218	8.6	.24	10
WH32308	8.0	100	3.9	218	8.6	.34	10

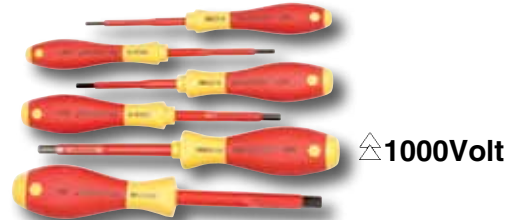

### WH32366 6 Piece Insulated Hex Metric Screwdriver Set


Item No.		⚡	lbs.
WH32366	Hex Metric: 2.5, 3.0, 4.0, 5.0, 6.0, 8.0mm		1.06

## Wiha Insulated Square Tip Screwdrivers



**WH358** Square Tip Screwdriver, With Wiha-SoftFinish® Handle Insulation According to ASTM F-1505-01, New VDE Specification 0682/part 201 and EN/IEC 60900, NFPA70E and CSA, ⚡ up to 1000 Volt. Individually Tested. Blade high alloy CVM steel, hardened, black finish. Insulation molded directly onto blade.

Item No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
WH35811	1	100	4.0	210	8.2	.12	10
WH35812	2	150	6.0	268	10.5	.19	10

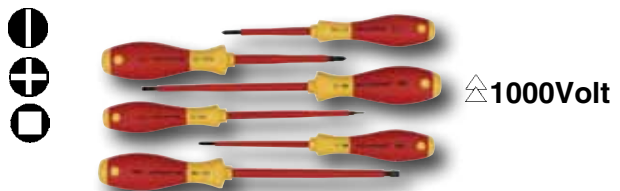

### WH35890 6 Piece Insulated Slotted, Phillips & Square Screwdrivers

Item No.		⚡
WH35890	Slotted: 4.5 x 125mm, 6.5 x 150mm Phillips: 1 x 80mm, 2 x 100mm Square: 1 x 100mm, 2 x 150mm	lbs. .83

### WH35891 6 Piece Insulated Slotted, Phillips & Square Screwdrivers

Item No.		⚡	lbs.
WH35891	Slotted: 3.0, 5.5mm Phillips: 1, 2 Square: 1, 2		.83