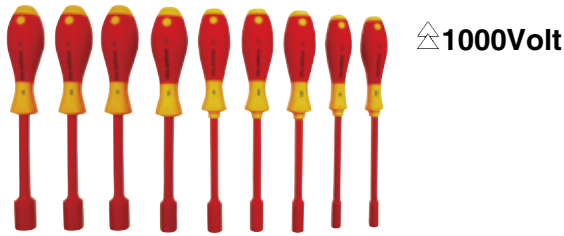



 



Wiha Insulated Inch Nut Driver Set





 
 


WH32288 9 Piece Nut Driver Set - Inch Sizes. In roll-up pouch

Item					
No.	Inch	Inch	Inch	Inch	lbs.
WH32288	3/16	5.0	7/16	5.0	3.16
	1/4	5.0	1/2	5.0	
	5/16	5.0	9/16	5.0	
	11/32	5.0	5/8	5.0	
	3/8	5.0			

Insulated Single-Pole Voltage Detector



 


 
 
 
WH25511 Insulated Single-Pole Voltage Detector. 110-250 Volts. Insulation According To DIN 57860/6 And DIN VDE 0680-6, GS Tested. Blade CVM steel, hardened, nickel-plated. Insulation molded directly onto blade. Amber LED light. 10,000Volt tested.

Item						
No.	mm	mm	mm	Inch	lbs.	pkg.
WH25511	3.0	65	145	5.7	.04	1

Insulated Terminal Block Xeno Screwdrivers




 


 
 
WH307 Combination Terminal Block Xeno Screwdriver, With Wiha SoftFinish® Handle. Insulation According to ASTM F-1505-01, VDE, 0682/part 201, EN/IEC 60900, NFPA70E & CSA specification. Individually Tested. Blade CVM steel, hardened, black finish. Insulation molded directly onto blade. Wiha-SoftFinish® handle, multi-component, cushion grip. For combination Slotted/Phillips head terminal screws.

Item						
No.	Size	mm	mm	Inch	lbs.	pkg.
WH30700	1	80	191	7.5	1.23	10
WH30701	2	100	218	8.6	1.23	10

Wiha Insulated TORX® Screwdrivers

 
 


WH325 TORX® Screwdriver, With Wiha-SoftFinish® Handle Insulation According to ASTM F-1505-01, New VDE Specification 0682/part 201 and EN/IEC 60900, NFPA70E and CSA, up to 1000 Volt. Individually Tested. Blade high alloy cvm steel, hardened, black finish. Insulation molded directly onto blade.

Item							
No.	Size	mm	Inch	mm	Inch	lbs.	pkg.
WH32505	T5	60	2.4	164	6.5	.06	10
WH32511	T6	60	2.4	164	6.5	.06	10
WH32516	T7	60	2.4	164	6.5	.06	10
WH32521	T8	60	2.4	164	6.5	.06	10
WH32526	T9	60	2.4	164	6.5	.06	10
WH32531	T10	60	2.4	164	6.5	.06	10
WH32536	T15	80	3.0	191	7.5	.12	10
WH32541	T20	80	3.0	191	7.5	.12	10
WH32546	T25	80	3.0	198	7.8	.17	10
WH32551	T27	100	4.0	218	8.6	.20	10
WH32556	T30	100	4.0	218	8.6	.20	10
WH32561	T40	150	6.0	274	10.8	.30	10


 
 
 
 


WH32590 6 Piece TORX® Set

Item					
No.	Size	mm	Size	mm	lbs.
WH32590	T8	60	T15	80	.83
	T9	60	T20	80	
	T10	60	T25	80	



WH32592 10 Piece TORX® Set

Item					
No.	Size	mm	Size	mm	lbs.
WH32592	T6	60	T15	80	1.2
	T7	60	T20	80	
	T8	60	T25	80	
	T9	60	T27	100	
	T10	60	T30	100	