




TYPE 3 & TYPE 12 SCREW COVER "GASKETED" BOXES - PAINTED

*NOTE: THE MAXIMUM SPACING BETWEEN SCREWS IS 12.25".

10-32 SCREWS THREAD INTO SEALED WELLS TO PREVENT LIQUID, DUST, ETC... FROM ENTERING INTO THE BOX THROUGH THE SCREW HOLES

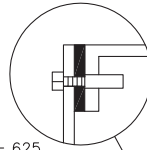

OIL-RESISTANT GASKET WITH SEALED WELLS




CONSTRUCTION:

- CODE GAUGE PAINT GRIP GALVANIZED STEEL
- SEAMS CONTINUOUSLY WELDED AND GROUND SMOOTH
- REMOVABLE COVER FASTENED WITH PLATED STEEL SCREWS

FINISH:

- ANSI 61 GRAY POLYESTER POWDER COATING INSIDE AND OUT

TYPE
3

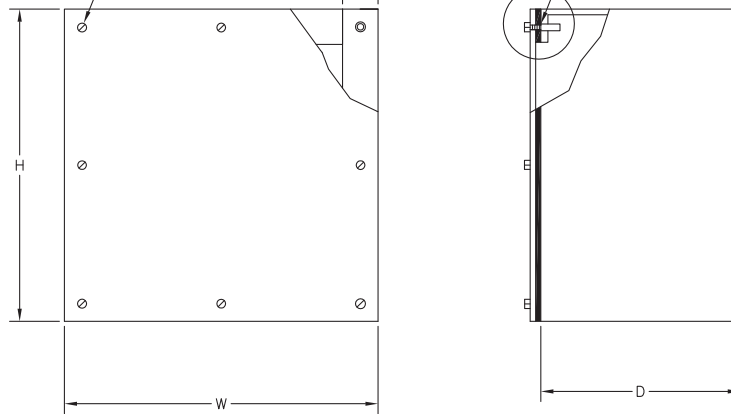

Enclosure Size HxWxD	Catalog Number	Weight
4x4x4	444SG	2
6x6x4	664SG	3
8x6x4	864SG	4
8x8x4	884SG	5
10x8x4	1084SG	5
10x10x4	10104SG	7
12x10x4	12104SG	7
12x12x4	12124SG	9
6x6x6	666SG	4
8x8x6	886SG	6
12x6x6	1266SG	7
10x10x6	10106SG	9
12x12x6	12126SG	11
15x12x6	15126SG	13
15x15x6	15156SG	16
18x18x6	18186SG	20
24x18x6	24186SG	26
24x24x6	24246SG	39
8x8x8	888SG	7
12x12x8	12128SG	12
18x18x8	18188SG	23
24x24x8	24248SG	42
30x24x8	30248SG	51
36x24x8	36248SG	60
30x30x8	30308SG	88
36x30x8	36308SG	102
18x18x10	181810SG	25
24x24x10	242410SG	48
30x24x10	302410SG	58
36x24x10	362410SG	67
30x30x10	303010SG	96
36x30x10	363010SG	111
18x18x12	181812SG	28
24x24x12	242412SG	53
30x30x12	303012SG	103
36x36x12	363612SG	137

FOR LARGE QUANTITIES CALL FACTORY