

BENEFITS AND FEATURES

- Energy efficient LED lighting
- Low or line voltage available
- Available in a variety of colors
- Estimated life is 75,000+ hours
- No UV or IR radiation
- Compact, architecturally pleasing design
- Black powder coat finish
- Available with light adjustable controller (Dimmer) built-in
- Remote Control provides easy access to illumination

DETAILED SPECIFICATIONS

- Input Voltage: 12VDC or 120 VAC
- LED Input Current: 700mA
- Power Consumption: 7.9 Watts
- Maximum Connection 5 Modules
- Operating Temperature: -40°C - +80°C
- LED Expected Life: 75,000+ hours
- Brightness: 270 Lumens (white)
- Dimensions: 12"L x 2.36"W x 1"H

APPLICATIONS


- Cove Lighting
- Accent Lighting
- Cabinet/Under cabinet Lighting
- Display Case Lighting
- RV Cabin Lighting
- Yacht Cabin/Accent Lighting



REMOTE CONTROL

UNDER CABINET MODULES

LED Cove/Under cabinet modules are ready-to-operate light fixtures with six 1 Watt Luxeon® Emitters included, per unit. Constructed of a high quality extruded aluminum housing with a flat black powder coat finish. These modules can be wall mounted or bracket mounted in any location. Each module is driven by a 12VDC power source or can be provided with a 120VAC power adaptor and plug. The brightness is dimmable with our patented infrared controller. The modules can be daisy-chained together (up to five modules) to run from one power source.

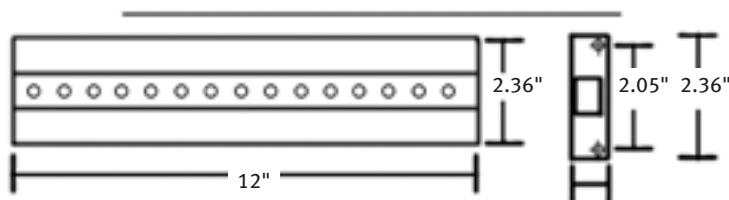

Luxeon® is a registered trademark of Lumileds®

ORDERING INFORMATION

MODEL	COLOR	VOLTAGE	OPTIONS
CLED	W = White	12 = 12 VAC	DIM = Built-in Dimmer
	WW = Warm White	120 = 120 VAC	IC = Infrared Controller

Ordering Example: CLED-W-12-IC