

# Armored Cable and Flexible Metal Conduit Connectors

## Flexible Metal Conduit - 90° Connectors

### Applications

- To ground and secure armored cable and flexible metal conduit to boxes and enclosures.

### Features

- Furnished with locknut.
- Male hub threads — NPS.
- Insulated throat version available.

### Standard Material/Finish

- Malleable iron/zinc electroplated

### Certifications and Compliances

- UL Standard: 514B
- UL Listed: E14814
- CSA Standard: C22.2 No. 18.3
- CSA Certified: 065178
- NEMA: FB-1



7383




7383I



7385



7385I

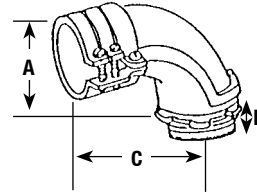

Catalog Number	Insulated Throat Catalog Number	Flexible Conduit Size (Inches)	Cable Opening (In./Mm)		Dimensions in Inches/Millimeters			Weight Lbs./Kgs. Per 100
			Max.	Min.	A	B	C	
7383	7383I	1	1.38/35.1	1.19/30.2	2.31/58.7	0.50/12.7	2.13/54.1	56.00/25.40
7384	7384I	1-1/4	1.78/45.2	1.47/37.3	2.81/71.4	0.56/14.2	2.75/69.9	118.00/53.52
7385	7385I	1-1/2	2.00/50.8	1.72/43.7	2.97/75.4	0.56/14.2	3.50/88.9	176.00/79.83
7386	7386I	2	2.44/61.9	2.00/50.8	4.13/104.9	0.75/19.1	4.75/120.7	290.00/131.54
7387	7387I	2-1/2	3.00/76.2	2.66/67.6	4.88/124.0	1.06/26.9	5.88/149.4	450.00/204.12
7388	7388I	3	3.50/88.9	3.16/80.3	5.50/139.7	1.06/26.9	6.63/168.4	612.00/277.60

COMMERCIAL PRODUCTS: CORD AND CABLE FITTINGS

Commercial Products