

# Conduit Clamps

## Type UBC

Right Angle

## Type UPC

Parallel

## Type UEC

Edge type

### Use:

Designed to secure Rigid Conduit, IMC or EMT across, parallel or perpendicular to beam, channel and angle supports.

### Features:

- Easily installed
- Capable of withstanding heavy loads

### Material:


All components are Malleable Iron except nuts and bolts which are steel.

### Finish:


Clamp - Hot Dipped Galvanized  
Hardware - Mechanically Galvanized

### Note:


Edge type UEC used for rigid conduit only.

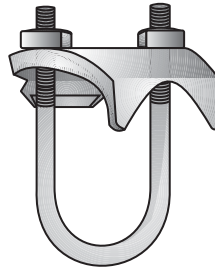

Type UBC-G  
Right Angle Type

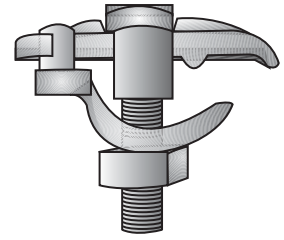

Type UEC - G  
Edge Type

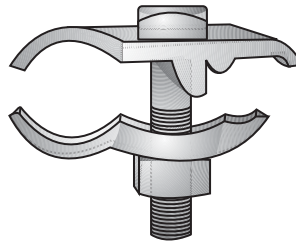

Type UPC-G  
Parallel Type

Trade Size (Inches)	Right Angle Type Catalog Number	Parallel Type Catalog Number	Edge Type Catalog Number
½	UBC-50G	UPC-50G	UEC-50G
¾	UBC-75G	UPC-75G	UEC-75G
1	UBC-100G	UPC-100G	UEC-100G
1¼	UBC-125G	UPC-125G	UEC-125G
1½	UBC-150G	UPC-150G	UEC-150G
2	UBC-200G	UPC-200G	UEC-200G
2½	UBC-250G	UPC-250G	UEC-250G
3	UBC-300G	UPC-300G	UEC-300G
3½	UBC-350G	UPC-350G	
4	UBC-400G	UPC-400G	
5	UBC-500G		
6	UBC-600G		