

# Bonding Jumpers

For Rigid Steel, IMC & EMT

## Type BJ & Type BJ-E

**Use:**

Type BJ - For bonding two rigid, EMT or IMC steel conduits together.

Type BJ-E - For bonding conduit to a flat surface, such as a cabinet or box.

**Material:**

Clamps - Malleable or Ductile Iron  
 U-Bolts - Steel  
 Braids - Tinned Copper

**Finish:**

Clamps and U-Bolts are Hot Dip Galvanized.

**Sizes:**

Braid lengths listed are fully extended.

**Optional Sizes:**

- Available in custom lengths. Contact your local representative for pricing and availability.

**Third Party Certification:**




UL Listed: E-24264




CSA Certified: 15978

**Applicable Third Party Standards:**

UL Standard: 467  
 CSA Standard: C22.2 No. 41  
 Fed. Spec: W-F-406E  
 NEMA: FB-1

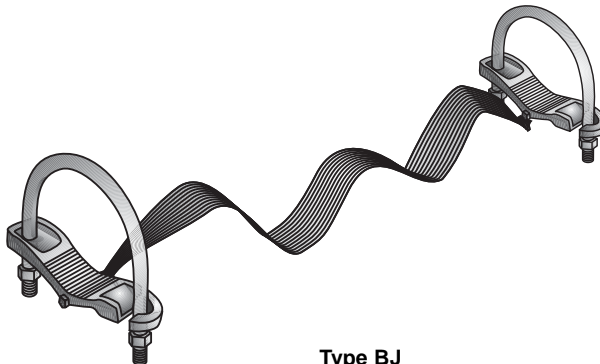

Type BJ

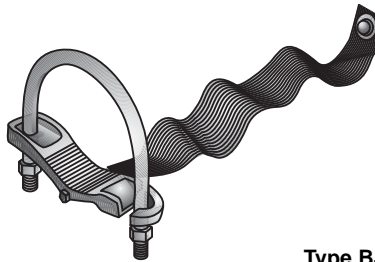

Type BJ-E

14" - Use with Type AX

24" - Use with Type AX8, TX & EX

16" - Use with Type EXE

Catalog Number	Trade Size (in.)	
	Min.	Max.
BJ-0507-14	½	¾
BJ-1012-14	1	1¼
BJ-1520-14	1½	2
BJ-2530-14	2½	3
BJ-3540-14	3½	4
BJ-5060-14	5	6

Catalog Number	Trade Size (in.)	
	Min.	Max.
BJ-0507-24	½	¾
BJ-1012-24	1	1¼
BJ-1520-24	1 ½	2
BJ-2530-24	2 ½	3
BJ-3540-24	3 ½	4
BJ-5060-24	5	6

Catalog Number	Trade Size (in.)	
	Min.	Max.
BJ-0507 E-16	½	¾
BJ-1012 E-16	1	1¼
BJ-1520 E-16	1½	2
BJ-2530 E-16	2½	3
BJ-3540 E-16	3½	4
BJ-5060 E-16	5	6