


Conduit Sealing Bushings

For Use with Pipe, Conduit or Tubing

Type CSM Dimensional Data:

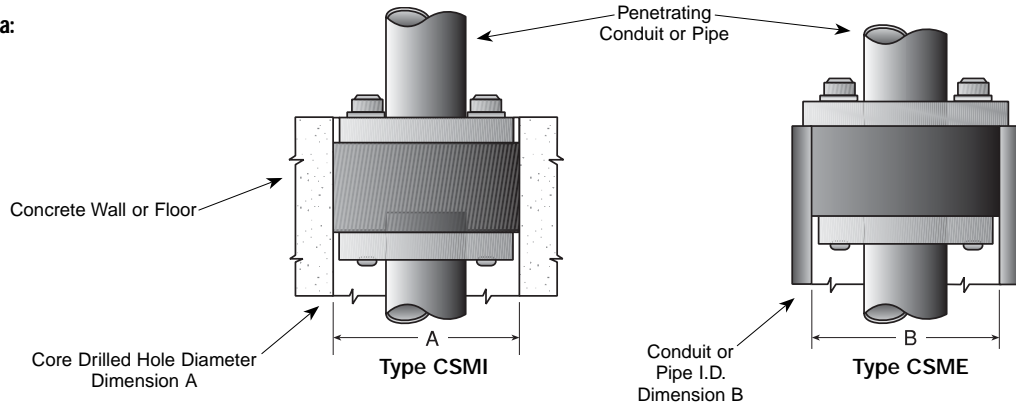

| Use with Core Drilled Hole Dia. "A" | Conduit or Pipe I.D. "B" | Single Penetration Applications Dimension in Inches | | | | Multiple Penetration Max. O.D. for More Than One Pipe | | | Catalog Numbers | | | | | | |
|-------------------------------------|--------------------------|--|--|-------------------------|-------------------------|--|----------------|---------|-----------------|------------|-----------|------------|-----------|-----------|-----------|
| | | Steel Pipe or Conduit Nom I.D. | Cast Iron Pipe O.D. | Copper Tubing Nom I.D. | O.D. | 2 Holes | 3 Holes | 4 Holes | Type CSMI | Type CSML | Type CSMC | Type CSME | Type CSMG | | |
| 2 | 2.067 | 3/8 1/2 3/4 | .675 .840 1.050 | 3/8 1/2 3/4 | .500 .625 .875 | .790 | .710 | .600 | CSMI-200P | CSML-200P | CSMC-200P | CSME-200P | CSMG-200P | | |
| 2 1/2 | 2.469 | 1 | 1.315 | 1 | 1.125 | .970 | .930 | .730 | CSMI-250P | CSML-250P | CSMC-250P | CSME-250P | CSMG-250P | | |
| 3 | 3.068 | 1 1/4 1 1/2 | 1.660 1.900 | 1 1/4 1 1/2 1 3/4 | 1.375 1.625 1.875 | 1.210 | 1.110 | .930 | CSMI-300P | CSML-300P | CSMC-300P | CSME-300P | CSMG-300P | | |
| 3 1/2 | 3.548 | | 2.000 | 2 | 2.125 | 1.375 | 1.315 | 1.125 | CSMI-350P | CSML-350P | CSMC-350P | CSME-350P | CSMG-350P | | |
| 4 | 4.026 | 2 | 2.375 | 2 2 | 2.500 2.625 | 2 1/4 2 1/2 | 2.375 2.625 | 1.625 | 1.460 | 1.315 | CSMI-400P | CSML-400P | CSMC-400P | CSME-400P | CSMG-400P |
| 5 | 5.047 | 2 1/2 3 | 2.875 3.000 3.500 | 2 | 2.750 | 2.000 | 1.875 | 1.625 | CSMI-500P | CSML-500P | CSMC-500P | CSME-500P | CSMG-500P | | |
| 6 | 6.065 | 3 1/2 4 | 4.000 4.500 | 3 3 3 | 3.660 3.800 3.960 | 2.500 | 2.125 | 2.000 | CSMI-600P | CSML-600P | CSMC-600P | CSME-600P | CSMG-600P | | |
| 8 | 7.981 | 4 1/2 5 6 | 5.000 5.250 5.500 5.563 6.000 6.625 | 4 4 | 4.800 5.000 | 3.000 | 3.000 | 2.875 | CSMI-800P | CSML-800P | CSMC-800P | CSME-800P | • | | |
| 10 | 10.020 | | 7.000 | 6 6 | 6.900 7.100 | Single Penetration Only | | | CSMI-1000P | CSML-1000P | • | CSME-1000P | • | | |
| 12 | 11.938 | 8 | 8.000 8.625 | 8 8 | 9.050 9.300 | Single Penetration Only | | | CSMI-1200P | CSML-1200P | • | CSME-1200P | • | | |
| 14 | 13.126 | 10 | 10.000 10.750 | 10 10 | 11.100 11.400 | Single Penetration Only | | | CSMI-1400P | CSML-1400P | • | CSME-1400P | • | | |
| 16 | 15.000 | 12 | 12.000 12.750 | 12 12 | 13.200 13.500 | Single Penetration Only | | | CSMI-1600P | CSML-1600P | • | CSME-1600P | • | | |

The suffix P in the Catalog Number indicates PVC Coated Steel Pressure Discs. For Aluminum Pressure Discs, change P to A.

•Type CSMG and CSMC are not available in these sizes.

† Blank fittings are intended as abandonment and future use devices only. Do not field drill.

NOTE: For additional information on Type CSM Series See Pages RA21, RA 23