


# Insulated Grounding Bushings for Threaded Rigid Metal Conduit and IMC

GIB-L-AC Series – with Aluminum Lay-In-Lug™ for Copper or Aluminum Conductors.

GIB-L-BC Series – with Bronze Lay-In-Lug™ for Copper Conductors Only.

COMMERCIAL PRODUCTS: RIGID AND IMC FITTINGS

Commercial Products

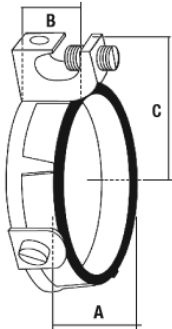

Catalog Number Aluminum Lug	Catalog Number Bronze Lug	Trade Size (Inches)	Wire Size		Dimensions in Inches/Millimeters		
			Min.	Max.	A Bushing Diameter	B Bushing Height	C Turning Radius w/Lug
GIB-50L-4AC	GIB-50L-4BC	1/2	14 SOL	4 STR	1.41/ 35.8	0.44/ 11.2	1.19/ 30.2
GIB-75L-4AC	GIB-75L-4BC	3/4	14 SOL	4 STR	1.44/ 36.6	0.50/ 12.7	1.31/ 33.3
GIB-100L-4AC	GIB-100L-4BC	1	14 SOL	4 STR	1.75/ 44.5	0.56/ 14.2	1.44/ 36.6
GIB-100L-20AC	GIB-100L-20BC	1	14 SOL	2/0 STR	1.75/ 44.5	0.56/ 14.2	1.69/ 42.9
GIB-125L-4AC	GIB-125L-4BC	1-1/4	14 SOL	4 STR	2.13/ 54.1	0.63/ 16.0	1.63/ 41.4
GIB-125L-20AC	GIB-125L-20BC	1-1/4	14 SOL	2/0 STR	2.13/ 54.1	0.63/ 16.0	1.41/ 35.8
GIB-150L-4AC	GIB-150L-4BC	1-1/2	14 SOL	4 STR	2.31/ 58.7	0.69/ 17.5	1.75/ 44.5
GIB-150L-20AC	GIB-150L-20BC	1-1/2	14 SOL	2/0 STR	2.31/ 58.7	0.69/ 17.5	2.00/ 50.8
GIB-200L-4AC	GIB-200L-4BC	2	14 SOL	4 STR	2.81/ 71.4	0.75/ 19.1	2.00/ 50.8
GIB-200L-20AC	GIB-200L-20BC	2	14 SOL	2/0 STR	2.81/ 71.4	0.75/ 19.1	2.25/ 57.2
GIB-250L-4AC	GIB-250L-4BC	2-1/2	14 SOL	4 STR	3.38/ 85.9	0.88/ 22.4	2.25/ 57.2
GIB-250L-20AC	GIB-250L-20BC	2-1/2	14 SOL	2/0 STR	3.38/ 85.9	0.88/ 22.4	2.50/ 63.5
GIB-250L-25AC	GIB-250L-25BC	2-1/2	6 STR	250 STR	3.38/ 85.9	0.88/ 22.4	2.47/ 62.7
GIB-300L-4AC	GIB-300L-4BC	3	14 SOL	4 STR	4.06/ 103.1	1.31/ 33.3	2.63/ 66.8
GIB-300L-20AC	GIB-300L-20BC	3	14 SOL	2/0 STR	4.06/ 103.1	1.31/ 33.3	2.81/ 71.4
GIB-300L-25AC	GIB-300L-25BC	3	6 STR	250 STR	4.06/ 103.1	1.31/ 33.3	3.31/ 84.1