

Pull Boxes with Threaded Hubs and Covers

For use with Threaded Rigid Metal Conduit and IMC.

Applications

- Serve as pulling fittings.
- Provide openings for splicing.
- Make straight connections and 90° bends in conduit runs.
- Permit access to conductors for maintenance.

Features

- Roomy interiors, more wiring space.
- Accurately tapped, tapered threads (NPT) for tight, rigid joints and ground continuity.

Standard Materials


- Bodies and covers: steel
- Hubs: malleable iron or steel
- Cover bolts: stainless steel

Standard Finish

- Zinc electroplate, chromate and epoxy powder coat.

Options

- Custom lengths up to 72 in/1828.8 mm available, contact your local sales representative.

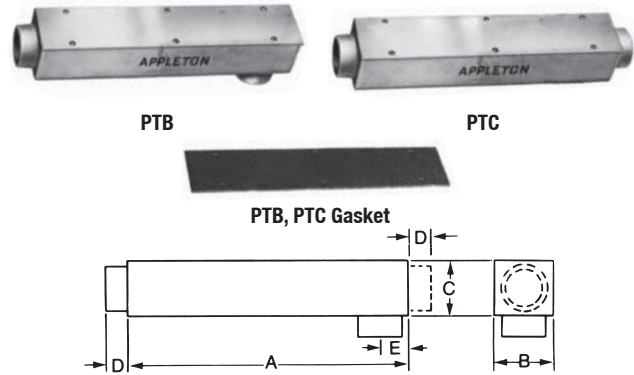

Certifications and Compliances

- UL Standard: 514A
- UL Listed: E2527

Catalog Numbers		Gaskets for PTC & PTB	Hub Size (Inches)	Pull Box Dimensions (Inches/Millimeters)				
Straight PTC Box	90° PTB Box			A	B	C	D	E
12-inch								
1200	1250	GK-12-100	1	12.00/304.8	2.19/55.6	2.13/54.1	0.84/21.3	0.94/23.9
1201	1251	GK-12-150	1-1/4	12.00/304.8	2.50/63.5	2.44/62.0	1.06/26.9	1.16/29.5
1202	1252	GK-12-150	1-1/2	12.00/304.8	2.50/63.5	2.44/62.0	1.06/26.9	1.38/35.1
1203	1253	GK-12-200	2	12.00/304.8	3.34/84.8	3.31/84.1	1.31/33.3	1.69/42.9
18-inch								
1211	—	GK-18-150	1-1/4	18.00/457.2	2.50/63.5	2.44/62.0	1.06/26.9	1.16/29.5
1212	—	GK-18-150	1-1/2	18.00/457.2	2.50/63.5	2.44/62.0	1.06/26.9	1.38/35.1
1213	—	GK-18-200	2	18.00/457.2	3.34/84.8	3.31/84.1	1.31/33.3	1.69/42.9
1214	—	GK-18-250	2-1/2	18.00/457.2	4.81/122.2	4.75/120.7	1.59/40.4	1.81/46.0
24-inch								
1222	1272	GK-24-150	1-1/2	24.00/609.6	2.50/63.5	2.44/62.0	1.06/26.9	1.38/35.1
1223	1273	GK-24-200	2	24.00/609.6	3.34/84.8	3.31/84.1	1.31/33.3	1.69/42.9
1224	1274	GK-24-300	2-1/2	24.00/609.6	4.81/122.2	4.75/120.7	1.59/40.4	1.81/46.0
1225	1275	GK-24-300	3	24.00/609.6	4.81/122.2	4.75/120.7	1.66/42.2	2.06/52.3
36-inch								
1244	1294	GK-36-300	2-1/2	36.00/914.4	4.81/122.2	4.75/120.7	1.59/40.4	1.81/46.0
1245	1295	GK-36-300	3	36.00/914.4	4.81/122.2	4.75/120.7	1.66/42.2	2.06/52.3
1246	1296	GK-36-400	3-1/2	36.00/914.4	6.31/160.3	6.19/157.2	1.91/48.5	2.38/60.5
1247	1297	GK-36-400	4	36.00/914.4	6.31/160.3	6.19/157.2	1.91/48.5	2.66/67.6
48-inch								
1812	—	GK-48-300	3	48.00/1219.2	4.81/122.2	4.75/120.7	1.66/42.2	2.06/52.3
1813	—	GK-48-400	3-1/2	48.00/1219.2	6.31/160.3	6.19/157.2	1.91/48.5	2.38/60.5
1814	—	GK-48-400	4	48.00/1219.2	6.31/160.3	6.19/157.2	1.91/48.5	2.66/67.6
1815	—	GK-48-500	5	48.00/1219.2	7.31/185.7	7.19/182.6	1.84/46.7	3.25/82.6
1816	—	GK-48-600	6	48.00/1219.2	8.31/211.1	8.19/208.0	2.03/51.6	4.03/102.4