


# 4" Square Boxes with Snap-In Brackets


For 2½" and 3⅝" Metal Studs

Third Party Certification:


 UL Listed: E18095

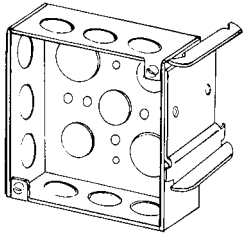


**4S1/2-SB2-1/2**  
1½" Deep, Welded  
For 2½" metal stud

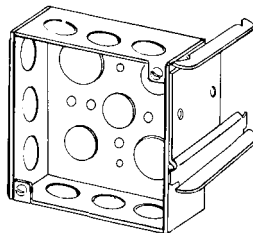


**4S1/2-SB3-5/8**  
1½" Deep, Welded  
For 3⅝" metal stud

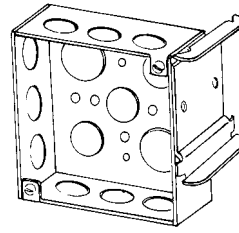


**4S-SPL-SB2-1/2**  
1½" Deep, Welded  
For 2½" metal stud

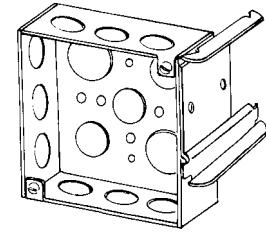


**4S-SPL-SB3-5/8**  
1½" Deep, Welded  
For 3⅝" metal stud

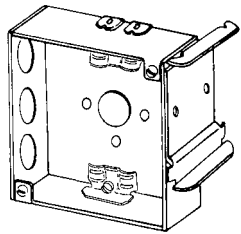


**4SR-SB2-1/2**  
1½" Deep, Welded  
For 2½" metal stud

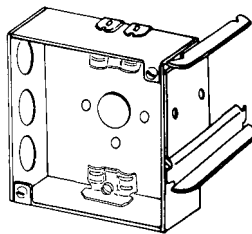

**4SR-SB3-5/8**  
1½" Deep, Welded  
For 3⅝" metal stud

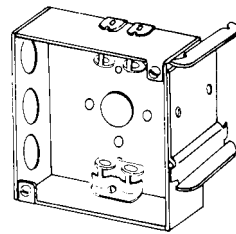

**4SX-SB2-1/2**  
1½" Deep, Welded  
For 2½" metal stud

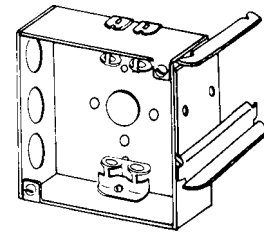

**4SX-SB3-5/8**  
1½" Deep, Welded  
For 3⅝" metal stud

Catalog Number	Depth (inches)	Stud Size (inches)	Wiring Cubic Inch Capacity	Type Clamp	Knockout Description	Wt. Lbs. Per 100	Std. Pkg.		
					Sides	Ends	Bottom		
<b>With Conduit Knockouts</b>									
<b>4S1/2-SB2-1/2</b>	1½	2½	21.0	--	(9)½"	--	(5)½"	92.0	25
<b>4S1/2-SB3-5/8</b>	1½	3⅝	21.0	--	(9)½"	--	(5)½"	102.0	25
<b>4S-SPL-SB2-1/2</b>	1½	2½	21.0	--	(6)½" (3)¾"	--	(3)½" (2)¾"	92.0	25
<b>4S-SPL-SB3-5/8</b>	1½	3⅝	21.0	--	(6)½" (3)¾"	--	(3)½" (2)¾"	102.0	25
<b>With Nonmetallic Sheathed Cable Clamps</b>									
<b>4SR-SB2-1/2</b>	1½	2½	21.0	CL-26	(3)½"	(4) <sup>2</sup> / <sub>32</sub> "	(1)½"	93.0	25
<b>4SR-SB3-5/8</b>	1½	3⅝	21.0	CL-26	(3)½"	(4) <sup>2</sup> / <sub>32</sub> "	(1)½"	103.0	25
<b>With Armored Cable/Metal Clad Cable Clamps</b>									
<b>4SX-SB2-1/2</b>	1½	2½	21.0	CL-13	(3)½"	(4) <sup>2</sup> / <sub>32</sub> "	(1)½"	119.0	25
<b>4SX-SB3-5/8</b>	1½	3⅝	21.0	CL-13	(3)½"	(4) <sup>2</sup> / <sub>32</sub> "	(1)½"	129.0	25