


Wire Mesh Strain Relief for Steel Cord Connectors

Suitable for use in:
 Class I, Division 2
 Class II, Division 1 and 2
 Class III
 NEMA 3R

Not to be used with stainless steel and nickel plated aluminum CG connectors

| Steel Cord Connectors | | | Dimensions (in/mm) | | Wt. Lbs./Kgs. Per 100 |
|--|--------------|----------------|--------------------|-------------|-----------------------|
| CG-Straight | CG-90° | Catalog Number | A | B | |
| For Connectors with 3/8 Inch Hubs | | | | | |
| CG-1238S | CG90-1238S | CG-SR1S | 0.94/23.9 | 3.63/92.2 | 5.40/2.40 |
| CG-1838S | CG90-1838S | CG-SR2S | 0.94/23.9 | 4.38/111.3 | 5.40/2.40 |
| CG-3138S | CG90-3138S | CG-SR3S | 0.94/23.9 | 5.5/139.7 | 5.40/2.40 |
| For Connectors with 1/2 Inch Hubs | | | | | |
| CG-1250S | — | CG-SR1S | 0.94/23.9 | 3.63/92.2 | 11.70/5.30 |
| — | CG90-1250S | CG-SR4S | 1.25/31.8 | 4.38/111.3 | 11.70/5.30 |
| CG-1850S | — | CG-SR2S | 0.94/23.9 | 4.38/111.3 | 11.70/5.30 |
| — | CG90-2550S | CG-SR5S | 1.25/31.8 | 5.5/139.7 | 11.70/5.30 |
| CG-3150S | — | CG-SR3S | 0.94/23.9 | 5.5/139.7 | 11.70/5.30 |
| CG-3750S | CG90-3750S | CG-SR6S | 1.25/31.8 | 6.13/155.7 | 11.70/5.30 |
| CG-5050S | CG90-5050S | CG-SR7S | 1.25/31.8 | 6.88/174.8 | 11.70/5.30 |
| CG-6250S | CG90-6250S | CG-SR8S | 1.25/31.8 | 9.38/238.3 | 11.70/5.30 |
| For Connectors with 3/4 Inch Hubs | | | | | |
| CG-1275S | — | CG-SR4S | 1.25/31.8 | 4.38/111.3 | 16.10/7.30 |
| CG-2575S | — | CG-SR5S | 1.25/31.8 | 5.5/139.7 | 16.10/7.30 |
| — | CG90-2575S | CG-SR9S | 1.38/35.1 | 4.13/104.9 | 16.10/7.30 |
| CG-3775S | — | CG-SR6S | 1.25/31.8 | 6.13/155.7 | 16.10/7.30 |
| — | CG90-3775S | CG-SR10S | 1.38/35.1 | 5.5/139.7 | 16.10/7.30 |
| CG-5075S | — | CG-SR7S | 1.25/31.8 | 6.88/174.8 | 16.10/7.30 |
| — | CG90-5075S | CG-SR11S | 1.38/35.1 | 6.38/162.1 | 16.10/7.30 |
| CG-6275S | CG90-6275S | CG-SR12S | 1.38/35.1 | 8.38/212.9 | 16.10/7.30 |
| CG-7575S | CG90-7575S | CG-SR13S | 1.38/35.1 | 9.13/231.9 | 16.10/7.30 |
| For Connectors with 1 Inch Hubs | | | | | |
| CG-37100S | — | CG-SR10S | 1.38/35.1 | 5.5/139.7 | 18.70/8.50 |
| CG-50100S | — | CG-SR11S | 1.38/35.1 | 6.38/162.1 | 18.70/8.50 |
| CG-62100S | — | CG-SR12S | 1.38/35.1 | 8.38/212.9 | 18.70/8.50 |
| — | CG90-62100S | CG-SR14S | 1.75/44.5 | 9.06/230.1 | 18.70/8.50 |
| CG-75100S | CG90-75100S | CG-SR15S | 1.75/44.5 | 9.06/230.1 | 18.70/8.50 |
| CG-87100S | CG90-87100S | CG-SR16S | 1.75/44.5 | 7.94/201.7 | 18.70/8.50 |
| CG-100100S | CG90-100100S | CG-SR17S | 1.75/44.5 | 7.94/201.7 | 18.70/8.50 |
| For Connectors with 1-1/4 Inch Hubs | | | | | |
| CG-75125S | — | CG-SR15S | 1.75/44.5 | 9.06/230.1 | 21.40/9.70 |
| — | CG90-75125S | CG-SR18S | 2.13/54.1 | 8.94/227.1 | 21.40/9.70 |
| CG-87125S | — | CG-SR16S | 1.75/44.5 | 7.94/201.7 | 21.40/9.70 |
| — | CG90-87125S | CG-SR19S | 2.13/54.1 | 7.94/201.7 | 21.40/9.70 |
| CG-100125S | CG90-100125S | CG-SR20S | 2.13/54.1 | 8.69/220.7 | 21.40/9.70 |
| CG-112125S | CG90-112125S | CG-SR21S | 2.13/54.1 | 9.31/236.5 | 21.40/9.70 |
| CG-125125S | CG90-125125S | CG-SR22S | 2.13/54.1 | 11.56/293.6 | 21.40/9.70 |
| CG-137125S | CG90-137125S | CG-SR23S | 2.13/54.1 | 10.81/274.6 | 21.40/9.70 |

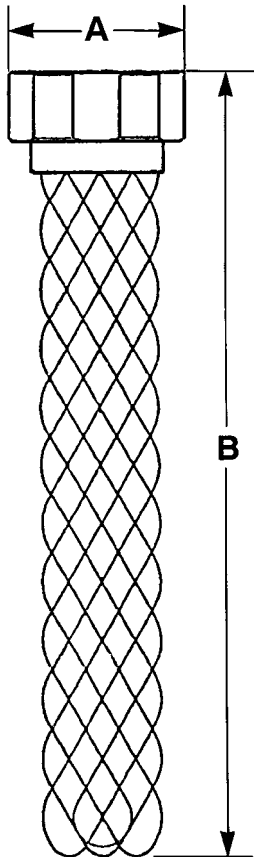

FITTINGS: CABLE AND CORD FITTINGS

Fittings