

# G25

# LED

## 7 Watt G25 Specifications



The ETi 7 watt 500 lumen G25 LED lamp offers exceptional performance for precision lighting applications, while reducing energy and maintenance cost when compared with conventional light sources. They are UL listed for use in damp and dry locations and are RoHS compliant with no lead or mercury. Warranty period is 3 years or 36 months. Suitable for installations from - 4° F to 113° F.


### KEY FEATURES & BENEFITS

- 7 Watt Low Power and High Performance
- 500 Lumen
- Dimmable
- 82 CRI
- 3000K
- UL - Damp or Dry Locations
- Replaces most applications using 60w energy saving incandescent lamps
- Rated Lifetime: 25,000 hours



This light source meets restrictions on hazardous substances.

### LAMP DIMENSIONS

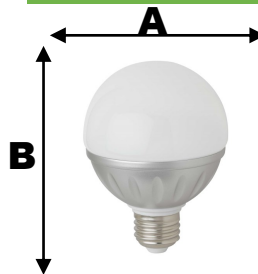

SKU# 52028111

Dimension A = 3.2"

Dimension B = 4.3"

This device complies with part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) This device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation. For FCC Part 15 user information, please see www.etiled.us

### APPLICATION INFORMATION

Chandeliers, bathroom vanity, accent lighting and general decorative indoor lighting in residential, office, retail, restaurant, school, hospital and hotel/motel locations.



# 8.5 Watt G25

# LED

## SPECIFICATION DATA

Project \_\_\_\_\_

Item Number \_\_\_\_\_


Prepared by \_\_\_\_\_ Date \_\_\_\_\_

## ORDERING INFORMATION

Item Number	Description	Wattage	Base Type	Input Voltage (VAC)	Average Rated Life <sup>1</sup>	Typical Lumens <sup>2</sup>	CCT <sup>3</sup>	CBCP	Beam	R9	Duv	CR1 <sup>4</sup>	Power Factor	Operating Frequency
52028111	G25 7 E26 DIM E830D164	7	E26	120	25,000	500	3000K	91.2	164	7.2	0.001	82	>0.94	60Hz
<sup>1</sup> Hours lifetime with 70% lumen maintenance														
<sup>2</sup> Thermally stable typical lumens (±10%)														
<sup>3</sup> Thermally stable CCT (±10%)														
<sup>4</sup> Color rendering index/Ra														

## SHIPPING INFORMATION

Item Number	Item UPC	Item Dimensions (H x L x W)	Item Weight (lbs)	Inner Pack Qty	Inner Carton Code	Inner Carton Dimensions (H x L x W)	Inner Pack Weight (lbs)	Master Pack Qty	Master Carton Code	Master Dimensions (H x L x W)	Master Pack Weight (lbs)
52028111	836607006387	4.9" x 3.5" x 3.5"	0.33	6	3083660706388	10.4" x 13.7" x 6"	3.8	24	50836607006382	21.9" x 14.4" x 12.7"	17.4

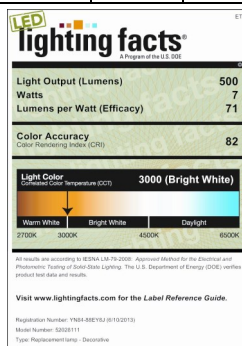

**The Americas Headquarters**  
**26650 Renaissance Parkway, STE 6**  
**Cleveland, OH 44128**

**855-384-7754**    **www.etiled.us**