

Terminal Blocks - Double Row

Bussmann
by **A-T-N**

Series TB200 & TB200HB
Double Row Terminal Blocks


SPECIFICATIONS

Rating: TB200 - 30A, 300V*
TB200HB - 30A, 600V*
Center Spacing: 0.437" or 7/16" (11.10mm)
Wire Range: #12 - 22 AWG Cu
Screw Size: #6-32 phillslot screws
Torque Rating: 9 lb-in.
Distance Between Barriers: 0.353" (8.97mm)
Mounting: #6 screws
Operating Temperature: 130°C (266°F) max., -40°C (-40°F) min.
Materials: Molded base: Black, UL rated 94V0 thermoplastic
Terminal plating: Tin over brass; Screws: zinc-plated steel
Breakdown Voltage: 4800V
Agency Information: UL File E62622, CSA File 47235 & 15364;
IEC Compliance; CE Certified


* Max. rating shown; some options may be rated lower - consult factory.

| Poles | A | B | Poles | A | B | Poles | A | B |
|-------|------|------|-------|------|------|-------|-------|-------|
| 02 | 1.63 | 1.31 | 12 | 6.00 | 5.68 | 22 | 10.37 | 10.06 |
| 03 | 2.07 | 1.75 | 13 | 6.44 | 6.12 | 23 | 10.81 | 10.50 |
| 04 | 2.51 | 2.18 | 14 | 6.87 | 6.56 | 24 | 11.25 | 10.93 |
| 05 | 2.94 | 2.62 | 15 | 7.31 | 7.00 | 25 | 11.68 | 11.37 |
| 06 | 3.38 | 3.06 | 16 | 7.75 | 7.43 | 26 | 12.12 | 11.81 |
| 07 | 3.82 | 3.50 | 17 | 8.19 | 7.87 | 27 | 12.56 | 12.25 |
| 08 | 4.25 | 3.93 | 18 | 8.62 | 8.31 | 28 | 13.00 | 12.68 |
| 09 | 4.69 | 4.37 | 19 | 9.06 | 8.75 | 29 | 13.44 | 13.12 |
| 10 | 5.13 | 4.81 | 20 | 9.50 | 9.18 | 30 | 13.87 | 13.56 |
| 11 | 5.57 | 5.25 | 21 | 9.94 | 9.62 | | | |


* Dimensions in inches. To convert to millimeters, multiply by 25.4.

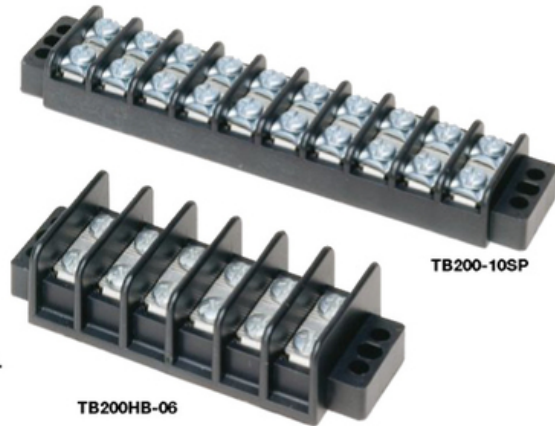

Dimensions - in (mm)

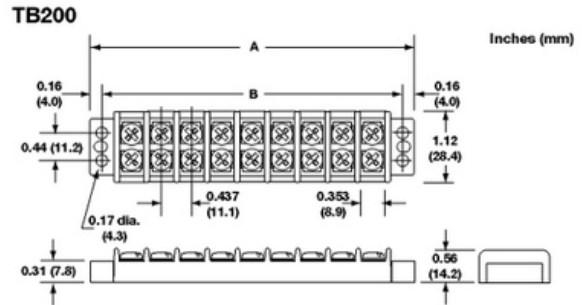

TB200HB

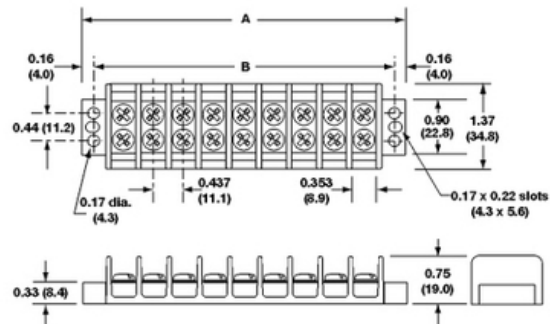

Part Numbering System

Series
TB200 - Standard
200HB - High barrier

Poles
02 to 30

Screw Options
Blank - steel phillslot, zinc-plated
00 - screws shipped bulk
B - brass phillslot, nickel-plated
BS - brass Sems phillslot, nickel-plated
SP - steel Sems phillslot, zinc-plated
P - steel Sems (P-style)
ST - stainless steel, phillslot
SS - stainless steel Sems, phillslot

Marking
L1 to L6 - (pg 36)
Marker strips (pg 37)
Covers (pg 36)

Hardware Options
QC1 to QC20 - quick connects
*J201 - flat slip-on jumper (2 position only)
*OJ3 - over barrier jumpers
*OJ5 - over barrier jumpers
*OJ7 - over barrier jumpers

* Custom Options. Consult factory for configuration.

For additional product information, visit www.bussmann.com

Terminal Blocks:
Single & Double Row

EuroTag Series

Terminal Blocks:
Panel & Rail Mount

Power Distribution
Blocks

Wire Management
Products

Edge Connectors,
One-Sided Boards

Compliance
References