



Powering Business Worldwide

[pe.eaton.com](http://pe.eaton.com)

## Industrial Control Transformer

**C3000K2CXX**

**UPC:**786680004773

### Dimensions:

- **Height:** 7.638 IN
- **Length:** 7.52 IN
- **Width:** 9.016 IN

**Weight:**56 LB

**Notes:**Epoxy resin impregnated coil design, 50/60 Hz operation, 180°C insulation system

### Warranties:

- Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

### Specifications:


- **Coil Material:** Copper windings
- **Design:** MTK
- **Modification 1:** No secondary fuse clips
- **Primary Voltage:** 240V X 480V
- **Secondary Voltage:** 120 X 240V
- **Tap Size:** None
- **Temperature Rating:** 115°C
- **Type:** Industrial Control Transformer
- **Volt Ampere Rating:** 3000 VA

### Supporting documents:

- [Eatons Volume 7-Logic Control, Operator Interface and Connectivity Solutions](#)
- [Eaton Specification Sheet - C3000K2CXX](#)

### Certifications:

- CSA Certified
- cUL Certified
- UL Listed

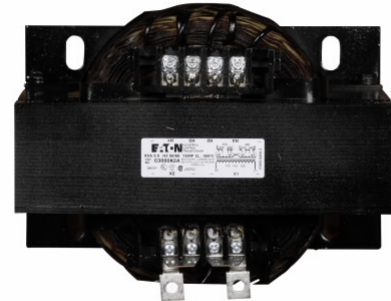

**Product compliance:**

- RoHS Compliant

---

© 2016 Eaton. All rights reserved.