



Powering Business Worldwide

[pe.eaton.com](http://pe.eaton.com)

## Molded Case Engine Generator Circuit Breaker

**FG3175WS02**

**UPC:**782116320127

### Dimensions:

- **Height:** 5 IN
- **Length:** 7 IN
- **Width:** 5 IN

**Weight:**4 LB

### Warranties:

- Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

### Specifications:


- **Amperage Rating:** 175A
- **Number Of Poles:** Three-pole
- **Series:** Series C
- **Shunt Trip:** 12-24 Vac/dc left pigtail rear
- **Terminals:** Line and load
- **Trip Type:** Thermal magnetic
- **Feed Type:** Reverse
- **Frame:** FG-frame
- **Generator Rating:** 63 kVA/51 kW at 240V, 126 kVA/101 kW at 480V, 158 kVA/126 kW at 600V
- **Pickup:** Fixed

### Supporting documents:

- [Eaton's Volume 4-Circuit Protection](#)
- [Eaton Specification Sheet - FG3175WS02](#)

### Certifications:

- UL 489
- IEC 947-2
- CSA Std. C22.2 No. 5

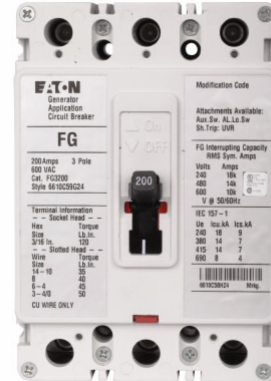

**Product compliance:** No Data

---

© 2016 Eaton. All rights reserved.