



Powering Business Worldwide

[pe.eaton.com](http://pe.eaton.com)

## DS7 Soft Start Controllers

**DS7-340SX135N0-L**

**UPC:786685887319**

### Dimensions:

- **Height:** 7.01 IN
- **Length:** 8.46 IN
- **Width:** 4.25 IN

**Weight:**8.16 LB

### Warranties:


- Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

### Specifications:

- **Options:** Expanded temperature range down to -40°C
- **Amperage Rating:** 135A
- **Frame Size:** FR 4
- **Horsepower:** 100 hp
- **Number Of Poles:** Three-pole
- **Phase:** Three-phase
- **Protection:** IP20
- **Type:** Standard soft starter with internal bypass
- **Voltage Rating:** 480V
- **Wiring Connection:** Inline or Inside-the-Delta wiring configuration

### Supporting documents:

- [DS7 Series soft start controller](#)
- [DS7 series soft start controllers, Frame 1 \(4-12A\)](#)
- [Eatons Volume 6-Solid-State Motor Control](#)
- [Eaton Specification Sheet - DS7-340SX135N0-L](#)
- [Product Datasheet - DS7-340SX135N0-L](#)

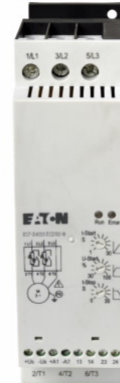

**Certifications:** No Data

**Product compliance:** No Data

---

© 2016 Eaton. All rights reserved.