



Powering Business Worldwide

pe.eaton.com

22.5 mm, Non-metallic Assembled Indicating Light

E22H3X11

UPC:782113552651

Dimensions:

- **Height:** 1.5 IN
- **Length:** 3.5 IN
- **Width:** 3 IN

Weight: .16 LB

Warranties:

- Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

Specifications:


- **Type:** Non-metallic Heavy-Duty
- **Actuator:** Standard
- **Bezel:** Black
- **Light Unit Type:** Incandescent, transformer
- **Enclosure:** NEMA 3, 3R, 4, 4X, 12, 13
- **Lamp Voltage:** 6 Vac
- **Led Lamp Number:** #755
- **Lens Color:** Green
- **Lens Type:** Plastic
- **Series:** E22
- **Style:** 22.5 mm
- **Supply Voltage:** 120 Vac at 60 Hz, 110 Vac at 50 Hz

Supporting documents:

- [Pushbuttons, Indicating lights, Selector switches and Stacklights](#)
- [Eaton Specification Sheet - E22H3X11](#)

Certifications:

- UL 508

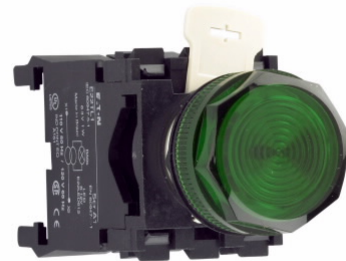

- CSA Certified
- IEC 947-5-1 MTTA
- Lloyd's Register Certified

Product compliance:

- CE Marked

© 2016 Eaton. All rights reserved.