



Powering Business Worldwide

pe.eaton.com

Definite Purpose Control - Contactor

C25DNF240C

UPC:782116310791

Dimensions:

- **Height:** 3.75 IN
- **Length:** 3.35 IN
- **Width:** 2.4 IN

Weight:1.3 LB

Warranties:

- 1 year

Specifications:


- **Amperage Rating:** 40A
- **Coil:** 440-480 Vac, 50/60 Hz
- **Enclosure:** Open with metal mounting plate
- **Frame Size:** 15-50A, two- and three-pole
- **Model:** Contactor
- **Number Of Poles:** Two-pole
- **Resistive Load:** 50A
- **Terminals:** Box lugs (posidrive setscrew) and quick connect terminals (side-by-side)
- **Type:** Non-reversing

Supporting documents:

- [Eatons Volume 5-Motor Control and Protection](#)
- [C25DNF2 3D Inventor](#)
- [Eaton Specification Sheet - C25DNF240C](#)
- [C25DNF2 AutoCAD 2D Footprint](#)
- [C25DNF2 2D Drawing Xchange](#)
- [C25DNF2 AutoCAD 2D Footprint \(mm\)](#)
- [C25DNF2 2D PDF](#)
- [C25DNF2 3D Model Xchange](#)

Certifications:

- UL Recognized
- CSA Certified

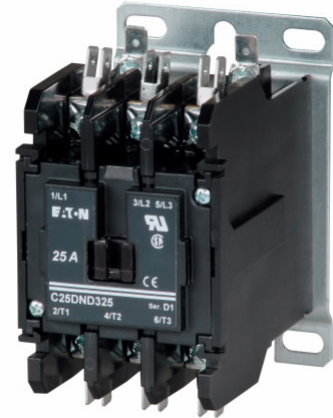

Product compliance: No Data

© 2016 Eaton. All rights reserved.