



Powering Business Worldwide

pe.eaton.com

D4 Series General Purpose Plug-In Relay

D4PR1W1

UPC:782114227848

Dimensions:

- **Height:** 1.14 IN
- **Length:** 1.14 IN
- **Width:** .51 IN

Weight: .5 LB

Notes: Indicator lamp available. Consult sales office or customer support center for additional coil voltages.

Warranties:


- Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

Specifications:

- **Amperage Rating:** 10A
- **Coil Voltage:** 48 Vdc
- **Contact Configuration:** SPDT
- **Cover:** Plain
- **Inductive Full Load:** 7.5A, 250 Vac/5A, 30 Vdc
- **Maximum Voltage:** 380 Vac/125 Vdc
- **Quantity:** 1
- **Resistive Load:** 10A, 250 Vac/30 Vdc
- **Series:** D4 series

Supporting documents:

- [Eatons Volume 7-Logic Control, Operator Interface and Connectivity Solutions](#)
- [D4_R1 3D Inventor](#)
- [Eaton Specification Sheet - D4PR1W1](#)
- [D4_R1 AutoCAD 2D Footprint](#)
- [D4_R1 2D Drawing Xchange](#)

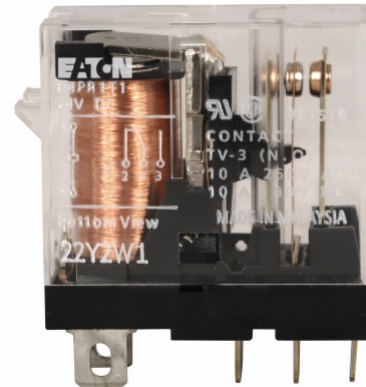

- [D4_R1 2D PDF](#)
- [D4_R1 3D Model Xchange](#)
- [D4_R1 AutoCAD 2D Footprint \(mm\)](#)

Certifications:

- CSA file No. LR701519
- cRUus
- UL Listed file E1491
- UL Listed file E65657

Product compliance:

- RoHS Compliant
- CE Marked