



Powering Business Worldwide

pe.eaton.com

22.5 mm, Non-Metallic Indicating Light

E22H3X44

UPC:782114636312

Dimensions:

- **Height:** X
- **Length:** X
- **Width:** X

Warranties:

- Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

Specifications:

- **Type:** 22.5 mm, Non-metallic Heavy-Duty
- **Actuator:** Standard
- **Bezel:** Black
- **Light Unit Type:** LED, full voltage
- **Enclosure:** NEMA 3, 3R, 4, 4X, 12, 13
- **Led Lamp Number:** Bayonet base
- **Lens Color:** Green
- **Lens Type:** Plastic
- **Series:** E22
- **Supply Voltage:** 120 Vac


Supporting documents:

- [Pushbuttons, Indicating lights, Selector switches and Stacklights](#)
- [Eaton Specification Sheet - E22H3X44](#)

Certifications:

- IEC 947-5-1 MTTA
- UL 508
- CSA Certified
- Lloyd's Register Certified

Product compliance:

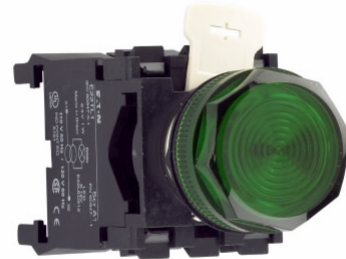

- CE Marked

© 2016 Eaton. All rights reserved.